

Hi-Pro 360

Innovation in every direction—literally!
Rotating, multi-angle LED lamp.

Applications


- Indoor/outdoor direct replacement
- Street lamps/shoe box
- High bays/low bays
- Parking garages
- Commercial and industrial security
- Gymnasiums and other high ceiling applications
- Outdoor canopies

Features

- Multi-angle rotating LED lamp with folding panel design
- Replaces HID, CFL, and incandescent
- Direct wire range voltage 100-277V
- Approved for totally enclosed fixtures
- 70 Watts
- 2700K 4000K or 5000K options
- Built-in 4K surge protection
- EX39 base
- IP64/Damp location
- Long life—50,000 hours
- 5 Year limited warranty

Accessories

- 80/954 - Hi-Pro WiFi Module
- 80/955 - Hi-Pro Motion Sensor / PIR
- 80/956 - Hi-Pro Photocell
- 80/957 - Hi-Pro Motion Sensor / MW

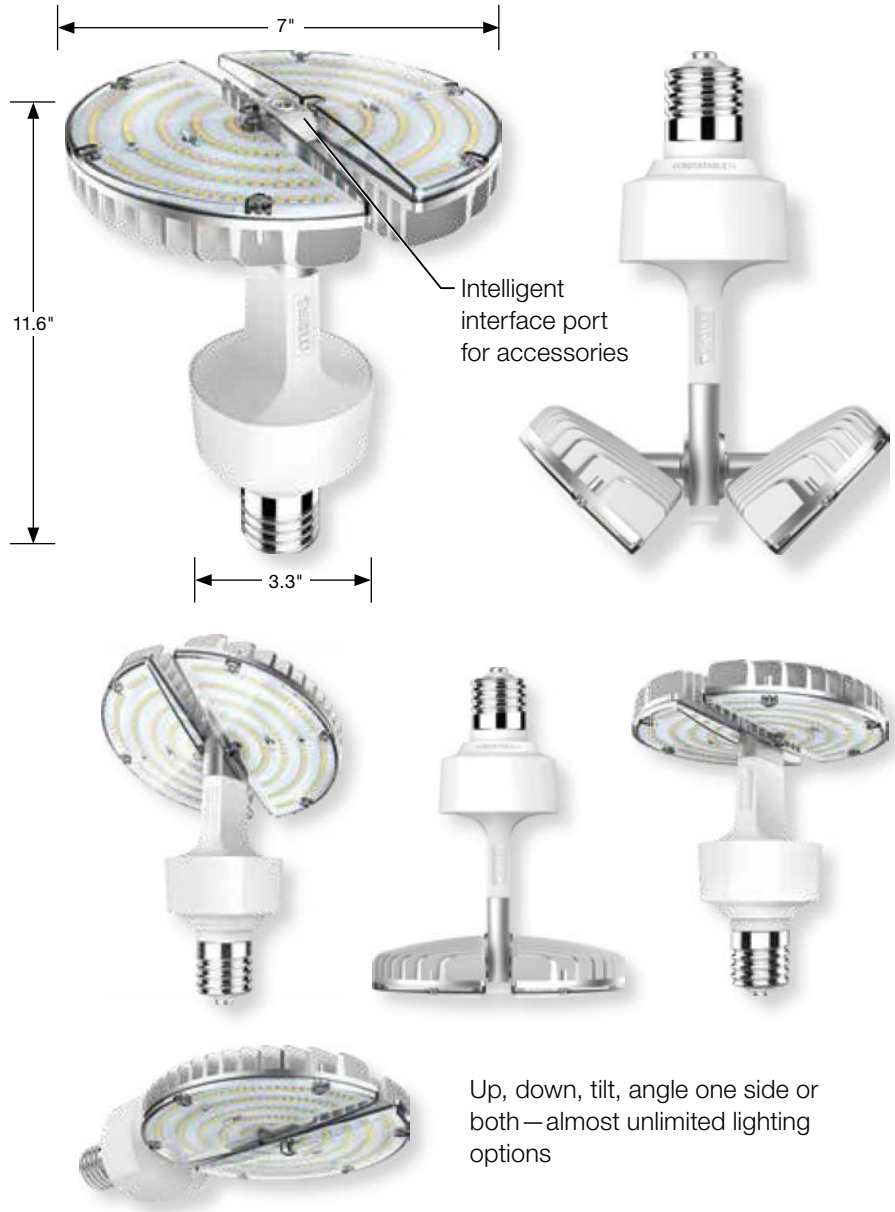

Hi-Pro 360 Lamps

| Item Number | Lamp Description | W | V | Base Type | CRI | CCT | Lm | M.O.L. (Inches) | Life/Hrs. | UPC | Pk./Mstr. |
|-------------|-------------------|----|---------|-----------|-----|------|-------|-----------------|-----------|--------------|-----------|
| S13120* | 70W/LED/HP360/827 | 70 | 100-277 | EX39 | 80+ | 2700 | 10500 | 11.58 | 50K | 045923131202 | 8 |
| S13121* | 70W/LED/HP360/840 | 70 | 100-277 | EX39 | 80+ | 4000 | 10500 | 11.58 | 50K | 045923131219 | 8 |
| S13122* | 70W/LED/HP360/850 | 70 | 100-277 | EX39 | 80+ | 5000 | 10500 | 11.58 | 50K | 045923131226 | 8 |

† Dimmable via WiFi accessory only.



Product sheet SA2579

**See warranty for details.