



# PL-T Triple 4-Pin Base

## PL-T 26W/827/A/4P/ALTO

Philips Linear Compact Fluorescent Lamps offer designers, specifiers and end-users new levels of efficiencies and versatility in sizes, configurations and application possibilities. With so many elegant fixtures available to complement their small size, high light output and advanced technology, Philips Energy Advantage lamps are fast becoming the preferred choice when maximum efficiency and sleek design solutions are required.

### Product data

General Information		Operating and Electrical	
Cap-Base	GX24Q-3 [ GX24q-3]	Power (Rated) (Nom)	27.0 W
LSF Preheat 2000 h Rated	99 %	Lamp Current (Nom)	0.335 A
LSF Preheat 4000 h Rated	98 %		
LSF Preheat 6000 h Rated	97 %		
LSF Preheat 8000 h Rated	90 %		
Light Technical		Temperature	
Color Code	827 [ CCT of 2700K]	Design Temperature (Nom)	28 °C
Initial lumen (Nom)	1750 lm		
Luminous Flux (Rated) (Nom)	1750 lm		
Color Designation	Incandescent White	Controls and Dimming	
Correlated Color Temperature (Nom)	2700 K	Dimmable	Yes
Luminous Efficacy (Rated) (Nom)	64.8 lm/W		
Color Rendering Index (Nom)	82	Mechanical and Housing	
LLMF 2000 h Rated	92 %	Cap-Base Information	4P
LLMF 4000 h Rated	88 %		
LLMF 6000 h Rated	85 %	Approval and Application	
LLMF 8000 h Rated	84 %	Energy Efficiency Label (EEL)	B
LLMF 12000 h Rated	81 %	Mercury (Hg) Content (Nom)	1.4 mg
		Product Data	
		Order product name	PL-T 26W/827/A/4P/ALTO
		EAN/UPC - Product	046677384401
		Order code	458240

# PL-T Triple 4-Pin Base


Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	10
Material Nr. (12NC)	927910982750
Net Weight (Piece)	64.000 g

ILCOS Code	FSM-26/27/1B-E-GX24q=3
------------	------------------------

## Warnings and Safety

- Lamp contains mercury. Manage in Accord with Disposal Laws. See: [www.lamprecycle.org](http://www.lamprecycle.org) or 1-800-555-0050


## Dimensional drawing

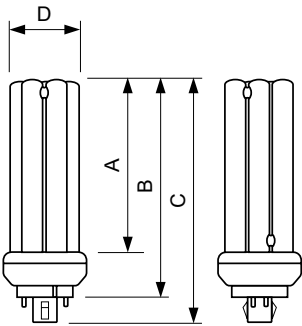


PL-T ALTO 26W/827/4P A

Product	D (max)	A (max)	B (max)	C (max)
PL-T 26W/827/A/4P/ALTO	41 mm	86.7 mm	111.0 mm	126.7 mm

## Photometric data

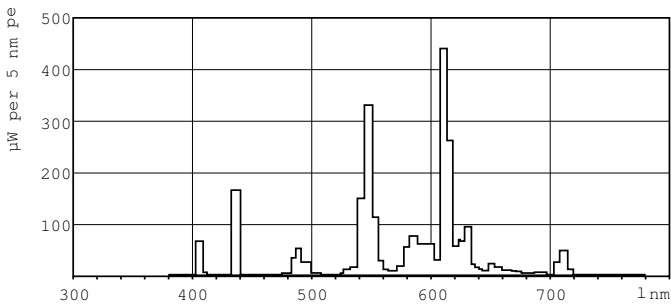



Lightcolor /827

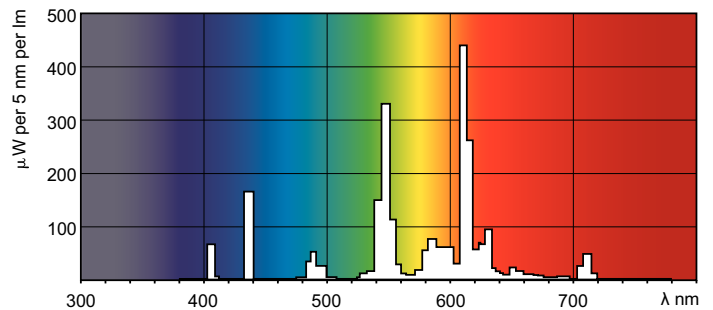


Lightcolor /827

# PL-T Triple 4-Pin Base

## Lifetime

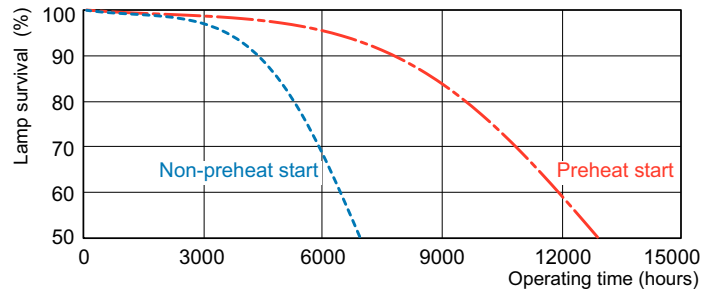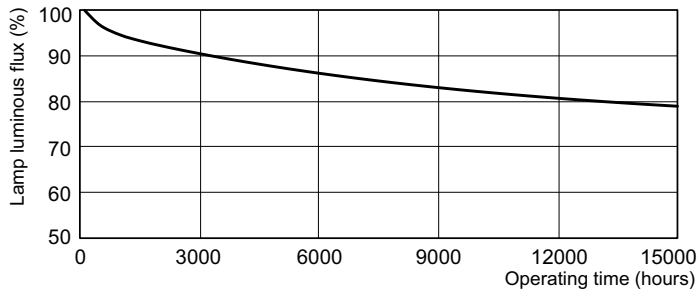

## Lumen Maintenance 3 h and 12 h cycle

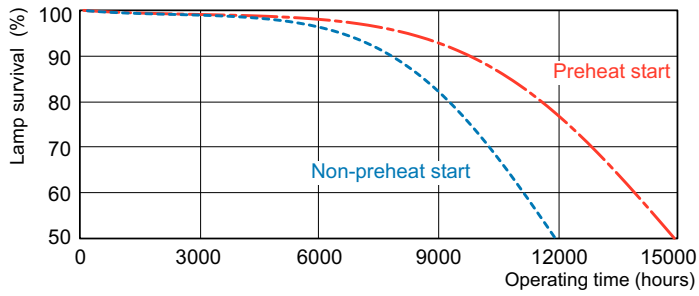

## Life Expectancy 3 h cycle

## Life Expectancy 12 h cycle

