


Project Name

Location

Prepared By

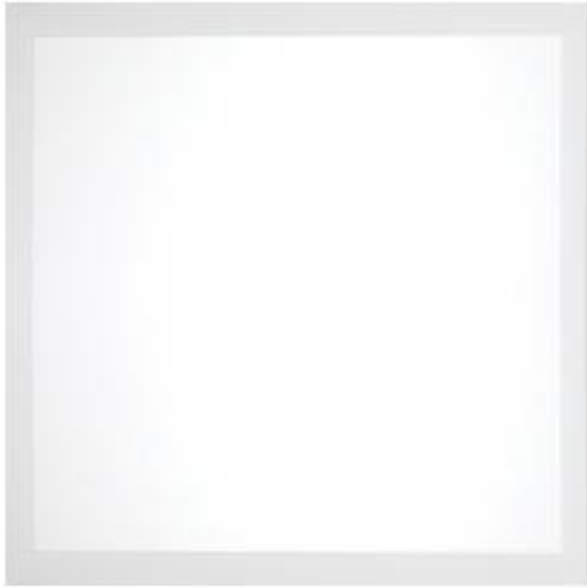

NUVO 65-581

2X2 LED BACKLIT FLAT PANEL

Notes

General

Status	Active
Fixture Type	Flat Panel
Finish	White
Wattage	40
Lumen Output	4200L/4400L/4400L
CCT (Kelvin)	3500K/4000K/5000K

Specifications

Technology	LED
CRI	80+
Voltage	100V-347V
Rated Hours	50000
Operating Temperature	-17C (1F) to a maximum of +45C (+113F)
Dimmable	0-10V Dimming Only
Photocell	No Photocell
Weight (lb.)	4.85

Dimensions

Height (in.)	1.5
Width (in.)	23.75
Length (in.)	23.75

Compliance

Safety Listing	cETLus
Location Rating	Damp
UL Application	Ceiling
Energy Star	No
DLC Approved	Yes
DLC ID	PLGZ8OJ3A5EO
CEC Status	Lawful for sale in California
RoHS Compliant	Yes

Additional Information

Warranty	5 Year Limited
----------	----------------