

4 in. Square boxes
Conduit knockouts

01 **BC52151-K**
Concentric knockouts.

02 **CI52151-KSB**
Concentric knockouts
with side bracket.

03 **BC52151-KSSX**
Concentric knockouts.
“Wraparound” bracket for
2 1/2 in. and 3 5/8 in. steel
studs. With integral
support bracket. Mud /
tile ring must be used.

04 **BC53151-K**
Concentric knockouts.



01



02



03



04



	Volume	Features		Knockouts			
Cat. No.	(Cu. in.)	Bracket	Raised Ground Screw	1/2 in. sides	1/2 in. bottom	3/4 in. sides	3/4 in. bottom
1 1/2 in. deep							
BC52151-K	21.0	–	yes	10	4	6	2
CI52151-KSB	21.0	“SB”	yes	8	4	4	2
BC52151-KSSX	21.0	“SSX”	yes	7	4	3	2
BC53151-K	21.0	–	–	10	–	6	–

4 in. Square boxes

Conduit knockouts

01 **BC52171-HV-KIT**

02 **BC52171-KSSXHVKIT**

03 **CI52171-1-SSX-1**
"Wraparound" bracket for 2 1/2 in. and 3 5/8 in. steel studs. With integral support bracket. Brackets are positioned so the front of the box will be flush with 1/2" drywall.

04 **CI52171-1**
1 in. knockout

05 **BC52171-K**
Concentric knockouts. 1 in. knockout

06 **CI52171-KSB**
Concentric knockouts with side bracket.

07 **BC52171-KSSX**
Concentric knockouts. "Wraparound" bracket for 2 1/2 in. and 3 5/8 in. steel studs. With integral support bracket. Mud / Tile ring must be used.

08 **CI52171-KSSX-1**
Concentric knockouts. "Wraparound" bracket for 2 1/2 in. and 3 5/8 in. steel studs. With integral support bracket. Brackets are positioned so the front of the box will be flush with 1/2" drywall.

09 **BC53171-K**
Concentric knockouts.



01



02



03



04



05



06



07



08



09



	Volume (Cu. in.)	Features						Knockouts
Cat. No.		Bracket	Raised Ground Screw	1/2 in. sides	1/2 in. bottom	3/4 in. sides	3/4 in. bottom	1 in. sides
2 1/8 in. deep								
BC52171-HV-KIT*	33.6	-	yes	6	-	2	-	-
BC52171-KSSXHVKIT*	33.6	“SSX”	yes	6	-	2	-	-
CI52171-1	30.0	-	yes	-	4	-	2	4
CI52171-1-SSX	21.0	“SSX”	yes	-	4	-	2	2
CI52171-1-SSX-1	21.0	“SSX”	yes	-	4	-	2	2
BC52171-K	30.0	-	yes	10	4	6	2	-
CI52171-KSB	30.0	“SB”	yes	8	4	4	2	-
BC52171-KSSX	30.0	“SSX”	yes	7	4	3	2	-
CI52171-KSSX-1	30.0	“SSX”	yes	7	4	3	2	-
BC52171-K	30.0	-	-	10	-	6	-	-

* Must be purchased as a kit. The tile ring cover alone as well as the box alone are not available.

4 in. Square boxes

Mud / plaster ring covers



BC52-C-1



BC52-C-6



52C31/2-25




BC52-C-0



CI52-C-10 to CI-52-C-62



BC52-C-0-B

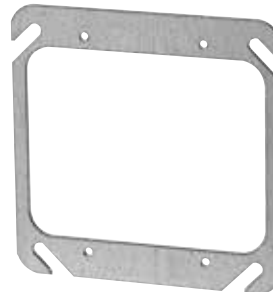

BC52-C-00



BC52-C-17



Cat. No.	Description
Flat covers	
BC52-C-1	Blank
BC52-C-6	1/2 in. conduit knockout
Plaster ring cover	
52C31/2-25*	Raised 1/2 in. (3.5 cu. in.) Tapped ears on 2 3/4 in. centers
Single device covers	
BC52-C-0	Flat
BC52-C-0-B	Flat blank cover
CI52-C-10	Raised 1/8 in. (1.0 cu. in.)
BC52-C-13	Raised 1/2 in. (3.6 cu. in.)
CI52-C-14	Raised 3/4 in. (5.7 cu. in.)
CI52-C-14-5/8	Raised 5/8 in. (4.3 cu. in.)
CI52-C-15	Raised 7/8 in. (6.8 cu. in.)
CI52-C-16	Raised 1 1/4 in. (9.5 cu. in.)
CI52-C-62	Raised 1 1/4 in. (1.8 cu. in.)
Two device covers	
BC52-C-00	Flat
BC52-C-17	Raised 1/2 in. (6.2 cu. in.)
52 C 18*	Raised 3/4 in. (9.0 cu. in.)
52C185/8-25*	Raised 5/8 in. (7.3 cu. in.)

* UL Listed and CSA certified