

## Cushion-Grip Nut Drivers

### Hollow-Shaft Nut Drivers

Includes core Cushion-Grip Nut Driver features plus:

- 3" (76 mm) length for most long bolt and stud applications
- 6" (152 mm) length reaches into deep recesses and fits over extra-long bolts and studs
- Exclusive hollow shaft\* design with Rare Earth magnetic tip features unobstructed pass-through, even on long bolts

Refer to the insulated section for insulated nut drivers.

Cat. No.	Nut Driver Sizes	Shaft Length	Color Code	Overall Length	Weight
610-1/4	1/4"	1.5" (38.1 mm)	Red	3.5" (88.9 mm)	0.10 lb (0.05 kg)
610-5/16	5/16"	1.5" (38.1 mm)	Yellow	3.5" (88.9 mm)	0.10 lb (0.05 kg)
630-3/16	3/16"	3" (76.2 mm)	Black	6.75" (171.5 mm)	0.20 lb (0.09 kg)
630-1/4	1/4"	3" (76.2 mm)	Red	6.75" (171.5 mm)	0.20 lb (0.09 kg)
630-5/16	5/16"	3" (76.2 mm)	Yellow	6.75" (171.5 mm)	0.20 lb (0.09 kg)
630-11/32	11/32"	3" (76.2 mm)	Green	6.75" (171.5 mm)	0.20 lb (0.09 kg)
630-3/8	3/8"	3" (76.2 mm)	Blue	6.75" (171.5 mm)	0.20 lb (0.09 kg)
630-7/16	7/16"	3" (76.2 mm)	Brown	7.313" (185.8 mm)	0.25 lb (0.11 kg)
630-1/2	1/2"	3" (76.2 mm)	Red	7.313" (185.8 mm)	0.25 lb (0.11 kg)
630-9/16	9/16"	4" (101.6 mm)	Orange	9.375" (238.1 mm)	0.35 lb (0.16 kg)
630-5/8	5/8"	4" (101.6 mm)	Yellow	9.375" (238.1 mm)	0.35 lb (0.16 kg)
646-3/16	3/16"	6" (152.4 mm)	Black	9.75" (247.7 mm)	0.25 lb (0.11 kg)
646-1/4	1/4"	6" (152.4 mm)	Red	9.75" (247.7 mm)	0.25 lb (0.11 kg)
646-5/16	5/16"	6" (152.4 mm)	Yellow	9.75" (247.7 mm)	0.25 lb (0.11 kg)
646-11/32	11/32"	6" (152.4 mm)	Green	9.75" (247.7 mm)	0.25 lb (0.11 kg)
646-3/8	3/8"	6" (152.4 mm)	Blue	9.75" (247.7 mm)	0.30 lb (0.14 kg)
646-7/16	7/16"	6" (152.4 mm)	Brown	10.313" (262 mm)	0.35 lb (0.16 kg)
646-1/2	1/2"	6" (152.4 mm)	Red	10.313" (262 mm)	0.35 lb (0.16 kg)
646-9/16	9/16"	6" (152.4 mm)	Orange	11.375" (288.9 mm)	0.40 lb (0.18 kg)
646-5/8	5/8"	6" (152.4 mm)	Yellow	11.375" (288.9 mm)	0.40 lb (0.18 kg)
<b>Metric</b>					
630-4MM	4 mm	3" (76.2 mm)	Red	6.75" (171.5 mm)	0.20 lb (0.09 kg)
630-4.5MM	4.5 mm	3" (76.2 mm)	Yellow	6.75" (171.5 mm)	0.20 lb (0.09 kg)
630-5MM	5 mm	3" (76.2 mm)	Black	6.75" (171.5 mm)	0.20 lb (0.09 kg)
630-6MM	6 mm	3" (76.2 mm)	Red	6.75" (171.5 mm)	0.20 lb (0.09 kg)
630-7MM	7 mm	3" (76.2 mm)	Orange	6.75" (171.5 mm)	0.20 lb (0.09 kg)
630-8MM	8 mm	3" (76.2 mm)	Yellow	6.75" (171.5 mm)	0.20 lb (0.09 kg)
630-10MM	10 mm	3" (76.2 mm)	Blue	6.75" (171.5 mm)	0.20 lb (0.09 kg)
630-11MM	11 mm	3" (76.2 mm)	Brown	7.313" (185.8 mm)	0.20 lb (0.09 kg)



630-11MM

Cat. No.	Set Contains	Weight
631	Nut Driver Set 3" Shafts, 7 Piece	1.5 lb (0.7 kg)

#### Cat. No. Description

630-3/16	3/16" Nut Driver with 3" Hollow Shaft
630-1/4	1/4" Nut Driver 3" Shaft Cushion Grip
630-5/16	5/16" Nut Driver Cushion-Grip 3" Shaft
630-11/32	11/32" Nut Driver 3" Hollow Shaft
630-3/8	3/8" Nut Driver with 3" Hollow Shaft
630-7/16	7/16" Hollow Nut Driver, 3", Cushion-Grip
630-1/2	1/2" Nut Driver, 3" Shaft, Cushion-Grip

Cat. No.	Set Contains	Weight
647	Nut Driver Set 6" Shafts, 7 Piece	1.7 lb (0.8 kg)

#### Cat. No. Description

646-3/16	3/16" Nut Driver with 6" Hollow Shaft
646-1/4	1/4" Nut Driver with 6" Hollow Shaft
646-5/16	5/16" Nut Driver, 6" Hollow Shaft
646-11/32	11/32" Nut Driver 6" Hollow Shaft
646-3/8	3/8" Nut Driver, 6" Hollow Shaft
646-7/16	7/16" Nut Driver, 6" Hollow Shaft
646-1/2	1/2" Nut Driver with 6" Hollow Shaft

Cat. No.	Set Contains	Weight
65160	Nut Driver Set, Metric, 3" Shafts, 7-Piece	1.5 lb (0.7 kg)

#### Cat. No. Description

630-5MM	5 mm Nut Driver, 3" Hollow Shaft
630-55MM	5.5 mm Cushion-Grip Hollow-Shank Nut Driver
630-6MM	6 mm Nut Driver, 3" Hollow Shaft, Cushion Grip
630-7MM	7 mm Cushion Grip Nut Driver with 3" Shaft
630-8MM	8 mm Nut Driver, Cushion Grip, 3" Hollow Shaft
630-9MM	9 mm Cushion-Grip Nut Driver, 3" Hollow Shaft
630-10MM	10mm Cushion Grip Nut Driver with 3" Shaft

Cat. No.	Set Contains	Weight
633	Nut Driver Set, Cushion Grip, 4-Piece	1.3 lb (0.6 kg)

#### Cat. No. Description

630-1/4	1/4" Nut Driver 3" Shaft Cushion Grip
630-5/16	5/16" Nut Driver Cushion-Grip 3" Shaft
630-3/8	3/8" Nut Driver with 3" Hollow Shaft
630-9/16	9/16" Hollow Shaft Nut Driver 4" Shaft

Cat. No.	Set Contains	Weight
610	Stubby Nut Driver Set 1-1/2" Shafts 2 Pc	0.20 lb (0.09 kg)

#### Cat. No. Description

610-1/4	1/4" Stubby Nut Driver with 1-1/2" Shaft
610-5/16	5/16" Stubby Nut Driver, 1-1/2" Shaft



## Cushion-Grip Multi-Nut Drivers

Solid build quality with nut drivers that exceed the standard torque performance



**Wrench-assist** feature for added torque



ASSEMBLED  
IN  
**USA**



**Cushion-Grip handle** for greater torque and comfort

**Hollow-shafts** accommodate long bolts

**Color-coded bands** for easy identification

## Heavy-Duty Multi-Nut Drivers

- Multiple sizes in one convenient tool
- Heavy-duty handle and shaft exceed the torque performance of regular nut drivers
- Wrench-assist feature for added torque
- Strong, rare earth magnets securely hold nuts and bolts (Cat. No. 32807MAG)



32807MAG



32800

Cat. No.	Description	Nut Driver Sizes	Shaft Length	Overall Length	Weight
<b>NEW</b> 32807MAG	7-in-1 Nut Driver	1/4", 5/16", 11/32", 3/8", 1/2", 7/16", 9/16"		9.54" (242.3 mm)	1.12 lb (0.51 kg)
32800	6-in-1 Multi-Nut Driver Heavy Duty	3/16", 1/4", 5/16", 3/8", 7/16", 9/16"	4" (101.6 mm)	9.5" (241.3 mm)	1.2 lb (0.5 kg)
32801	5-in-1 Multi-Nut Driver Heavy Duty	3/16", 1/4", 5/16", 3/8", 9/16"	4" (101.6 mm)	9.109" (231.4 mm)	1.0 lb (0.5 kg)

## Specialty Cushion-Grip Nut Drivers

### Coated Hollow-Shaft Nut Drivers

Includes core Cushion-Grip Nut Driver features plus:

- Entire shaft plastic coated for circuit protection only. NOT INSULATED
- Special plastic coating resists cutting, cracking and chipping
- Thin coating permits use in confined areas



640-1/2

Cat. No.	Nut Driver Sizes	Shaft Length	Color Code	Overall Length	Weight
640-3/16	3/16"	3" (76.2 mm)	Black	6.75" (171.5 mm)	0.25 lb (0.11 kg)
640-1/4	1/4"	3" (76.2 mm)	Red	6.75" (171.5 mm)	0.25 lb (0.11 kg)
640-5/16	5/16"	3" (76.2 mm)	Yellow	6.75" (171.5 mm)	0.25 lb (0.11 kg)
640-3/8	3/8"	3" (76.2 mm)	Blue	6.75" (171.5 mm)	0.25 lb (0.11 kg)
640-7/16	7/16"	3" (76.2 mm)	Brown	7.313" (185.8 mm)	0.30 lb (0.14 kg)
640-1/2	1/2"	3" (76.2 mm)	Red	7.313" (185.8 mm)	0.25 lb (0.11 kg)
640-9/16	9/16"	4" (101.6 mm)	Orange	9.375" (238.1 mm)	0.40 lb (0.18 kg)
640-5/8	5/8"	4" (101.6 mm)	Yellow	9.375" (238.1 mm)	0.40 lb (0.18 kg)


**⚠ WARNING:** NOT insulated. Coating is intended for protection of circuits only.

See page 297 for additional information on warnings.



# Plastic-Handle Nut Drivers

Meets or exceeds applicable ASME / ANSI and MIL specifications.

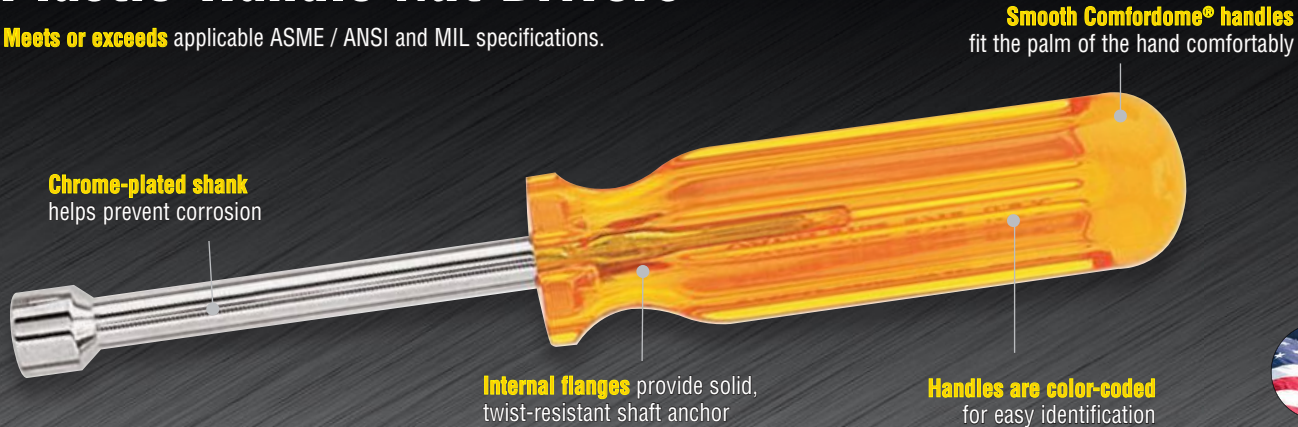

## Hollow-Shaft Nut Drivers

Includes core Plastic-Handle Nut Driver features plus:

- Standard length works for most applications
- Fits over long bolts and studs
- Cat. Nos. SS8, SS10 and SS12 have smaller shaft length for work in close quarters



S11



Cat. No.	Nut Driver Sizes	Shaft Length	Handle Color	Overall Length	Weight
SS8	1/4"	1.5" (38.1 mm)	Red	3.75" (95.3 mm)	0.15 lb (0.07 kg)
SS10	5/16"	1.5" (38.1 mm)	Amber	3.75" (95.3 mm)	0.15 lb (0.07 kg)
SS12	3/8"	1.5" (38.1 mm)	Blue	3.75" (95.3 mm)	0.15 lb (0.07 kg)
S5	5/32"	3" (76.2 mm)	Amber	6.5" (165.1 mm)	0.10 lb (0.05 kg)
S6	3/16"	3" (76.2 mm)	Black	6.625" (168.3 mm)	0.10 lb (0.05 kg)
S7	7/32"	3" (76.2 mm)	Brown	6.625" (168.3 mm)	0.10 lb (0.05 kg)
S8	1/4"	3" (76.2 mm)	Red	6.625" (168.3 mm)	0.15 lb (0.07 kg)
S9	9/32"	3" (76.2 mm)	Orange	6.625" (168.3 mm)	0.15 lb (0.07 kg)
S10	5/16"	3" (76.2 mm)	Amber	6.625" (168.3 mm)	0.15 lb (0.07 kg)
S11	11/32"	3" (76.2 mm)	Green	6.625" (168.3 mm)	0.15 lb (0.07 kg)
S12	3/8"	3" (76.2 mm)	Blue	6.625" (168.3 mm)	0.15 lb (0.07 kg)
S14	7/16"	3" (76.2 mm)	Brown	7" (177.8 mm)	0.20 lb (0.09 kg)
S16	1/2"	3" (76.2 mm)	Red	7" (177.8 mm)	0.20 lb (0.09 kg)
S18	9/16"	4" (101.6 mm)	Red	8.5" (215.9 mm)	0.30 lb (0.14 kg)
S20	5/8"	4" (101.6 mm)	Red	8.5" (215.9 mm)	0.30 lb (0.14 kg)
S66	3/16"	6" (152.4 mm)	Black	9.625" (244.5 mm)	0.15 lb (0.07 kg)
S86	1/4"	6" (152.4 mm)	Red	9.625" (244.5 mm)	0.15 lb (0.07 kg)
S106	5/16"	6" (152.4 mm)	Amber	9.625" (244.5 mm)	0.15 lb (0.07 kg)
S116	11/32"	6" (152.4 mm)	Green	9.625" (244.5 mm)	0.15 lb (0.07 kg)
S126	3/8"	6" (152.4 mm)	Blue	9.625" (244.5 mm)	0.15 lb (0.07 kg)
S146	7/16"	6" (152.4 mm)	Brown	10" (254.0 mm)	0.20 lb (0.09 kg)
S166	1/2"	6" (152.4 mm)	Red	10" (254.0 mm)	0.20 lb (0.09 kg)

Cat. No.	Set Contains	Weight
K7	Nut Driver Set, 3" Shafts, 7-Piece	1.2 lb (0.5 kg)

Cat. No.	Description
S6	3/16" Nut Driver, 3" Hollow Shaft
S8	1/4" Hollow Shaft Nut Driver, 3" Shaft
S10	5/16" Nut Driver 3" Hollow Shaft
S11	11/32" Nut Driver, 3" Hollow Shaft
S12	3/8" Nut Driver, 3" Hollow Shaft
S14	7/16" Nut Driver, 3" Hollow Shaft
S16	1/2" Nut Driver 3" Hollow Shaft

Cat. No.	Set Contains	Weight
89904	Nut Driver Set, 6" Shafts, 7-Piece	1.2 lb (0.5 kg)

Cat. No.	Description
S66	3/16" Nut Driver 6" Hollow Shaft
S86	1/4" Nut Driver, 6" Hollow Shaft
S106	5/16" Nut Driver, 6" Shaft
S116	11/32" Nut Driver, 6" Shaft
S126	3/8" Nut Driver, 6" Hollow Shaft
S146	7/16" Nut Driver, 6" Hollow Shaft
S166	1/2" Nut Driver, 6" Hollow Shaft

Set Cat. No. K7 includes a vinyl pouch which hangs up or rolls up

