

## Saws & Blades

### High-Tension Hacksaw

- Adjustable blade tension up to 30,000 PSI for fast, precise cuts
- Soft-touch grips
- Alternative 45° mounting for flush cutting
- Front mount for reciprocating saw blades
- Blade storage in handle
- Includes 12" x 24 TPI bi-metal hack saw blade and 6" x 24 TPI bi-metal reciprocating saw blade

Cat. No.	Blade Length	Overall Length	Weight
702-12	12" (304.8 mm)	16.25" (412.8 mm)	1.5 lb (0.7 kg)



702-12

### Dual-Purpose Hacksaw - Golden Tri-Cut™ 3-in-1 Blade

- Blade has three teeth sizes
- Blade converts quickly to 90° or 45° for standard or flush-cut applications
- Pivot-lock adjusts blade tension for straighter cuts and longer blade life
- Set screw allows for storage of extra blades and secures blade for "jab" sawing
- Thumb guard for two-hand sawing
- Made in USA

Cat. No.	Blade Length	Overall Length	Weight
701-S	12" (304.8 mm)	16" (406.4 mm)	1.5 lb (0.7 kg)



701-S



Blade has three teeth sizes

### Bi-Metal Blades



1224BI

- Special high-speed steel teeth fused to carbon-steel body, which provides superior cutting and longer life
- Withstands greater saw tension for less blade flexing
- Fits all 12" (305 mm) hacksaw blades
- Available in box of 100 blades or in a reclosable, heavy-vinyl, seal-tight pouch of 10 blades
- Made in USA

Cat. No.	Teeth Per Inch	Overall Length	Package Quantity	Weight
1218BI-P	18	12" (304.8 mm)	10	0.45 lb (0.20 kg)
1224BI-P	24	12" (304.8 mm)	10	0.45 lb (0.20 kg)
1232BI-P	32	12" (304.8 mm)	10	0.45 lb (0.20 kg)
1218BI	18	12" (304.8 mm)	100	4.5 lb (2.0 kg)
1224BI	24	12" (304.8 mm)	100	4.5 lb (2.0 kg)
1232BI	32	12" (304.8 mm)	100	4.5 lb (2.0 kg)

### Golden Tri-Cut™ Blades



1200BI



Blade has three teeth sizes

- Unique design provides three teeth sizes on one blade
- Has 32 teeth/inch for quick starts, along with 24 teeth/inch and 18 teeth/inch for fast and smooth conventional cutting
- Special high-speed steel teeth fused to carbon-steel provide superior cutting action and long life
- Available in box of 100 blades or in a reclosable, heavy-vinyl, seal-tight pouch of ten blades
- Made in USA

Cat. No.	Teeth Per Inch	Overall Length	Package Quantity	Weight
1200BI-P	32-24-18	12" (304.8 mm)	10	0.45 lb (0.20 kg)
1200BI	32-24-18	12" (304.8 mm)	100	4.5 lb (2.0 kg)



## Saws & Blades

### Reciprocating Saw Blades

- Bi-metal blades offer different cutting applications of steel and wood
- Bi-metal construction for long cutting life
- Heat and wear resistant
- Shock resistant teeth resist strippage
- 1/2" universal shank to fit all popular reciprocating saw tools
- Made in USA



31716



31728

Cat. No.	Application	Teeth Per Inch	Blade Length	Blade Width	Blade Thickness	Package Quantity	Weight
31716	Wood with Nails	6	6" (152.4 mm)	0.75" (19.1 mm)	0.050" (1.27 mm)	5	0.23 lb (0.10 kg)
31751	Wood, Wood with Nails	6	9" (228.6 mm)	0.75" (19.1 mm)	0.05" (1.27 mm)	5	0.30 lb (0.14 kg)
31761	Wood with Nails	6	12" (304.8 mm)	0.75" (19.1 mm)	0.05" (1.27 mm)	5	0.50 lb (0.23 kg)
31731	Wood with Nails, Heavy Gauge Metals	10/14	6" (152.4 mm)	0.75" (19.1 mm)	0.050" (1.27 mm)	5	0.25 lb (0.11 kg)
31741	Wood with Nails, Heavy Gauge Metals	10/14	8" (203.2 mm)	0.75" (19.1 mm)	0.05" (1.27 mm)	5	0.40 lb (0.18 kg)
31727	Heavy Gauge Metals	14	6" (152.4 mm)	0.75" (19.1 mm)	0.035" (0.89 mm)	5	0.25 lb (0.11 kg)
31755	Heavy Gauge Metals	14	9" (228.6 mm)	1" (25.4 mm)	0.042" (1.07 mm)	5	0.50 lb (0.23 kg)
31728	Heavy Gauge Metals	18	6" (152.4 mm)	0.75" (19.1 mm)	0.035" (0.89 mm)	5	0.41 lb (0.19 kg)
31739	Heavy Gauge Metals	18	8" (203.2 mm)	0.75" (19.1 mm)	0.035" (0.89 mm)	5	0.30 lb (0.14 kg)
31734	18 Gauge and Under	24	6" (152.4 mm)	0.75" (19.1 mm)	0.035" (0.89 mm)	5	0.10 lb (0.05 kg)

NOTE: Read and follow safety instructions in power tool owner's manual.

### Magic-Slot Compass Saws

- Magic-Slot design allows fast blade changing without removing thumbscrew
- Strong, lightweight, die-cast zinc handle with blue finish is contoured for comfort
- Cat. No. 703 comes with Cat. No. 706 8" blade
- Cat. No. 702 can be used with Magic-Slot cut-in or general-purpose blades only
- Made in USA



703

Cat. No.	Teeth Per Inch	Overall Length	Weight
703	10	13" (330.2 mm)	1.2 lb (0.5 kg)
<b>Magic-Slot Compass Saw Handle</b>			
702	702	5" (127.0 mm)	1.1 lb (0.5 kg)

### Compass Saw Replacement Blades


- For cutting through wallboard or Masonite to install wiring, outlet boxes, etc.
- Tough high-quality carbon steel
- Fits Magic-Slot compass saw handle Cat. No. 702



709

Cat. No.	Teeth Per Inch	Blade Length	Weight
704	8	12" (304.8 mm)	0.14 lb (0.06 kg)
705	10	12" (304.8 mm)	0.14 lb (0.06 kg)
706	10	8" (203.2 mm)	1.4 oz (40 g)
707	10	10" (254.0 mm)	0.12 lb (0.05 kg)
709	10	4" (101.6 mm)	1.0 oz (28 g)



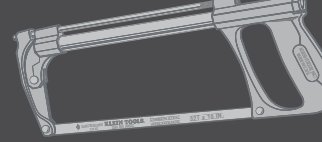

## Saws & Blades

### Jab Saws

- Cuts drywall, wallboard, plywood and plastic and other construction materials
- Faster cutting blade with triple ground teeth and ability to cut in both directions (push and pull)
- Folding Jab Saw (Cat. No. 31737) is as sturdy as fixed blade jab saws, with a lockback mechanism to secure the blade open at 125° and fully open at 180°
- Hardened, carbon-steel blade for durability
- Hardened, beveled blade point for scoring and plunge cuts
- Comfort cushioned grip handle
- Flat-end grip for palming or punching through drywall



725



31737

Folding Jab Saw blade securely locks at 125° and 180°



Folding Jab Saw shown closed, prevents punctures to tool bags

Cat. No.	Description	Blade Length	Overall Length	Weight
<b>NEW</b> 31737	Folding Jab Saw	5.2" (132.1 mm)	11.9" (302.6 mm)	0.54 lb (0.25 kg)
725	Jab Saw	6" (152.4 mm)	12" (304.8 mm)	0.31 lb (0.14 kg)



See page 297 for additional information on warnings.

