

High Leverage Side-Cutting Pliers

Rivet is closer to cutting edge

46% GREATER cutting and gripping power than other pliers designs



FORGED STEEL

from Klein's US-made, proprietary blend

Unique handle tempering helps absorb the "snap" when cutting wire

Hot-riveted joint ensures smooth action and no handle wobble

Induction hardened cutting knives for long life

Sure-gripping cross-hatched knurled jaws

Precision-hardened plier head for on-the-job toughness

Lineman's Pliers

Includes core high-leverage side-cutting features plus:

- Combination polished and black-oxide finish
- New England nose (Cat. No. J20008 has New England Tapered nose; Cat. No. D213-9 has Square nose)
- Glow in the dark grips are easily spotted in dark or low lit areas (Cat. No. D2000-9NEGLW)



 
D213-9NE



SPLIT TETHER RING
FOR USE WITH TETHER
D213-9NETT



Plain



Plastic-Dipped



JOURNEYMAN™
Dual-Material



Heavy,
Plastic-Dipped

Refer to the insulated section for insulated pliers.

Cat. No.	Overall Length	Jaw Length	Jaw Width	Jaw Thickness	Knife Length	Handle Color	Handle Finish	Weight
213-9NE	9.25" (235 mm)	1.594" (40.5 mm)	1.25" (31.8 mm)	5/8" (15.9 mm)	0.781" (19.8 mm)	Black	Plain	1.1 lb (0.5 kg)
D213-9	9.375" (238.1 mm)	1.594" (40.5 mm)	1.25" (31.8 mm)	1-19/32" (40.5 mm)	0.781" (19.8 mm)	Dark Blue	Plastic-Dipped	1.1 lb (0.5 kg)
D213-8NE	8.688" (220.7 mm)	1.438" (36.5 mm)	1.188" (30.2 mm)	5/8" (15.9 mm)	0.719" (18.3 mm)	Dark Blue	Plastic-Dipped	0.90 lb (0.41 kg)
D213-9NE	9.375" (238.1 mm)	1.594" (40.5 mm)	1.25" (31.8 mm)	5/8" (15.9 mm)	0.781" (19.8 mm)	Dark Blue	Plastic Dipped	1.1 lb (0.5 kg)
D213-9NETT	9.375" (238.1 mm)	1.594" (40.5 mm)	1.25" (31.8 mm)	1-19/32" (40.5 mm)	0.781" (19.8 mm)	Dark Blue	Plastic Dipped	1.1 lb (0.5 kg)
HD213-9NE	9.5" (241.3 mm)	1.594" (40.5 mm)	1.25" (31.8 mm)	5/8" (15.9 mm)	0.781" (19.8 mm)	Light Red	Heavy Plastic-Dipped	1.2 lb (0.5 kg)
J2138NE	8.813" (223.9 mm)	1.438" (36.5 mm)	1.188" (30.2 mm)	5/8" (15.9 mm)	0.719" (18.3 mm)	Dark Blue/Black	Journeyman	0.97 lb (0.44 kg)
J213-9NE	9.5" (241.3 mm)	1.594" (40.5 mm)	1.25" (31.8 mm)	5/8" (15.9 mm)	0.781" (19.8 mm)	Dark Blue/Black	Journeyman	1.1 lb (0.5 kg)
Pliers with heavy-duty cutting knives designed to cut ACSR, screws, nails and most hardened wire								
D2000-7	7.875" (200 mm)	1.281" (32.5 mm)	1.031" (26.2 mm)	1/2" (12.7 mm)	0.75" (19.1 mm)	Light Blue	Plastic-Dipped	0.66 lb (0.30 kg)
D2000-8	8.688" (220.7 mm)	1.438" (36.5 mm)	1.109" (28.2 mm)	5/8" (15.9 mm)	0.75" (19.1 mm)	Light Blue	Plastic-Dipped	0.85 lb (0.39 kg)
D2000-9NE	9.375" (238.1 mm)	1.594" (40.5 mm)	1.25" (31.8 mm)	5/8" (15.9 mm)	0.781" (19.8 mm)	Light Blue	Plastic-Dipped	1.1 lb (0.5 kg)
D20009NEGLW	9.375" (238.1 mm)	1.594" (40.5 mm)	1.25" (31.8 mm)	5/8" (15.9 mm)	0.781" (19.8 mm)	Glow in the Dark	Plastic-Dipped	1.1 lb (0.5 kg)
HD2000-9NE	9.5" (241.3 mm)	1.594" (40.5 mm)	1.25" (31.8 mm)	5/8" (15.9 mm)	0.781" (19.8 mm)	Light Red	Heavy Plastic-Dipped	1.2 lb (0.5 kg)
J20008	8.813" (223.9 mm)	1.438" (36.5 mm)	1.109" (28.2 mm)	5/8" (15.9 mm)	0.75" (19.1 mm)	Light Blue/Black	Journeyman	0.93 lb (0.42 kg)
J2000-9NE	9.5" (241.3 mm)	1.594" (40.5 mm)	1.25" (31.8 mm)	5/8" (15.9 mm)	0.781" (19.8 mm)	Light Blue/Black	Journeyman	1.1 lb (0.5 kg)





High-Leverage Side-Cutting Pliers

Fish Tape Pulling Pliers

Includes core high-leverage side-cutting features plus:

- Easily pulls 1/8" or 1/4" flat steel fish tape without damaging the tape
- Crimps non-insulated connectors, lugs, and terminals (Cat. No. J2000-9NECRTP)



D213-9NETP



Plastic-Dipped



JOURNEYMAN™
Dual-Material

Cat. No.	Overall Length	Jaw Length	Jaw Width	Jaw Thickness	Knife Length	Handle Color	Handle Finish	Weight
D213-9NETP	9.375" (238.1 mm)	1.594" (40.5 mm)	1.25" (31.8 mm)	5/8" (15.9 mm)	0.781" (19.8 mm)	Dark Blue	Plastic-Dipped	1.1 lb (0.5 kg)
J213-9NETP	9.5" (241.3 mm)	1.594" (40.5 mm)	1.25" (31.8 mm)	5/8" (15.9 mm)	0.781" (19.8 mm)	Dark Blue/Black	Journeyman	1.1 lb (0.5 kg)
Pliers with heavy-duty cutting knives designed to cut ACSR, screws, nails and most hardened wire								
D2000-9NETP	9.375" (238.1 mm)	1.594" (40.5 mm)	1.25" (31.8 mm)	5/8" (15.9 mm)	0.781" (19.8 mm)	Light Blue	Plastic-Dipped	1.1 lb (0.5 kg)
J2000-9NETP	9.5" (241.3 mm)	1.594" (40.5 mm)	1.25" (31.8 mm)	5/8" (15.9 mm)	0.781" (19.8 mm)	Light Blue/Black	Journeyman	1.1 lb (0.5 kg)
J2000-9NECRTP	9.5" (241.3 mm)	1.594" (40.5 mm)	1.25" (31.8 mm)	1-19/32" (40.5 mm)	0.781" (19.8 mm)	Blue/Black	Journeyman	1.1 lb (0.5 kg)

Bolt-Thread Holding Pliers

Includes core high-leverage side-cutting features plus:

- Hinge opening holds and cleans 5/8" pole line and hardware bolts or threaded rods



D213-9NETH



Plastic-Dipped



Heavy,
Plastic-Dipped

Cat. No.	Overall Length	Jaw Length	Jaw Width	Jaw Thickness	Knife Length	Handle Color	Handle Finish	Weight
D213-9NETH	9.375" (238.1 mm)	1.594" (40.5 mm)	1.25" (31.8 mm)	5/8" (15.9 mm)	0.781" (19.8 mm)	Dark Blue	Plastic-Dipped	1.1 lb (0.5 kg)
HD213-9NETH	9.5" (241.3 mm)	1.594" (40.5 mm)	1.25" (31.8 mm)	5/8" (15.9 mm)	0.781" (19.8 mm)	Light Red	Heavy Plastic-Dipped	1.2 lb (0.5 kg)
Pliers with heavy-duty cutting knives designed to cut ACSR, screws, nails and most hardened wire								
D2000-9NETH	9.375" (238.1 mm)	1.594" (40.5 mm)	1.25" (31.8 mm)	5/8" (15.9 mm)	0.781" (19.8 mm)	Light Blue	Plastic-Dipped	1.2 lb (0.5 kg)

Connector Crimping Pliers

Includes core high-leverage side-cutting features plus:

- Crimps non-insulated connectors, lugs and terminals
- Cleanly strips 10-12 AWG solid wire and 12-14 AWG stranded wire (Cat. No. J2139NECRN)



D213-9NECR



Plastic-Dipped



JOURNEYMAN™
Dual-Material



WIRE STRIPPING HEAD
J213-9NECRN


Cat. No.	Overall Length	Jaw Length	Jaw Width	Jaw Thickness	Knife Length	Handle Color	Handle Finish	Weight
D213-9NE-CR	9.375" (238.1 mm)	1.594" (40.5 mm)	1.25" (31.8 mm)	5/8" (15.9 mm)	0.781" (19.8 mm)	Yellow	Plastic-Dipped	1.0 lb (0.5 kg)
J213-9NECR	9.5" (241.3 mm)	1.594" (40.5 mm)	1.25" (31.8 mm)	5/8" (15.9 mm)	0.781" (19.8 mm)	Yellow/Black	Journeyman	1.1 lb (0.5 kg)
J2139NECRN	9.5" (241.3 mm)	1.594" (40.5 mm)	1.25" (31.8 mm)	5/8" (15.9 mm)	0.781" (19.8 mm)	Yellow/Black	Journeyman	1.1 lb (0.5 kg)
Pliers with heavy-duty cutting knives designed to cut ACSR, screws, nails and most hardened wire								
D2000-9NECR	9.375" (238.1 mm)	1.594" (40.5 mm)	1.25" (31.8 mm)	5/8" (15.9 mm)	0.781" (19.8 mm)	Light Blue	Plastic-Dipped	1.1 lb (0.5 kg)
J2000-9NECR	9.5" (241.3 mm)	1.594" (40.5 mm)	1.25" (31.8 mm)	5/8" (15.9 mm)	0.781" (19.8 mm)	Light Blue/Black	Journeyman	1.1 lb (0.5 kg)




Side-Cutting Pliers

Side-Cutting Pliers

- J20017NE features Journeyman™ Series dual-material handles

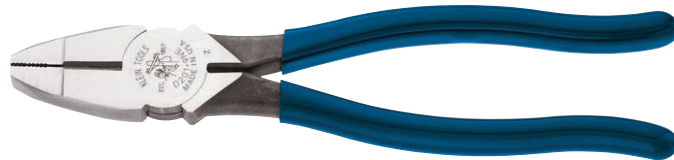

D201-9NE

 

Plastic-Dipped



JOURNEYMAN™ Dual-Material

Cat. No.	Overall Length	Jaw Length	Jaw Width	Jaw Thickness	Knife Length	Handle Color	Handle Finish	Weight
D201-8	8.688" (220.7 mm)	1.438" (36.5 mm)	1.219" (31 mm)	5/8" (15.9 mm)	0.719" (18.3 mm)	Dark Blue	Plastic-Dipped	0.93 lb (0.42 kg)
D201-7NE	7.438" (188.9 mm)	1.281" (32.5 mm)	1.063" (27 mm)	1/2" (12.7 mm)	0.625" (15.9 mm)	Dark Blue	Plastic-Dipped	0.55 lb (0.25 kg)
D201-8NE	8.688" (220.7 mm)	1.438" (36.5 mm)	1.188" (30.2 mm)	5/8" (15.9 mm)	0.719" (18.3 mm)	Dark Blue	Plastic-Dipped	0.92 lb (0.42 kg)
J20017NE	7.563" (192.1 mm)	1.281" (32.5 mm)	1.063" (27 mm)	1-9/32" (32.5 mm)	0.625" (15.9 mm)	Light Blue/Black	Journeyman	0.61 lb (0.28 kg)

Ironworker's Pliers


- Twists and cuts soft annealed rebar tie wire
- High-leverage design. Rivet is closer to the cutting edge for 46% greater cutting and gripping power than other pliers designs (Cat. Nos. 213-9ST, D213-9ST and D20009ST)
- Hook bend handle
- Spring-loaded action for self-opening
- Heavy-duty knurled jaws (Cat. Nos. D201-7CSTA, D213-9STT, 213-9ST, D213-9ST and D2000-9ST)



SPLIT TETHER RING FOR USE WITH TETHER
D201-7CSTT
D213-9STT




D201-7CSTA

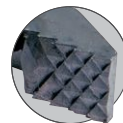

DEEPER CHANNELS ON KNURL
D201-7CSTA



 Plain



Plastic-Dipped

Cat. No.	Overall Length	Jaw Length	Jaw Width	Jaw Thickness	Knife Length	Handle Color	Handle Finish	Weight
201-7CST	9.125" (231.8 mm)	1.281" (32.5 mm)	1.156" (29.4 mm)	1/2" (12.7 mm)	0.625" (15.9 mm)	Black	Plain	0.65 lb (0.29 kg)
D201-7CST	9.25" (235 mm)	1.281" (32.5 mm)	1.156" (29.4 mm)	1/2" (12.7 mm)	0.625" (15.9 mm)	Blue	Plastic	0.75 lb (0.34 kg)
D201-7CSTA	9.25" (235 mm)	1.281" (32.5 mm)	1.156" (29.4 mm)	1-9/32" (32.5 mm)	0.625" (15.9 mm)	Red	Plastic	0.75 lb (0.34 kg)
D201-7CSTT	9" (228.6 mm)	1.5" (38.1 mm)	1.25" (31.8 mm)	1-1/2" (38.1 mm)	0.625" (15.9 mm)	Blue	Plastic	0.68 lb (0.31 kg)
213-9ST	9.25" (235 mm)	1.594" (40.5 mm)	1.25" (31.8 mm)	5/8" (15.9 mm)	0.781" (19.8 mm)	Black	Plain	1.0 lb (0.5 kg)
D213-9ST	9.375" (238.1 mm)	1.594" (40.5 mm)	1.25" (31.8 mm)	5/8" (15.9 mm)	0.781" (19.8 mm)	Blue	Plastic	1.1 lb (0.5 kg)
D213-9STT	9.375" (238.1 mm)	2" (50.8 mm)	1.25" (31.8 mm)	2" (50.8 mm)	0.781" (19.8 mm)	Blue	Plastic	1.1 lb (0.5 kg)
Pliers with heavy-duty cutting knives designed to cut ACSR, screws, nails and most hardened wire								
D2000-7CST	9.25" (235 mm)	1.281" (32.5 mm)	1.156" (29.4 mm)	1/2" (12.7 mm)	0.625" (15.9 mm)	Blue	Plastic	0.70 lb (0.32 kg)
D2000-9ST	9.375" (238.1 mm)	1.594" (40.5 mm)	1.25" (31.8 mm)	5/8" (15.9 mm)	0.781" (19.8 mm)	Blue	Plastic Dipped	1.1 lb (0.5 kg)

