
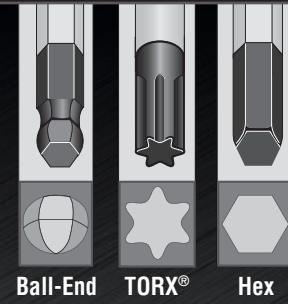


JOURNEYMAN

T-Handle Hex-Keys

Tip-Ident™
sizes marked

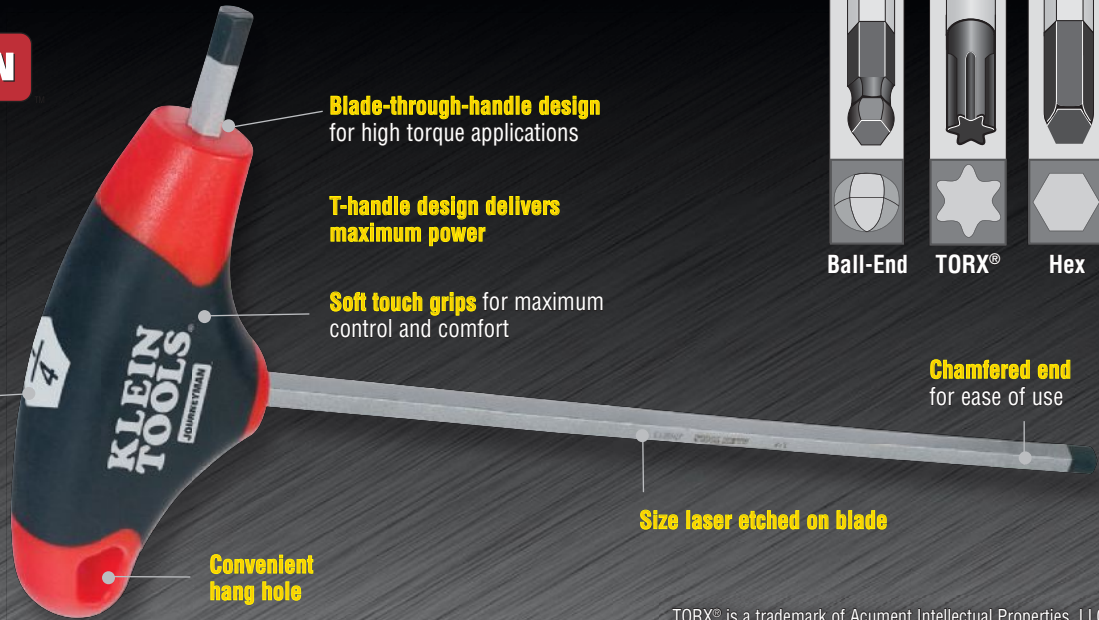

Ball-End TORX® Hex

Chamfered end
for ease of use

Size laser etched on blade

TORX® is a trademark of Acument Intellectual Properties, LLC.

T-Handle Ball-End Hex-Keys - SAE

Includes core Journeyman™ T-handle hex-key features plus:

- Short blade-through-handle provides maximum tool versatility



JTH6E13BE

Cat. No.	Hex Size	Blade Length	Weight
JTH6E06BE	3/32"	6" (152.4 mm)	0.64 oz (18.1 g)
JTH6E07BE	7/64"	6" (152.4 mm)	0.80 oz (22.7 g)
JTH6E08BE	1/8"	6" (152.4 mm)	1.0 oz (28 g)
JTH6E09BE	9/64"	6" (152.4 mm)	1.1 oz (31 g)
JTH6E10BE	5/32"	6" (152.4 mm)	0.12 lb (0.05 kg)
JTH6E11BE	3/16"	6" (152.4 mm)	0.14 lb (0.06 kg)

Cat. No.	Hex Size	Blade Length	Weight
JTH6E12BE	7/32"	6" (152.4 mm)	0.17 lb (0.08 kg)
JTH6E13BE	1/4"	6" (152.4 mm)	0.27 lb (0.12 kg)
JTH6E14BE	5/16"	6" (152.4 mm)	0.35 lb (0.16 kg)
JTH6E15BE	3/8"	6" (152.4 mm)	0.45 lb (0.20 kg)
JTH6E17BE	1/2"	6" (152.4 mm)	0.70 lb (0.32 kg)

T-Handle Ball-End Hex-Key Set with Stand - SAE

Includes core Journeyman™ T-handle hex-key features plus:

- Metal stand for convenient hanging, storage on bench or wall
- Short blade-through-handle provides maximum tool versatility

Cat. No.	Set Contains	Weight																																	
JTH610EB	<table border="1"> <thead> <tr> <th>Cat. No.</th> <th>Hex Size</th> <th>Blade Length</th> </tr> </thead> <tbody> <tr> <td>JTH6E06BE</td> <td>3/32"</td> <td>6" (152.4 mm)</td> </tr> <tr> <td>JTH6E07BE</td> <td>7/64"</td> <td>6" (152.4 mm)</td> </tr> <tr> <td>JTH6E08BE</td> <td>1/8"</td> <td>6" (152.4 mm)</td> </tr> <tr> <td>JTH6E09BE</td> <td>9/64"</td> <td>6" (152.4 mm)</td> </tr> <tr> <td>JTH6E10BE</td> <td>5/32"</td> <td>6" (152.4 mm)</td> </tr> <tr> <td>JTH6E11BE</td> <td>3/16"</td> <td>6" (152.4 mm)</td> </tr> <tr> <td>JTH6E12BE</td> <td>7/32"</td> <td>6" (152.4 mm)</td> </tr> <tr> <td>JTH6E13BE</td> <td>1/4"</td> <td>6" (152.4 mm)</td> </tr> <tr> <td>JTH6E14BE</td> <td>5/16"</td> <td>6" (152.4 mm)</td> </tr> <tr> <td>JTH6E15BE</td> <td>3/8"</td> <td>6" (152.4 mm)</td> </tr> </tbody> </table>	Cat. No.	Hex Size	Blade Length	JTH6E06BE	3/32"	6" (152.4 mm)	JTH6E07BE	7/64"	6" (152.4 mm)	JTH6E08BE	1/8"	6" (152.4 mm)	JTH6E09BE	9/64"	6" (152.4 mm)	JTH6E10BE	5/32"	6" (152.4 mm)	JTH6E11BE	3/16"	6" (152.4 mm)	JTH6E12BE	7/32"	6" (152.4 mm)	JTH6E13BE	1/4"	6" (152.4 mm)	JTH6E14BE	5/16"	6" (152.4 mm)	JTH6E15BE	3/8"	6" (152.4 mm)	3.0 lb (1.4 kg)
Cat. No.	Hex Size	Blade Length																																	
JTH6E06BE	3/32"	6" (152.4 mm)																																	
JTH6E07BE	7/64"	6" (152.4 mm)																																	
JTH6E08BE	1/8"	6" (152.4 mm)																																	
JTH6E09BE	9/64"	6" (152.4 mm)																																	
JTH6E10BE	5/32"	6" (152.4 mm)																																	
JTH6E11BE	3/16"	6" (152.4 mm)																																	
JTH6E12BE	7/32"	6" (152.4 mm)																																	
JTH6E13BE	1/4"	6" (152.4 mm)																																	
JTH6E14BE	5/16"	6" (152.4 mm)																																	
JTH6E15BE	3/8"	6" (152.4 mm)																																	



JTH610EB





JOURNEYMAN™

T-Handle Hex-Keys

T-Handle Hex-Keys - SAE

Includes core Journeyman™ T-handle hex-key features plus:

- Short blade-through-handle provides maximum tool versatility



JTH6E15

Cat. No.	Hex Size	Blade Length	Weight
4" Length			
JTH4E06	3/32"	4" (101.6 mm)	0.05 oz (1.4 g)
JTH4E07	7/64"	4" (101.6 mm)	0.05 oz (1.4 g)
JTH4E08	1/8"	4" (101.6 mm)	0.05 oz (1.4 g)
JTH4E09	9/64"	4" (101.6 mm)	0.06 oz (1.7 g)
JTH4E10	5/32"	4" (101.6 mm)	0.11 oz (3.1 g)
JTH4E11	3/16"	4" (101.6 mm)	0.13 oz (3.7 g)
JTH4E12	7/32"	4" (101.6 mm)	0.14 oz (4.0 g)
JTH4E13	1/4"	4" (101.6 mm)	0.24 oz (6.8 g)
JTH4E14	5/16"	4" (101.6 mm)	0.30 oz (8.5 g)
JTH4E15	3/8"	4" (101.6 mm)	0.38 oz (10.8 g)
JTH4E17	1/2"	4" (101.6 mm)	0.59 oz (16.7 g)
6" Length			
JTH6E06	3/32"	6" (152.4 mm)	0.05 oz (1.4 g)
JTH6E07	7/64"	6" (152.4 mm)	0.05 oz (1.4 g)
JTH6E08	1/8"	6" (152.4 mm)	0.05 oz (1.4 g)
JTH6E09	9/64"	6" (152.4 mm)	0.06 oz (1.7 g)
JTH6E10	5/32"	6" (152.4 mm)	0.11 oz (3.1 g)
JTH6E11	3/16"	6" (152.4 mm)	0.13 oz (3.7 g)
JTH6E12	7/32"	6" (152.4 mm)	0.14 oz (4.0 g)
JTH6E13	1/4"	6" (152.4 mm)	0.24 oz (6.8 g)
JTH6E14	5/16"	6" (152.4 mm)	0.30 oz (8.5 g)
JTH6E15	3/8"	6" (152.4 mm)	0.38 oz (10.8 g)
JTH6E17	1/2"	6" (152.4 mm)	0.59 oz (16.7 g)
9" Length			
JTH9E06	3/32"	9" (228.6 mm)	0.05 oz (1.4 g)
JTH9E07	7/64"	9" (228.6 mm)	0.05 oz (1.4 g)
JTH9E08	1/8"	9" (228.6 mm)	0.06 oz (1.7 g)
JTH9E09	9/64"	9" (228.6 mm)	0.06 oz (1.7 g)
JTH9E10	5/32"	9" (228.6 mm)	0.11 oz (3.1 g)
JTH9E11	3/16"	9" (228.6 mm)	0.14 oz (4.0 g)
JTH9E12	7/32"	9" (228.6 mm)	0.18 oz (5.1 g)
JTH9E13	1/4"	9" (228.6 mm)	0.27 oz (7.7 g)
JTH9E14	5/16"	9" (228.6 mm)	0.35 oz (9.9 g)
JTH9E15	3/8"	9" (228.6 mm)	0.45 oz (12.8 g)
JTH9E17	1/2"	9" (228.6 mm)	0.70 oz (19.8 g)

T-Handle Hex-Key Sets with Stand - SAE

Includes core Journeyman™ T-handle hex-key features plus:

- Metal stand for convenient mounting on bench or wall
- Short blade-through-handle provides maximum tool versatility



JTH610E

Cat. No.	Set Contains	Weight
JTH410E	SAE T-Handle Hex Key Set, Stand, 4", 10-Piece	2.7 lb (1.2 kg)

Cat. No.	Hex Size	Blade Length
JTH4E06	3/32"	4" (101.6 mm)
JTH4E07	7/64"	4" (101.6 mm)
JTH4E08	1/8"	4" (101.6 mm)
JTH4E09	9/64"	4" (101.6 mm)
JTH4E10	5/32"	4" (101.6 mm)
JTH4E11	3/16"	4" (101.6 mm)
JTH4E12	7/32"	4" (101.6 mm)
JTH4E13	1/4"	4" (101.6 mm)
JTH4E14	5/16"	4" (101.6 mm)
JTH4E15	3/8"	4" (101.6 mm)

Cat. No.	Set Contains	Weight
JTH610E	T-Handle Set with Stand, SAE, 6" Blade 10 Pc	2.7 lb (1.2 kg)

Cat. No.	Hex Size	Blade Length
JTH6E06	3/32"	6" (152.4 mm)
JTH6E07	7/64"	6" (152.4 mm)
JTH6E08	1/8"	6" (152.4 mm)
JTH6E09	9/64"	6" (152.4 mm)
JTH6E10	5/32"	6" (152.4 mm)
JTH6E11	3/16"	6" (152.4 mm)
JTH6E12	7/32"	6" (152.4 mm)
JTH6E13	1/4"	6" (152.4 mm)
JTH6E14	5/16"	6" (152.4 mm)
JTH6E15	3/8"	6" (152.4 mm)

Cat. No.	Set Contains	Weight
JTH910E	T-Handle Set with Stand, SAE, 9" Blade 10 Pc	3.6 lb (1.6 kg)

Cat. No.	Hex Size	Blade Length
JTH9E06	3/32"	9" (228.6 mm)
JTH9E07	7/64"	9" (228.6 mm)
JTH9E08	1/8"	9" (228.6 mm)
JTH9E09	9/64"	9" (228.6 mm)
JTH9E10	5/32"	9" (228.6 mm)
JTH9E11	3/16"	9" (228.6 mm)
JTH9E12	7/32"	9" (228.6 mm)
JTH9E13	1/4"	9" (228.6 mm)
JTH9E14	5/16"	9" (228.6 mm)
JTH9E15	3/8"	9" (228.6 mm)

See page 297 for additional information on warnings.

