


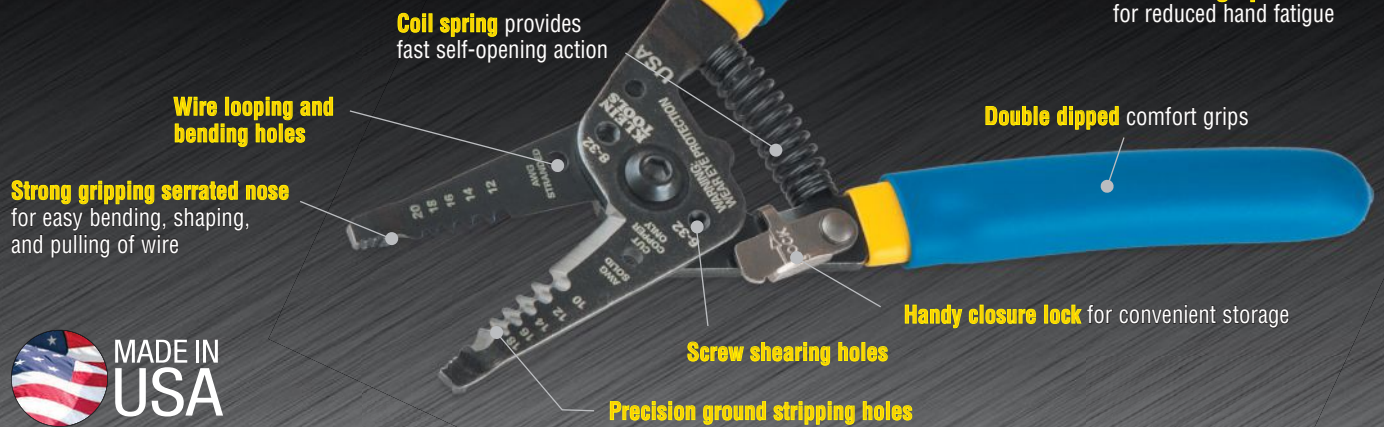

Wire Strippers/Cutters



Klein-Kurve™ Wire Strippers/Cutters

Includes core features plus:

- Easy-to-read markings
- Precision shear-type blades
- Narrow nose fits into tight places
- Glow in the dark grips to easily locate your tool in dark or low lit areas (Cat. No. 11054GLW)



11054

Cat. No.	Strips and Cuts	Screw Shearing	Overall Length	Handle Color	Weight
11053	6-12 AWG Stranded (16.0-4.0 mm ²)	6-32 and 8-32	7.125" (181 mm)	Blue/Red	0.34 lb (0.15 kg)
11054	8-16 AWG Solid (10.0-1.5 mm ²); 10-18 AWG Stranded (6.0-1.0 mm ²)	6-32 and 8-32	7.125" (181 mm)	Blue/White	0.34 lb (0.15 kg)
11054GLW	8-16 AWG Solid (10.0-1.5 mm ²); 10-18 AWG Stranded (6.0-1.0 mm ²)	6-32 and 8-32	7.125" (181 mm)	Glow in the Dark	0.34 lb (0.15 kg)
11055	10-18 AWG Solid (6.0-1.0 mm ²); 12-20 AWG Stranded (4.0-0.50 mm ²)	6-32 and 8-32	7.125" (181 mm)	Blue/Yellow	0.34 lb (0.15 kg)
11057	20-30 AWG Solid (0.50-0.05 mm ²); 22-32 AWG Stranded (0.35-0.03 mm ²)	6-32 and 8-32	7.125" (181 mm)	Blue/Red	0.32 lb (0.15 kg)
K1412	NM-B Cable 12/2 and 14/2; 12-14 AWG Solid (4.0-2.5 mm ²); 14-16 AWG Stranded (2.5-1.5 mm ²)	6-32 and 8-32	7.75" (196.9 mm)	Yellow/White	0.41 lb (0.19 kg)
K1412CAN	NMD-90 Cable 12/2 and 14/2; 12-14 AWG Solid (4.0-2.5 mm ²); 14-16 AWG Stranded (2.5-1.5 mm ²)	6-32 and 8-32	7.75" (196.9 mm)	Yellow/White	0.41 lb (0.19 kg)

Klein-Kurve™ Wire Strippers/Crimpers/Cutters

Includes core features plus:

- Crimps insulated and non-insulated connectors
- Tip designed to grab, pull and bend the smallest of wires
- Reinforced head reduces flex
- Optimized for ideal leverage when stripping and crimping
- Precision shear-type cutting blades for easier cutting
- Do no use to cut steel wire



1019

Cat. No.	Strips and Cuts	Screw Shearing	Crimping Capacity	Overall Length	Handle Color	Weight
1009	10-20 AWG Solid (6.0-0.50 mm ²); 12-22 AWG Stranded (4.0-0.35 mm ²)	6-32 and 8-32	10-22 AWG (6.0-0.35 mm ²)	7.75" (196.9 mm)	Gray/Yellow	0.34 lb (0.15 kg)
NEW 1019	10-26 AWG Solid (6.0-0.14 mm ²); 12-28 AWG Stranded (4.0-0.10 mm ²)	6-32 and 8-32	10-22 AWG (6.0-0.35 mm ²) Insulated and Non-insulated Terminals; B-Connectors; Scotchlok® IDC Connectors	7.75" (196.9 mm)	Gray/Red	0.34 lb (0.15 kg)

See page 297 for additional information on warnings.



Wire Strippers/ Cutters

Textured handles provide a firm, comfortable grip

Spring loaded for self-opening action

Black-oxide finish resists corrosion

Easy-to-read wire gauge markings on both sides for stripping in either direction

Wire looping and bending holes

Precision-ground stripping holes for easy removal of insulation



Wire Strippers/Cutters

Includes core features plus:

- Narrow nose fits into tight places
- Cat. Nos. 1011 and 1011M strip six standard wire sizes without nicking wire
- Cat. No. 11048 strips two wires in a single motion
- Do not use for cutting steel wire or screws



DUAL-WIRE STRIPPER
11048



11045

Cat. No.	Strips and Cuts	Overall Length	Handle Color	Weight
11045	10-18 AWG Solid (6.0-1.0 mm ²)	6.25" (158.8 mm)	Yellow	0.27 lb (0.12 kg)
11046	16-26 AWG Stranded (1.5-0.14 mm ²)	6.25" (158.8 mm)	Red	0.27 lb (0.12 kg)
11047	22-30 AWG Solid (0.35-0.05 mm ²)	6.25" (158.8 mm)	Yellow	0.27 lb (0.12 kg)
11049	8-16 AWG Stranded (6 mm ² -1.0 mm ²)	6.25" (158.8 mm)	Red	0.27 lb (0.12 kg)
11048	10, 12, 14 AWG Solid (4.0 mm ² , 2.5 mm ² , 1.5 mm ²)	6.25" (158.8 mm)	Yellow	0.27 lb (0.12 kg)
1011	10-20 AWG Solid (6.0-0.50 mm ²); 12-22 AWG Stranded (4.0-0.35 mm ²)	6.125" (155.6 mm)	Blue	0.23 lb (0.10 kg)
1011M	0.15 to 4.0 mm ² Stranded Wire	6.125" (155.6 mm)	Blue	0.23 lb (0.10 kg)

Adjustable Wire Stripper/Cutters

- Cuts and strips solid and stranded wire
- Handy, light, compact tools for stripping insulation
- Adjustable dial for wire size adjustment prevents nicked wire (Cat. No. 74007)
- Adjustable slide stop with set screw for repeated stripping work (Cat. No. 1003, 1004)
- Convenient hole for looping or bending wire (Cat. No. 1003, 1004)
- Black-oxide finish with plastic-dipped handles



74007

Cat. No.	Strips and Cuts	Hold-Open Spring	Overall Length	Handle Color	Weight
74007	12-24 AWG Solid and Stranded (4.0-0.25 mm ²)	Yes	5.125" (130.2 mm)	Yellow	0.15 lb (0.07 kg)
1004	12-26 AWG Solid and Stranded (4.0- 0.14 mm ²)	Yes	5" (127.0 mm)	Yellow	0.18 lb (0.08 kg)
1003	12-26 AWG Solid and Stranded (4.0- 0.14 mm ²)	No	5" (127.0 mm)	Yellow	0.14 lb (0.06 kg)

