

Drivers

10-in-1 Folding Screwdriver/Nut Driver

10-FOLD™

- Conveniently folds up for easy storage or to fit into your pocket
- Each driver arm contains for interchangeable bit styles and two nut drivers
- Unfold each driver arm up to a full 180° for straight on driving power, or at 90° for extra leverage on stubborn fasteners
- The quick release button easily unlocks a fully extended driver arm



32534



Cat. No.	Nut Driver Sizes	Phillips Bits	Slotted Bits	Square Bits	Other Bits	Handle Color	Weight
32534	5/16", 1/4"	#1, #2	1/4" (6.4 mm), 3/16" (4.8 mm)	#1, #2	Schrader® Valve Insertion/Core Removal	Blue	0.37 lb (0.17 kg)

Schrader® is a registered trademark of Schrader-Bridgeport International, Inc.

11-in-1 Screwdriver/Nut Driver with Schrader® Valve Removal/Installation Bit

- Great for HVAC and other industrial applications
- Includes unique style bit for installation/removal of common TR-4 Schrader® valves and aggressive thread extractor tip for backing out broken cores



32527



Cat. No.	Nut Driver Sizes	Phillips Bits	Slotted Bits	Square Bits	Other Bits	Shank Length	Handle Color	Overall Length	Weight
32527	3/8", 5/16", 1/4"	#1, #2	1/4" (6.4 mm), 3/16" (4.8 mm)	#1, #2	Schrader® Valve Insertion/Core Removal	3" (76.2 mm)	Yellow/Black	7.75" (196.9 mm)	0.44 lb (0.20 kg)


Schrader® is a registered trademark of Schrader International, Inc.

8-in-1 HVAC Slide Driver™ Screwdriver/Nut Driver

- Unique, patented head slides back and forth to switch from 1/4" to 5/16" magnetic hex-head screwdriver
- Thumb nut locks tip setting
- Features a specialty bit for installation/removal of common TR-4 Schrader® valves
- Includes 1/4" and 3/8" hollow nut drivers, as well as #2 Phillips, 1/8" (3 mm) and 1/4" (6 mm) slotted screwdriver tips
- Great for HVAC applications including thermostat installation and control work
- U.S. patent 7,654,175 B2



32596

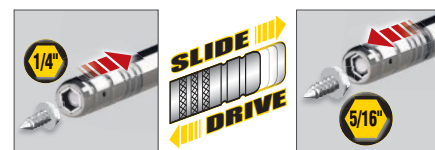

Cat. No.	Overall Length	Handle Color	Shank Length	Nut Driver Sizes	Phillips Bits	Slotted Bits	Other Bits	Weight
32596	7.5" (190.5 mm)	Yellow/Black	3.25" (82.6 mm)	1/4" Magnetic, 5/16" Magnetic, 1/4", 3/8"	#2	1/8" (3.2 mm), 1/4" (6.4 mm)	Schrader® Valve Core Removal	0.50 lb (0.2 kg)

Schrader® is a registered trademark of Schrader-Bridgeport International, Inc.

Magnetic Hex Drivers

- For driving sheet metal screws
- Strong rare earth magnets for maximum holding
- 1/4" (6.4 mm) hex shank with quick release groove



86602

Cat. No.	Description	Overall Length	Weight
86600	Magnetic Hex Drivers, 1/4", 3-Pack	1.75" (44.5 mm)	0.12 lb (0.05 kg)
86601	5/16" Magnetic Hex Drivers, 3-Pack	1.75" (44.5 mm)	0.14 lb (0.06 kg)
86602	3/8" Magnetic Hex Drivers, 3-Pack	1.75" (44.5 mm)	0.16 lb (0.07 kg)
8660010	1/4" Magnetic Hex Drivers, 10-pack	1.75" (44.5 mm)	0.43 lb (0.20 kg)
8660110	Magnetic Hex Drivers, 5/16", 10-Pack	1.75" (44.5 mm)	0.49 lb (0.22 kg)
8660210	3/8" Magnetic Hex Drivers, 10-pack	1.75" (44.5 mm)	0.57 lb (0.26 kg)

