

Pocket Knives

Silver Aluminum Lockback Knives


- Lockback secures blade in open position
- Reversible thumb stud for easy one-hand opening
- Cat. Nos. 44001, 44006, 44007 include removable pocket clip



44000



Coping Blade

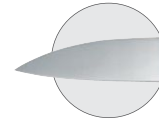

Drop Point Blade



Hawkbill Blade

Cat. No.	Blade Type	Blade Length	Blade Material	Handle Material	Length Closed	Overall Length	Weight
44000	Drop Point	2.25" (57.2 mm)	AUS 8 Stainless Steel	Anodized Aluminum	3.125" (79.4 mm)	5.5" (139.7 mm)	1.5 oz (43 g)
44001	Drop Point	2.5" (63.5 mm)	AUS 8 Stainless Steel	Anodized Aluminum	3.5" (88.9 mm)	6.125" (155.6 mm)	2.6 oz (74 g)
44006	Hawkbill	2.625" (66.7 mm)	AUS 8 Stainless Steel	Anodized Aluminum	3.875" (98.4 mm)	6.625" (168.3 mm)	1.3 oz (37 g)
44007	Coping	2.5" (63.5 mm)	AUS 8 Stainless Steel	Anodized Aluminum	3.5" (88.9 mm)	6.125" (155.6 mm)	1.5 oz (43 g)

Black Aluminum Lockback Knives


- Lockback secures blade in open position
- Black stainless-steel blade and black anodized-aluminum handle
- Reversible thumb stud for easy one-hand opening
- Cat. Nos. 44001-BLK and 44052-BLK include removable pocket clip



44000-BLK



Drop Point Blade

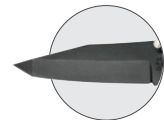

Tanto Blade

Cat. No.	Blade Type	Blade Length	Blade Material	Handle Material	Length Closed	Overall Length	Weight
44000-BLK	Drop Point	2.25" (57.2 mm)	AUS 8 Stainless Steel	Anodized Aluminum	3.125" (79.4 mm)	5.5" (139.7 mm)	1.1 oz (31 g)
44001-BLK	Drop Point	2.5" (63.5 mm)	AUS 8 Stainless Steel	Anodized Aluminum	3.5" (88.9 mm)	6.125" (155.6 mm)	1.5 oz (43 g)
44052BLK	Tanto	2.563" (65.1 mm)	AUS 8 Stainless-Steel	Anodized Aluminum	3.5" (88.9 mm)	6.125" (155.6 mm)	4.8 oz (136 g)

Lockback Knives

 
- Lockback secures blade in open position
- Impact-resistant nylon resin handle with rubber insert
- Reversible thumb stud for easy one-hand opening
- Cat. Nos. 44005C and 44005RC include pocket clip



44002



44005RC



Drop Point Blade



Sheepsfoot Blade



Hawkbill Blade




Hawkbill —
Rounded Tip Blade



POCKET CLIP
AVAILABLE ON
44005C
44005RC

Cat. No.	Blade Type	Blade Length	Blade Material	Handle Material	Length Closed	Overall Length	Weight
44002	Drop Point	2.375" (60.3 mm)	AUS 8 Stainless-Steel	Nylon Resin	3.5" (88.9 mm)	6" (152.4 mm)	1.5 oz (43 g)
44003	Drop Point	2.75" (69.9 mm)	AUS 8 Stainless Steel	Nylon Resin	4.125" (104.8 mm)	7" (177.8 mm)	2.6 oz (74 g)
44004	Sheepsfoot	2.5" (63.5 mm)	AUS 8 Stainless Steel	Nylon Resin	3.5" (88.9 mm)	6" (152.4 mm)	1.5 oz (43 g)
44005	Hawkbill	2.625" (66.7 mm)	AUS 8 Stainless Steel	Nylon Resin	4.203" (106.8 mm)	6.75" (171.5 mm)	2.6 oz (74 g)
44005R	Hawkbill - Rounded Tip	2.625" (66.7 mm)	AUS 8 Stainless Steel	Nylon Resin	4.203" (106.8 mm)	6.75" (171.5 mm)	2.6 oz (74 g)
44005RC	Hawkbill - Rounded Tip	2.625" (66.7 mm)	AUS 8 Stainless Steel	Nylon Resin	4.203" (106.8 mm)	6.75" (171.5 mm)	2.6 oz (74 g)
44005C	Hawkbill with Clip	2.625" (66.7 mm)	AUS 8 Stainless Steel	Nylon Resin	4.203" (106.8 mm)	6.75" (171.5 mm)	2.2 oz (62.4 g)

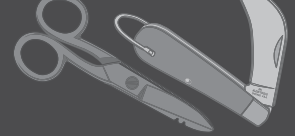

Pocket Knives

Compact Pocket Knife

- Lockback secures blade in open position
- Corrosion resistant black aluminum handle
- Reversible thumb stud for easy one-hand opening
- Lanyard hole allows knife to be tethered
- Low-carry pocket clip



44142

Cat. No.	Blade Type	Blade Length	Blade Material	Handle Material	Length Closed	Overall Length	Weight
44142	Drop Point	2.875" (73 mm)	440A Stainless Steel	Aluminum	3.8" (96.5 mm)	6.75" (171.5 mm)	0.14 oz (4.0 g)

Stainless Steel Compact Knives

- Lockback secures blade in open position
- High-grade stainless steel handle with rosewood inlay
- Lightweight and compact



44032

Cat. No.	Blade Type	Blade Length	Blade Material	Handle Material	Length Closed	Overall Length	Weight
44032	Drop Point	1.625" (41.3 mm)	Stainless Steel	Stainless Steel	2.406" (61.1 mm)	4.25" (108 mm)	1.0 oz (28 g)
44033	Drop Point	2.25" (57.2 mm)	Stainless Steel	Stainless Steel	3" (76.2 mm)	5.25" (133.4 mm)	1.8 oz (51 g)
44034	Drop Point	3" (76.2 mm)	Stainless Steel	Stainless Steel	4" (101.6 mm)	7" (177.8 mm)	4.0 oz (113 g)

Wood Grain Handle Pocket Knives

- Liner lock secures blade in open position
- Durable plastic handle with faux wood grain
- Shackle allows knife to be tethered



1550-4



1550-11



1550-44

Cat. No.	Blade Type	Blade Length	Blade Material	Handle Material	Length Closed	Overall Length	Weight
1550-4	Hawkbill	2.625" (66.7 mm)	Carbon Steel	Plastic	4.141" (105.2 mm)	6.125" (155.6 mm)	4.0 oz (113 g)
1550-11	Coping	2.25" (57.2 mm)	Carbon Steel	Plastic	3.25" (82.6 mm)	5.5" (139.7 mm)	1.5 oz (43 g)
1550-44	Hawkbill	2.625" (66.7 mm)	Stainless Steel	Plastic	3.5" (88.9 mm)	6.125" (155.6 mm)	4.0 oz (113 g)

Slitting Pocket Knife

- Liner lock secures blade in open position
- Durable plastic handle
- Shackle allows knife to be tethered



1550-24

Cat. No.	Blade Type	Blade Length	Blade Material	Handle Material	Length Closed	Overall Length	Weight
1550-24	Hawkbill	2.75" (69.9 mm)	Stainless Steel	Plastic	4.5" (114.3 mm)	6.75" (171.5 mm)	2.6 oz (74 g)

See page 297 for additional information on warnings.



WARNING: Blades are intended for cutting only, and should be handled and disposed of with care. Bending the blade can cause it to break, possibly resulting in bodily injury. **Check local laws on legality of selling or possessing these knives.**