



A-Shape LED

11A19/LED/827/FR/P/ND 4/6FB

Philips A-shape Dimmable LED lamps are the smart LED alternative to standard incandescents. The unique lamp design provides omi-directional light with excellent dimming performance.


Product data

General Information	
Cap-Base	E26 [Single Contact Medium Screw]
EU RoHS compliant	Yes
Nominal Lifetime (Nom)	11000 h
Switching Cycle	50000X
Technical Type	11-60W
Light Technical	
Color Code	827 [CCT of 2700K]
Beam Angle (Nom)	150 °
Luminous Flux (Nom)	800 lm
Color Designation	Warm White (WW)
Correlated Color Temperature (Nom)	2700 K
Luminous Efficacy (rated) (Nom)	72.00 lm/W
Color Consistency	ANSI
Color Rendering Index (Nom)	80
LLMF At End Of Nominal Lifetime (Nom)	70 %
Operating and Electrical	
Input Frequency	60 Hz
Power (Rated) (Nom)	11 W
Lamp Current (Nom)	165 mA
Wattage Equivalent	60 W
Starting Time (Nom)	0.5 s

Warm Up Time to 60% Light (Nom)	0.5 s
Power Factor (Nom)	0.5
Voltage (Nom)	120 V
Temperature	
T-Case Maximum (Nom)	85 °C
Controls and Dimming	
Dimmable	No
Mechanical and Housing	
Bulb Finish	Frosted
Product Data	
Order product name	11A19/LED/827/FR/P/ND 4/6FB
EAN/UPC - Product	50046677455595
Order code	455592
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	4
Material Nr. (12NC)	929001957675
Net Weight (Piece)	0.046 kg

A-Shape LED


Dimensional drawing

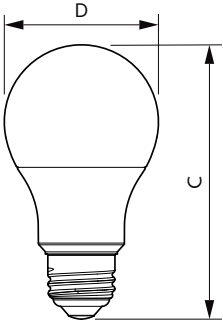


Bulb A60 120V 10-60W 800lm 2700K E26 ND

Product	D	C
11A19/LED/827/FR/P/ND 4/6FB	60 mm	110 mm


Photometric data

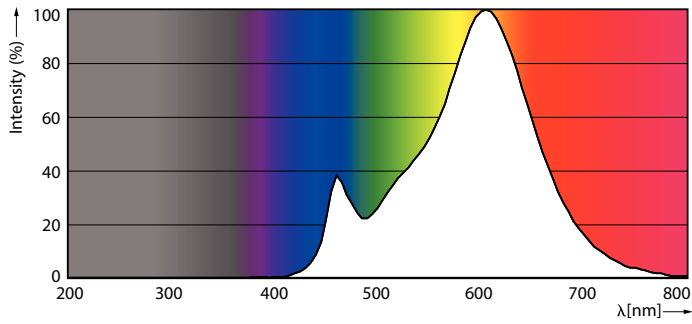

LedBulb A19 E26 11W

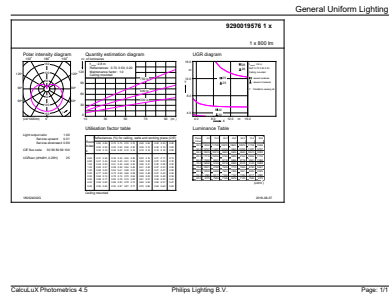



LedBulb A19 E26 11W

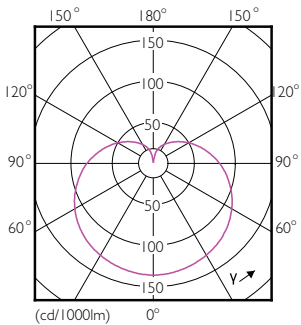

LedBulb A19 E26

A-Shape LED

Lifetime

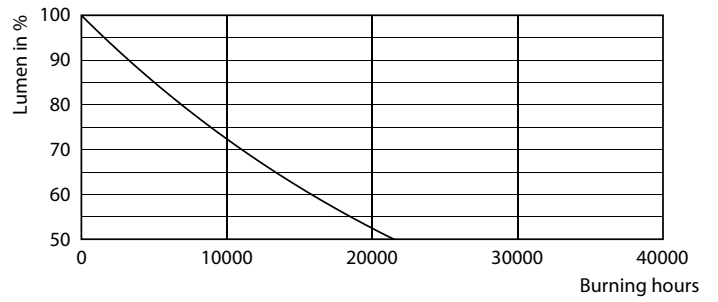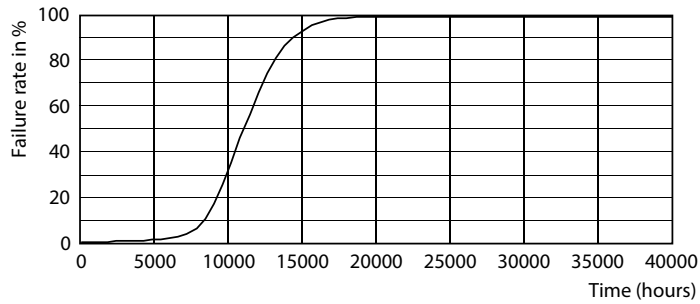

LedBulb A19 E26

LedBulb A19 E26

