



Meter Accessories

K-Type Temperature Pipe Clamp

- Features a temperature sensor that clamps around pipes ranging from 1/4" to 1-3/8" diameter (up to 35 mm)
- A flexible 40" (1016 mm) lead
- Works with any clamp or multimeter that measures temperature
- Includes banana plug adapter



69140

Cat. No.	Overall Length	Overall Height	Overall Width	Temperature Range	Weight
69140	5.25" (133.4 mm)	0.75" (19.1 mm)	3.00" (76.2 mm)	-4 to 212°F (-20 to 100°C)	3.13 lb (1420.0 g)

K-Type Thermocouple Probe

- Pointed tip easily pierces fiberglass ductwork for HVAC measurements
- A coiled 5 ft (1.5 m) lead
- Wide measurement range: -58 to 1112°F
- Works with any clamp or multimeter that measures temperature
- Includes banana plug adapter



69144


Cat. No.	Overall Length	Overall Height	Overall Width	Temperature Range	Weight
69144	12.50" (317.5 mm)	0.50" (12.7 mm)	0.50" (12.7 mm)	-58 to 1112°F (-50 to 600°C)	3.19 lb (1450.0 g)

Replacement K-Type Thermocouples

- UL® listed replacement thermocouple with banana plug connector 0° to 250°C (Cat. No. 69028)
- Measurement range of 0° to 250°C (Cat. No. 69435)
- Temperature measurement range of 0 to 480°C and includes banana plug adapter (Cat. No. 69142)
- Allows Type K temperature thermocouples to be used with a meter with banana plug ports (Cat. No. 69146)



69028

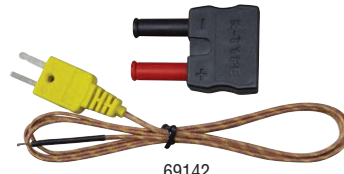

69142



69146



69435

Cat. No.	Type	For Use With	Weight
69028	K-Type Banana Thermocouple	CL200, CL210, CL310, CL312, CL330, CL700, CL1300, CL2300, MM200, MM400, MM600, MM700, MM1000, MM1300, MM2000, MM2300, MM6000	0.70 oz (19.8 g)
NEW 69435	K-Type Thermocouple	Any Clamp or Digital Multimeter that Measures Temperature	0.40 oz (11.0 g)
69142	K-Type Thermocouple, High Temperature with Adapter	Any Clamp or Digital Multimeter that Measures Temperature	0.40 oz (11.0 g)
69146	K-Type Banana Plug Adapter	Any Clamp or Digital Multimeter that Measures Temperature	0.40 oz (11.0 g)

Replacement Test Lead Set

- Safety Rating: Category IV 600V and CAT III 1000V
- Screw-on alligator clips attach to wires and other conductors
- Intended for use as replacement test leads for meters that have standard, banana-type input jacks
- Leads are 41" (1,041 mm) long
- Replacement test-lead set for all DMM, Clamp Meters, and testers
- The leads perform accurately with Klein Tools' meters and other manufacturer's meters



69410

Cat. No.	Weight
69410	0.20 lb (90.0 g)

See page 297 for additional information on warnings.



Meter Accessories

Line Splitter 10x

- Allows the measuring of current draw up to 15A without splitting the load's power cord
- For use with all Klein Tools clamp meters and other manufacture clamp meters
- Can be used to perform voltage checks with standard multimeter probes
- Provides 10X measurement mode
- For North American-style outlets only

⚠WARNINGS:

- Do NOT use with loads greater than 15A.
- Risk of electric shock and burn. Contact with live circuits could result in death or serious injury.
- Do not use if line splitter appears damaged. If in doubt, replace line splitter.
- Do NOT use line splitter if wet. For indoors use only.



69409

Cat. No.	Overall Length	Overall Height	Overall Width	Weight
69409	4.67" (118.6 mm)	4.67" (118.6 mm)	2.28" (57.9 mm)	0.24 lb (110.0 g)

Magnetic Hangers

- Durable nylon weave resists wear and tear
- Constructed with powerful rare earth magnets
- Has a secure loop & hook
- Hanger allows the user to safely work hands-free
- Cat. No. 69190 clips securely into back of rubber boot

Cat. No.	Application	For Use With	Weight
69417	Electrician's Multimeters and Select Clamps	MM300, MM400, MM600, MM700, CL450, CL600, CL700, CL800, CL900	1.10 oz (31.0 g)
69190	Electrician's Previous Generation Multimeters	MM1000, MM1300, MM2000, MM2300	1.10 oz (31.0 g)



Electrical Testers

Continuity Tester



69133

- Quickly reveals shorts or broken circuits in all types of electrical devices and controls
- Tests for continuity of circuit with power off
- Bulb in handle glows when circuit is complete (bulb included)
- Pointed 3-3/4" (95 mm) probe gets right to the problem
- Deluxe 4" (102 mm) long handle with removable nylon cap holds replaceable bulb and battery
- 36" (915 mm) test lead with alligator clip
- Uses one AAA battery (not included)
- Proudly built in U.S.A. with global components

Cat. No.	Overall Length	Weight
69133	43.75" (111.1 cm)	0.21 oz (6.0 g)
Replacement Part		
69131	Replacement Bulb for Continuity Tester Cat. No. 69133	0.05 oz (1.4 g)

Low-Voltage Tester



69127

- Device for checking live 6-24V, AC or DC circuits
- Tests for shorts in automotive and truck electrical systems, motor field coils, radio and low-voltage circuits, ground circuits of all lamps, wiring, fuses, etc.
- Bulb in handle glows when circuit is complete (bulb included)
- Pointed 3-3/4" (95 mm) probe makes checking easier
- Deluxe 3-1/2" (89 mm) long handle with nylon top holds replaceable bulb
- 36" (915 mm) test lead with alligator clip
- Proudly built in U.S.A. with global components

Cat. No.	Overall Length	Weight
69127	43.25" (109.9 cm)	0.21 oz (6.0 g)