




High-Leverage Diagonal-Cutting Pliers

Angled Head Diagonal Cutting Pliers

Includes core high-leverage diagonal-cutting features plus:

- Angled head design for easy work in confined spaces
- Glow in the dark grips are easily spotted in dark or low lit areas (Cat. No. D248-8GLW)

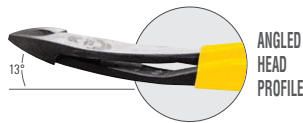

D2000-49



Plastic-Dipped



JOURNEYMAN™
Dual-Material


Refer to the insulated section for insulated pliers.

Cat. No.	Overall Length	Jaw Length	Jaw Width	Jaw Thickness	Cutting Knives	Handle Color	Handle Finish	Weight
D238-8	8.063" (204.8 mm)	0.813" (20.7 mm)	1.188" (30.2 mm)	13/16" (20.6 mm)	Semi-Flush	Red	Plastic-Dipped	0.59 lb (0.27 kg)
D248-8	8.063" (204.8 mm)	0.813" (20.7 mm)	1.188" (30.2 mm)	13/16" (20.6 mm)	Standard	Red	Plastic-Dipped	0.60 lb (0.27 kg)
D248-8-GLW	8.063" (204.8 mm)	0.813" (20.7 mm)	1.188" (30.2 mm)	13/16" (20.6 mm)	Standard	Glow in the Dark	Plastic-Dipped	0.60 lb (0.27 kg)
J248-8	8.125" (206.4 mm)	0.813" (20.7 mm)	1.188" (30.2 mm)	13/16" (20.6 mm)	Standard	Red/Black	Journeyman	0.61 lb (0.28 kg)
Pliers with heavy-duty cutting knives designed to cut ACSR, screws, nails and most hardened wire								
D2000-48	8" (203.2 mm)	0.813" (20.7 mm)	1.188" (30.2 mm)	13/16" (20.6 mm)	Standard	Blue	Plastic Dipped	0.60 lb (0.27 kg)
D2000-49	9" (228.6 mm)	0.813" (20.7 mm)	1.25" (31.8 mm)	13/16" (20.6 mm)	Standard	Yellow	Plastic Dipped	0.64 lb (0.29 kg)
J2000-48	8.125" (206.4 mm)	0.813" (20.7 mm)	1.188" (30.2 mm)	13/16" (20.6 mm)	Standard	Light Blue/Black	Journeyman	0.61 lb (0.28 kg)

Ironworker's Diagonal-Cutting Pliers

Includes core high-leverage diagonal-cutting features plus:

- Angled head design for easy working in confined spaces
- Hooked handle for improved grip

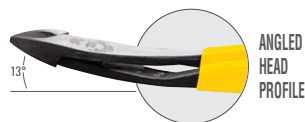

D248-9STT

Cat. No.	Overall Length	Jaw Length	Jaw Width	Jaw Thickness	Cutting Knives	Handle Color	Handle Finish	Weight
D248-9ST	9.188" (233.4 mm)	0.813" (20.7 mm)	1.188" (30.2 mm)	13/16" (20.6 mm)	Standard	Red	Plastic Dipped	0.68 lb (0.31 kg)
D248-9STT	9" (228.6 mm)	1" (25.4 mm)	1.25" (31.8 mm)	1" (25.4 mm)	Standard	Red	Plastic Dipped	0.68 lb (0.31 kg)

Diagonal-Cutting Pliers with Stripping Holes

Includes core high-leverage diagonal-cutting features plus:

- Cleanly strips 12-14 AWG solid wire



D243-8

Cat. No.	Overall Length	Jaw Length	Jaw Width	Jaw Thickness	Cutting Knives	Handle Color	Handle Finish	Weight
D243-8	8.063" (204.8 mm)	0.813" (20.7 mm)	1.188" (30.2 mm)	13/16" (20.6 mm)	Standard	Red	Plastic-Dipped	0.60 lb (0.27 kg)

See page 297 for additional information on warnings.



Diagonal-Cutting Pliers

Heavy-Duty Diagonal-Cutting Pliers - Tapered Nose

- Heavier design for all-purpose use
- Tapered nose for easy working in confined areas



D220-7

Cat. No.	Overall Length	Jaw Length	Jaw Width	Jaw Thickness	Cutting Knives	Handle Color	Handle Finish	Weight
D220-7	7.688" (195.3 mm)	1" (25.4 mm)	0.969" (24.6 mm)	1" (25.4 mm)	Standard	Red	Plastic-Dipped	0.54 lb (0.24 kg)
D252-6	6.125" (155.6 mm)	0.813" (20.7 mm)	0.75" (19.1 mm)	13/16" (20.6 mm)	Standard	Red	Plastic-Dipped	0.38 lb (0.17 kg)
Bell System Type "W" Notches - Slits insulation cleanly								
D252-6SW	6.125" (155.6 mm)	0.813" (20.7 mm)	0.75" (19.1 mm)	13/16" (20.6 mm)	Standard	Red	Plastic-Dipped	0.33 lb (0.15 kg)

Standard Diagonal-Cutting Pliers

- Tapered nose for easy working in confined areas and close tip cutting
- Trims plastic or printed circuit boards (Cat. D210-6C)
- Cleanly strips 16 AWG solid wire (Cat. No. D240-6)



D245-5

Cat. No.	Overall Length	Jaw Length	Jaw Width	Jaw Thickness	Cutting Knives	Handle Color	Handle Finish	Weight
D202-6	6.125" (155.6 mm)	0.813" (20.7 mm)	0.688" (17.5 mm)	13/16" (20.6 mm)	Standard	Red	Plastic-Dipped	0.29 lb (0.13 kg)
D202-6C	6.125" (155.6 mm)	0.813" (20.7 mm)	0.688" (17.5 mm)	13/16" (20.6 mm)	Standard	Red	Plastic-Dipped	0.31 lb (0.14 kg)
D245-5	5.063" (128.6 mm)	0.688" (17.5 mm)	0.563" (14.3 mm)	11/16" (17.5 mm)	Standard	Red	Plastic-Dipped	0.20 lb (0.09 kg)
D210-6C	6.125" (155.6 mm)	0.813" (20.7 mm)	0.688" (17.5 mm)	13/16" (20.6 mm)	Semi-Flush	Red	Plastic-Dipped	0.29 lb (0.13 kg)
D240-6	6.125" (155.6 mm)	0.813" (20.7 mm)	0.688" (17.5 mm)	13/16" (20.6 mm)	Standard	Red	Plastic-Dipped	0.30 lb (0.14 kg)
Bell-System Type "W" & "V" Notches - For quick insulation slitting								
D528V	5.813" (147.7 mm)	0.813" (20.7 mm)	0.563" (14.3 mm)	13/16" (20.6 mm)	Standard	Red	Plastic-Dipped	0.20 lb (0.09 kg)
Telephone Type D-6 "V" Notches - For quick insulation slitting and includes .030" and .045" stripping holes								
72192	6.125" (155.6 mm)	0.813" (20.7 mm)	0.75" (19.1 mm)	13/16" (20.6 mm)	Standard	Red	Plastic-Dipped	0.33 lb (0.15 kg)

Electronics Diagonal-Cutting Pliers

Midget Diagonal-Cutting Pliers

- Sharp pointed nose for precise tip cutting
- Tapered nose for easy working in confined areas and close tip cutting (Cat No. D295-4C, D257-4 & D257-4C)
- Spring-loaded for self-opening action (Not available on Cat. No. D257-4)
- Narrow jaw and hinge for delicate work in tight areas (Cat. No. D259-4C & D244-5C)
- Miniature jaw for close-quarter work with maximum visibility (Cat. No. D295-4C)



D257-4C



Tapered Nose Standard Jaw Tapered Nose Mini Jaw Pointed Nose Standard Jaw Pointed Nose Narrow Jaw Pointed Nose Extra Narrow Jaw

Cat. No.	Overall Length	Jaw Length	Jaw Width	Jaw Thickness	Cutting Knives	Handle Color	Handle Finish	Weight
D209-4C	4.25" (108 mm)	0.5" (12.7 mm)	0.438" (11.1 mm)	1/2" (12.7 mm)	Semi-Flush	Light Blue	Plastic-Dipped	0.13 lb (0.06 kg)
D209-5C	5.063" (128.6 mm)	0.688" (17.5 mm)	0.563" (14.3 mm)	11/16" (17.5 mm)	Semi-Flush	Light Blue	Plastic-Dipped	0.19 lb (0.09 kg)
D244-5C	5.063" (128.6 mm)	0.688" (17.5 mm)	0.5" (12.7 mm)	11/16" (17.5 mm)	Flush	Light Blue	Plastic-Dipped	0.18 lb (0.08 kg)
D259-4C	4.25" (108 mm)	0.5" (12.7 mm)	0.406" (10.3 mm)	1/2" (12.7 mm)	Flush	Light Blue	Plastic-Dipped	0.12 lb (0.05 kg)
D257-4	4.25" (108 mm)	0.5" (12.7 mm)	0.438" (11.1 mm)	1/2" (12.7 mm)	Semi-Flush	Light Blue	Plastic-Dipped	0.12 lb (0.05 kg)
D257-4C	4.25" (108 mm)	0.5" (12.7 mm)	0.438" (11.1 mm)	1/2" (12.7 mm)	Semi-Flush	Light Blue	Plastic-Dipped	0.12 lb (0.05 kg)
D295-4C	4.25" (108 mm)	0.5" (12.7 mm)	0.375" (9.5 mm)	1/2" (12.7 mm)	Flush	Light Blue	Plastic-Dipped	0.11 lb (0.05 kg)

