


Side-Cutting Long-Nose Pliers



FORGED STEEL
from Klein's US-made, proprietary blend

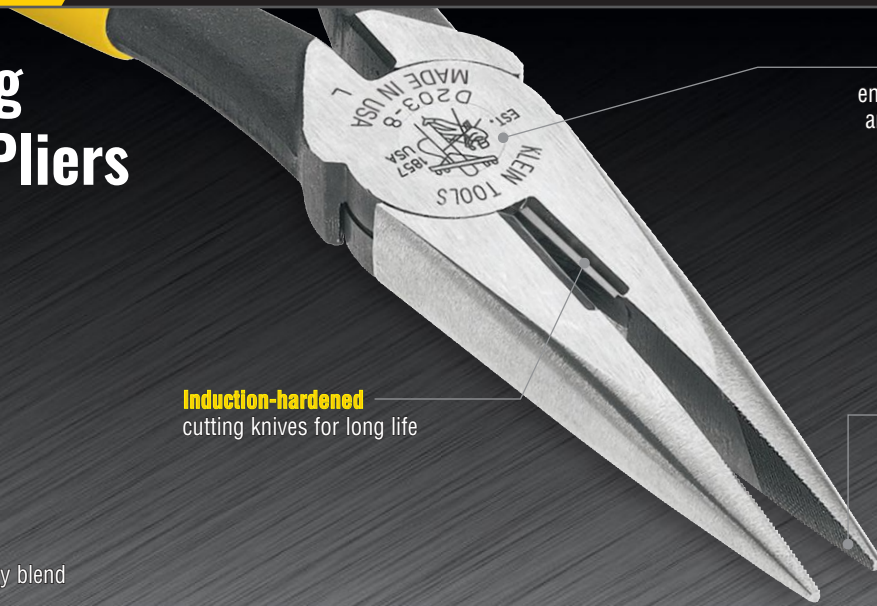

Hot-riveted joint
ensures smooth action and no handle wobble

Induction-hardened
cutting knives for long life

Slim head design
for working in confined areas

All-Purpose Pliers

Includes core features plus:

- Strips 8-16 AWG solid and 10-18 AWG stranded wire (Cat. No. J206-8C)
- Strips 10-18 AWG solid and 12-20 AWG stranded wire and crimps non-insulated connectors, lugs and terminals (Cat. No. J207-8CR)
- Knurled jaw for grabbing and looping wire
- 6-32 and 8-32 screw shearing



J206-8C



CRIMPING FEATURE
J207-8CR

Cat. No.	Overall Length	Jaw Length	Jaw Width	Jaw Thickness	Point Diameter	Knife Length	Handle Color	Handle Finish	Weight
J206-8C	8.625" (219.1 mm)	2.188" (55.6 mm)	1" (25.4 mm)	1/2" (12.7 mm)	1/8" (3.18 mm)	0.5" (12.7 mm)	Yellow/Black	Journeyman	0.60 lb (0.27 kg)
J207-8CR	8.625" (219.1 mm)	2.188" (55.6 mm)	1" (25.4 mm)	1/2" (12.7 mm)	1/8" (3.18 mm)	0.5" (12.7 mm)	Yellow/Black	Journeyman	0.60 lb (0.27 kg)


Heavy-Duty Side-Cutting Long-Nose Pliers

Includes core long-nose features plus:

- Heavier design for greater cutting power
- Extended handles provide added reach and greater leverage
- Glow in the dark grips are easily spotted in dark or low lit areas (Cat. No. D2303-8GLW)



D203-8NCR

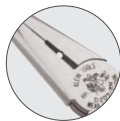

12 AWG WIRE STRIPPING
D203-8N
J203-8N



12 AWG WIRE STRIPPING AND CRIMPING
D203-8NCR



Plastic-Dipped



JOURNEYMAN™
Dual-Material

Refer to the insulated section for insulated pliers.

Cat. No.	Overall Length	Jaw Length	Jaw Width	Jaw Thickness	Point Diameter	Knife Length	Handle Color	Handle Finish	Weight
D203-8	8.438" (214.3 mm)	2.313" (58.8 mm)	1" (25.4 mm)	1/2" (12.7 mm)	1/8" (3.18 mm)	0.625" (15.9 mm)	Yellow	Plastic-Dipped	0.60 lb (0.27 kg)
D203-8-GLW	8.438" (214.3 mm)	2.313" (58.8 mm)	1" (25.4 mm)	1/2" (12.7 mm)	1/8" (3.18 mm)	0.625" (15.9 mm)	Glow in the Dark	Plastic-Dipped	0.60 lb (0.27 kg)
J203-8	8.563" (217.5 mm)	2.313" (58.8 mm)	1" (25.4 mm)	1/2" (12.7 mm)	1/8" (3.18 mm)	0.625" (15.9 mm)	Yellow/Black	Journeyman	0.63 lb (0.29 kg)
D203-8N	8.438" (214.3 mm)	2.313" (58.8 mm)	1" (25.4 mm)	1/2" (12.7 mm)	1/8" (3.18 mm)	0.625" (15.9 mm)	Yellow	Plastic-Dipped	0.59 lb (0.27 kg)
J203-8N	8.563" (217.5 mm)	2.313" (58.8 mm)	1" (25.4 mm)	1/2" (12.7 mm)	1/8" (3.18 mm)	0.625" (15.9 mm)	Yellow/Black	Journeyman	0.64 lb (0.29 kg)
D203-8NCR	8.438" (214.3 mm)	2.313" (58.8 mm)	1" (25.4 mm)	1/2" (12.7 mm)	1/8" (3.18 mm)	0.625" (15.9 mm)	Yellow	Plastic-Dipped	0.61 lb (0.28 kg)



 


Side-Cutting Long-Nose Pliers

Side-Cutting Long-Nose Pliers

Includes core long-nose features plus:

- Knurled jaws for grabbing and looping wire
- Curved handles provide greater tool control
- Spring-loaded action for self-opening (Cat. Nos. D203-6C, D203-7C)



19 & 22 AWG
WIRE STRIPPING
D203-6H2

Refer to the insulated section for insulated pliers.



D203-6C



Plastic-Dipped



JOURNEYMAN™
Dual-Material

Cat. No.	Overall Length	Jaw Length	Jaw Width	Jaw Thickness	Point Diameter	Knife Length	Handle Color	Handle Finish	Weight
D203-6	6.625" (168.3 mm)	1.875" (47.6 mm)	0.688" (17.5 mm)	3/8" (9.5 mm)	3/32" (2.38 mm)	0.5" (12.7 mm)	Yellow	Plastic-Dipped	0.27 lb (0.12 kg)
D203-6C	6.625" (168.3 mm)	1.875" (47.6 mm)	0.688" (17.5 mm)	3/8" (9.5 mm)	3/32" (2.38 mm)	0.5" (12.7 mm)	Yellow	Plastic-Dipped	0.27 lb (0.12 kg)
D203-7	7.188" (182.6 mm)	2.438" (61.9 mm)	0.688" (17.5 mm)	3/8" (9.5 mm)	3/32" (2.38 mm)	0.5" (12.7 mm)	Yellow	Plastic-Dipped	0.29 lb (0.13 kg)
D203-7C	7.188" (182.6 mm)	2.438" (61.9 mm)	0.688" (17.5 mm)	3/8" (9.5 mm)	3/32" (2.38 mm)	0.5" (12.7 mm)	Yellow	Plastic-Dipped	0.29 lb (0.13 kg)
J203-6	6.75" (171.5 mm)	1.875" (47.6 mm)	0.688" (17.5 mm)	3/8" (9.5 mm)	3/32" (2.4 mm)	0.5" (12.7 mm)	Yellow/Black	Journeyman	0.30 lb (0.14 kg)
J203-7	7.313" (185.8 mm)	2.438" (61.9 mm)	0.688" (17.5 mm)	3/8" (9.5 mm)	3/32" (2.4 mm)	0.5" (12.7 mm)	Yellow/Black	Journeyman	0.33 lb (0.15 kg)
D203-6H2	6.625" (168.3 mm)	1.875" (47.6 mm)	0.688" (17.5 mm)	3/8" (9.5 mm)	3/32" (2.4 mm)	0.5" (12.7 mm)	Yellow	Plastic-Dipped	0.26 lb (0.12 kg)

Long-Nose Pliers

Long-Nose Pliers

- Knurled jaws for grabbing and looping wire
- Curved handles provide greater tool control
- Spring-loaded action for self-opening (Cat. No. D301-6C)



D301-6

Cat. No.	Overall Length	Jaw Length	Jaw Width	Jaw Thickness	Point Diameter	Handle Color	Handle Finish	Weight
D301-6	6.625" (168.3 mm)	1.875" (47.6 mm)	0.688" (17.5 mm)	3/8" (9.5 mm)	3/32" (2.38 mm)	Yellow	Plastic-Dipped	0.29 lb (0.13 kg)
D301-6C	6.625" (168.3 mm)	1.875" (47.6 mm)	0.688" (17.5 mm)	3/8" (9.5 mm)	3/32" (2.38 mm)	Yellow	Plastic-Dipped	0.28 lb (0.13 kg)

Slim Long-Nose Pliers

- Longer nose and handles for deeper reach into work
- Spring-loaded for self-opening action
- Curved handles provide greater tool control



D307-5 1/2C

Cat. No.	Overall Length	Jaw Length	Jaw Width	Jaw Thickness	Point Diameter	Handle Color	Handle Finish	Weight
D307-51/2C	5.625" (142.9 mm)	1.688" (42.9 mm)	0.5" (12.7 mm)	5/16" (7.9 mm)	1/32" (.79 mm)	Yellow	Plastic-Dipped	0.15 lb (0.07 kg)
D327-51/2C	5.625" (142.9 mm)	1.688" (42.9 mm)	0.5" (12.7 mm)	5/16" (7.9 mm)	1/16" (1.58 mm)	Dark Blue	Plastic-Dipped	0.15 lb (0.07 kg)

See page 297 for additional information on warnings.



Electronics Long-Nose Pliers

Midget Slim Long-Nose Pliers

- Lightweight, slim-nose pliers for precision subminiature assembly work
- Knurled jaws for grabbing and looping wire
- Curved handles provide greater tool control
- Spring-loaded action for self-opening




D322-4 1/2C

Cat. No.	Overall Length	Jaw Length	Jaw Width	Jaw Thickness	Point Diameter	Handle Color	Handle Finish	Weight
D321-41/2C	4.813" (122.3 mm)	1.063" (27 mm)	0.438" (11.1 mm)	1/4" (6.4 mm)	1/32" x 1/16" (.79 mm x 1.58 mm)	Light Blue	Plastic-Dipped	0.13 lb (0.06 kg)
D322-41/2C	4.813" (122.3 mm)	1.063" (27 mm)	0.438" (11.1 mm)	1/4" (6.4 mm)	1/32" x 1/16" (.79 mm x 1.58 mm)	Light Blue	Plastic-Dipped	0.13 lb (0.06 kg)

Long Needle-Nose Pliers

- Designed for accurate work in hard-to-reach areas
- Knurled jaws for grabbing and looping wire
- Spring-loaded for self-opening action
- Curved handles provide greater tool control
- Extra-slim hinge for extremely close quarter work (Cat. No. D355-51/2C)

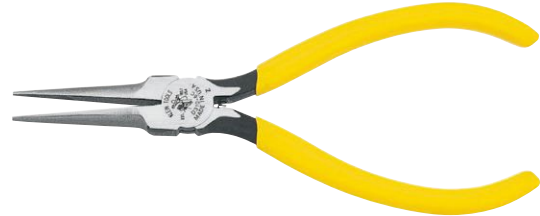

D310-6C

Cat. No.	Overall Length	Jaw Length	Jaw Width	Jaw Thickness	Point Diameter	Handle Color	Handle Finish	Weight
D310-6C	6.625" (168.3 mm)	1.875" (47.6 mm)	0.688" (17.5 mm)	3/8" (9.5 mm)	1/16" (1.58 mm)	Yellow	Plastic-Dipped	0.27 lb (0.12 kg)
D318-51/2C	5.625" (142.9 mm)	1.688" (42.9 mm)	0.5" (12.7 mm)	5/16" (7.9 mm)	1/16" (1.58 mm)	Yellow	Plastic-Dipped	0.13 lb (0.06 kg)
D335-51/2C	5.625" (142.9 mm)	1.688" (42.9 mm)	0.469" (11.9 mm)	1/4" (6.4 mm)	1/16" (1.58 mm)	Light Blue	Plastic-Dipped	0.13 lb (0.06 kg)

Curved Long-Nose Pliers

- 70° bent nose for maximum work visibility in confined areas
- Knurled jaws for grabbing and looping wire
- Curved handles provide greater tool control



D302-6

Cat. No.	Overall Length	Jaw Length	Jaw Width	Jaw Thickness	Point Diameter	Handle Color	Handle Finish	Weight
D302-6	6.375" (161.9 mm)	1.5" (38.1 mm)	0.688" (17.5 mm)	3/8" (9.5 mm)	3/32" (2.38 mm)	Yellow	Plastic Dipped	0.30 lb (0.14 kg)

Midget Curved Chain-Nose Pliers

- 60° bent nose for maximum work visibility in confined areas
- Easily bends and forms fine wire
- Polished inside jaws and radiused jaw edges prevent nicking wire
- Spring-loaded for self-opening action
- Curved handles provide greater tool control



D320-4 1/2C

Cat. No.	Overall Length	Jaw Length	Jaw Width	Jaw Thickness	Point Diameter	Handle Color	Handle Finish	Weight
D320-41/2C	4.75" (120.7 mm)	1" (25.4 mm)	0.406" (10.3 mm)	1/4" (6.4 mm)	1/16" (1.58 mm)	Light Blue	Plastic-Dipped	0.13 lb (0.06 kg)

