

Folding Hex-Key Sets

Hex-Key Sets

- Two key positions (straight-out or right angle) for extra leverage
- Hex ends are square-cut for a secure full-depth fit and maximum contact with the hex socket to prevent slippage and stripping of the socket
- Handy sets fit in your pocket or tool box easily and help eliminate the lost key problem
- Made in the U.S.A.



70579

Cat. No.	Description	Size	Handle Length	Key Lengths	Color	Weight
70591	Folding Hex Key Set, Nine-Key, Inch Sizes	5/64", 3/32", 7/64", 1/8", 9/64", 5/32", 3/16", 7/32", 1/4"	4.375" (111.1 mm)	2.688 to 3.813" (68.3 to 96.9 mm)	Silver	0.50 lb (0.23 kg)
70581	8-Key Folding Hex Key Set, 1/20 to 5/32" SAE	1/20", 1/16", 5/64", 3/32", 7/64", 1/8", 9/64", 5/32"	3.063" (77.8 mm)	1.875 to 3" (47.6 to 76.2 mm)	Silver	0.20 lb (0.09 kg)
70579	Folding Hex Key Set, 5", SAE, 5-Piece	3/16", 7/32", 1/4", 5/16", 3/8"	5.375" (136.5 mm)	2.688 to 3.813" (68.3 to 96.9 mm)	Silver	0.85 lb (0.39 kg)
70582	Seven-Key Metric Folding Hex Key Set	1-1/2 mm, 2 mm, 2-1/2 mm, 3 mm, 4 mm, 5 mm, 6 mm	3.703" (94.1 mm)	0.594 to 1.781" (15.1 to 45.2 mm)	Silver	0.27 lb (0.12 kg)
70580	Folding Hex Key Set, Six-Key, Metric Sizes	3 mm, 4 mm, 5 mm, 6 mm, 8 mm, 10 mm	5.375" (136.5 mm)	2.375 to 4" (60.3 to 101.6 mm)	Silver	0.85 lb (0.39 kg)

Grip-It™ Hex-Key Sets

- Blades rotate independently up to 270°
- Precision fit so hex tool end reduces stripping problems. Keys are industrial strength, impact-resistant and tested for performance to below freezing
- Glass-reinforced nylon handle
- Hex ends are square-cut for a secure full-depth fit and maximum contact with the hex socket to prevent slippage and stripping of the socket (Cat. Nos. 70570, 70573, 70574, and 70575)
- Ball design allows for a thicker neck diameter increasing torque capacity, while maintaining operational angles to 25% (Cat. Nos. 70571 and 70572)
- Made in the U.S.A.



70570

Cat. No.	Description	Size	Handle Length	Key Lengths	Color	Weight
70571	Grip-It® Ball End Hex Key Set, 5 Key, Inch Sizes	3/16", 7/32", 1/4", 5/16", 3/8"	4.438" (112.7 mm)	1.547 to 2" (39.3 to 50.8 mm)	Yellow	0.58 lb (0.26 kg)
70572	Grip-It® Five Key Ball Hex Set - Metric	5 mm, 6 mm, 7 mm, 8 mm, 10 mm	4.438" (112.7 mm)	1.594 to 1.938" (40.5 to 49.2 mm)	Red	0.58 lb (0.26 kg)
70573	Grip-It® 12 Key Hex Set - Inch/Metric	5/64", 3/32", 7/64", 1/8", 9/64", 5/32", 1.5 mm, 2 mm, 2.5 mm, 3 mm, 4 mm, 5 mm	4.438" (112.7 mm)	1.438 to 2.266" (36.5 to 57.6 mm)	Blue	0.30 lb (0.14 kg)
70574	Grip-It Nine Key Hex Set with 2 Positions	5/64", 3/32", 7/64", 1/8", 9/64", 5/32", 3/16", 7/32", 1/4"	4.438" (112.7 mm)	1.75 to 2.266" (44.5 to 57.6 mm)	Yellow	0.33 lb (0.15 kg)
70575	Grip-It® Nine Key Hex Set Square Cut	3/64", 1/16", 5/64", 3/32", 7/64", 1/8", 9/64", 5/32", 3/16"	3.813" (96.9 mm)	1.391 to 1.844" (35.3 to 46.8 mm)	Yellow	0.20 lb (0.09 kg)

TORX® Sets

Folding TORX® Set

- TORX® drive cuts slippage, saves fasteners, efficiently transmits more torque to the work
- Keys are tough, heat-treated chrome-nickel alloy steel for strength and durability
- Keys fold flat into handle
- Can be used straight out or at an angle for extra leverage



70586

Cat. No.	Size	Handle Length	Key Lengths	Color	Weight
70586	T10, T15, T20, T25, T27, T30, T40	4.375" (111.1 mm)	2.813 to 3" (71.5 to 76.2 mm)	Silver	0.30 lb (0.14 kg)

TORX® is a trademark of Acument Intellectual Properties, LLC.




Hex-Key Wrenches

L-Style Hex-Keys

Rust and corrosion resistant surfaces

Top-grade alloy steel

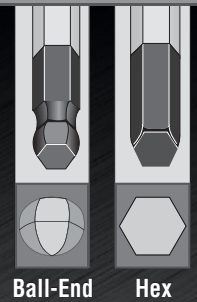

L-Style Hex-Keys

LL8

Cat. No.	Hex Size	Short Arm Length	Long Arm Length	Weight
LL2	0.050"	0.563" (14.3 mm)	2.875" (73 mm)	0.08 oz (2.3 g)
LL4	1/16"	0.625" (15.9 mm)	3.063" (77.8 mm)	0.08 oz (2.3 g)
LL5	5/64"	0.688" (17.5 mm)	3.25" (82.6 mm)	0.08 oz (2.3 g)
LL6	3/32"	0.75" (19.1 mm)	3.5" (88.9 mm)	0.16 oz (4.5 g)
LL7	7/64"	0.813" (20.7 mm)	3.688" (93.7 mm)	0.32 oz (9.1 g)
LL8	1/8"	0.875" (22.2 mm)	3.875" (98.4 mm)	0.32 oz (9.1 g)
LL9	9/64"	0.938" (23.8 mm)	4.125" (104.8 mm)	0.48 oz (13.6 g)
LL10	5/32"	1" (25.4 mm)	4.375" (111.1 mm)	0.48 oz (13.6 g)
LL12	3/16"	1.125" (28.6 mm)	4.688" (119.1 mm)	0.80 oz (22.7 g)
LL14	7/32"	1.25" (31.8 mm)	5.063" (128.6 mm)	0.70 lb (0.32 kg)
LL16	1/4"	1.375" (34.9 mm)	5.5" (139.7 mm)	0.10 lb (0.05 kg)
LL20	5/16"	1.563" (39.7 mm)	6.313" (160.4 mm)	0.18 lb (0.08 kg)
LL24	3/8"	1.75" (44.5 mm)	7.125" (181 mm)	0.25 lb (0.11 kg)
Metric				
LLM15	1.5 mm	0.563" (14.3 mm)	3.125" (79.4 mm)	0.08 oz (2.3 g)
LLM2	2 mm	0.688" (17.5 mm)	3.031" (77 mm)	0.08 oz (2.3 g)
LLM25	2.5 mm	0.813" (20.7 mm)	3.563" (90.5 mm)	0.16 oz (4.5 g)
LLM3	3 mm	0.875" (22.2 mm)	4" (101.6 mm)	0.32 oz (9.1 g)
LLM4	4 mm	1" (25.4 mm)	4.5" (114.3 mm)	0.48 oz (13.6 g)
LLM5	5 mm	1.25" (31.8 mm)	4.875" (123.8 mm)	0.80 oz (22.7 g)
LLM6	6 mm	1.438" (36.5 mm)	5.688" (144.5 mm)	1.3 oz (37 g)
LLM8	8 mm	1.688" (42.9 mm)	6.313" (160.4 mm)	0.15 lb (0.07 kg)
LLM10	10 mm	1.938" (49.2 mm)	7.125" (181 mm)	0.25 lb (0.11 kg)

L-Style Ball-End Hex-Keys

BL8

Includes core L-Style hex key features plus:

- Allows easy access, even in restricted areas
- Ball-end works on angles up to 30°

Cat. No.	Hex Size	Short Arm Length	Long Arm Length	Weight
BL2	0.050"	0.563" (14.3 mm)	2.875" (73 mm)	0.03 oz (0.9 g)
BL4	1/16"	0.625" (15.9 mm)	3.063" (77.8 mm)	0.03 oz (0.9 g)
BL5	5/64"	0.688" (17.5 mm)	3.25" (82.6 mm)	0.08 oz (2.3 g)
BL6	3/32"	0.75" (19.1 mm)	3.5" (88.9 mm)	0.08 oz (2.3 g)
BL7	7/64"	0.75" (19.1 mm)	3.688" (93.7 mm)	0.16 oz (4.5 g)
BL8	1/8"	0.875" (22.2 mm)	3.875" (98.4 mm)	0.32 oz (9.1 g)
BL9	9/64"	0.938" (23.8 mm)	4.125" (104.8 mm)	0.32 oz (9.1 g)
BL10	5/32"	1" (25.4 mm)	4.375" (111.1 mm)	0.48 oz (13.6 g)
BL12	3/16"	1.125" (28.6 mm)	4.688" (119.1 mm)	0.80 oz (22.7 g)
BL14	7/32"	1.25" (31.8 mm)	5.063" (128.6 mm)	1.0 oz (28 g)
BL16	1/4"	1.375" (34.9 mm)	5.813" (147.7 mm)	1.4 oz (40 g)
BL20	5/16"	1.563" (39.7 mm)	6.313" (160.4 mm)	0.17 lb (0.08 kg)
BL24	3/8"	1.75" (44.5 mm)	7.125" (181 mm)	0.23 lb (0.10 kg)
Metric				
BLM15	1.5 mm	0.563" (14.3 mm)	3.063" (77.8 mm)	0.16 oz (4.5 g)
BLM2	2 mm	0.688" (17.5 mm)	3.313" (84.2 mm)	0.16 oz (4.5 g)
BLM25	2.5 mm	0.813" (20.7 mm)	3.563" (90.5 mm)	0.16 oz (4.5 g)
BLM3	3 mm	0.875" (22.2 mm)	4" (101.6 mm)	0.32 oz (9.1 g)
BLM4	4 mm	1" (25.4 mm)	4.5" (114.3 mm)	0.48 oz (13.6 g)
BLM5	5 mm	1.25" (31.8 mm)	4.875" (123.8 mm)	0.80 oz (22.7 g)
BLM6	6 mm	1.438" (36.5 mm)	5.688" (144.5 mm)	1.3 oz (37 g)
BLM8	8 mm	1.688" (42.9 mm)	6.313" (160.4 mm)	0.14 lb (0.06 kg)
BLM10	10 mm	1.938" (49.2 mm)	6.125" (155.6 mm)	0.24 lb (0.11 kg)

See page 297 for additional information on warnings.



L-Style Hex-Key Sets

L-Style Caddy Sets

Includes core L-Style hex key features plus:

- L-style hex-keys organized in convenient, durable caddy sets
- Each set contains a unique locking feature and marked slots for each key
- Ball-end works on angles up to 30° (Cat. Nos. BLK12 and BLMK10)



BLK12



LMK10

Cat. No.	Set Contains	Weight
BLK12	L Style Ball End Hex Key Caddy Set 12-Piece	0.53 lb (0.24 kg)

Cat. No.	Hex Size	Short Arm Length	Long Arm Length
BL2	0.050"	0.563" (14.3 mm)	2.875" (73 mm)
BL4	1/16"	0.625" (15.9 mm)	3.063" (77.8 mm)
BL5	5/64"	0.688" (17.5 mm)	3.25" (82.6 mm)
BL6	3/32"	0.75" (19.1 mm)	3.5" (88.9 mm)
BL7	7/64"	0.75" (19.1 mm)	3.688" (93.7 mm)
BL8	1/8"	0.875" (22.2 mm)	3.875" (98.4 mm)
BL9	9/64"	0.938" (23.8 mm)	4.125" (104.8 mm)
BL10	5/32"	1" (25.4 mm)	4.375" (111.1 mm)
BL12	3/16"	1.125" (28.6 mm)	4.688" (119.1 mm)
BL14	7/32"	1.25" (31.8 mm)	5.063" (128.6 mm)
BL16	1/4"	1.375" (34.9 mm)	5.813" (147.7 mm)
BL20	5/16"	1.563" (39.7 mm)	6.313" (160.4 mm)

Cat. No.	Set Contains	Weight
BLMK10	L Style Ball End Hex Key Caddy Set Metric 9-Piece	0.62 lb (0.28 kg)

Cat. No.	Hex Size	Short Arm Length	Long Arm Length
BLM15	1.5 mm	0.563" (14.3 mm)	3.063" (77.8 mm)
BLM2	2 mm	0.688" (17.5 mm)	3.313" (84.2 mm)
BLM25	2.5 mm	0.813" (20.7 mm)	3.563" (90.5 mm)
BLM3	3 mm	0.875" (22.2 mm)	4" (101.6 mm)
BLM4	4 mm	1" (25.4 mm)	4.5" (114.3 mm)
BLM5	5 mm	1.25" (31.8 mm)	4.875" (123.8 mm)
BLM6	6 mm	1.438" (36.5 mm)	5.688" (144.5 mm)
BLM8	8 mm	1.688" (42.9 mm)	6.313" (160.4 mm)
BLM10	10 mm	1.938" (49.2 mm)	6.125" (155.6 mm)

Cat. No.	Set Contains	Weight
LLK12	L-Style Hex Key Caddy Set 12-Piece	0.54 lb (0.24 kg)

Cat. No.	Hex Size	Short Arm Length	Long Arm Length
LL2	0.050"	0.563" (14.3 mm)	2.875" (73 mm)
LL4	1/16"	0.625" (15.9 mm)	3.063" (77.8 mm)
LL5	5/64"	0.688" (17.5 mm)	3.25" (82.6 mm)
LL6	3/32"	0.75" (19.1 mm)	3.5" (88.9 mm)
LL7	7/64"	0.813" (20.7 mm)	3.688" (93.7 mm)
LL8	1/8"	0.875" (22.2 mm)	3.875" (98.4 mm)
LL9	9/64"	0.938" (23.8 mm)	4.125" (104.8 mm)
LL10	5/32"	1" (25.4 mm)	4.375" (111.1 mm)
LL12	3/16"	1.125" (28.6 mm)	4.688" (119.1 mm)
LL14	7/32"	1.25" (31.8 mm)	5.063" (128.6 mm)
LL16	1/4"	1.375" (34.9 mm)	5.5" (139.7 mm)
LL20	5/16"	1.563" (39.7 mm)	6.313" (160.4 mm)

Cat. No.	Set Contains	Weight
LMK10	L-Style Hex Key Caddy Set Metric, 9-Piece	0.63 lb (0.29 kg)

Cat. No.	Hex Size	Short Arm Length	Long Arm Length
LLM15	1.5 mm	0.563" (14.3 mm)	3.125" (79.4 mm)
LLM2	2 mm	0.688" (17.5 mm)	3.031" (77 mm)
LLM25	2.5 mm	0.813" (20.7 mm)	3.563" (90.5 mm)
LLM3	3 mm	0.875" (22.2 mm)	4" (101.6 mm)
LLM4	4 mm	1" (25.4 mm)	4.5" (114.3 mm)
LLM5	5 mm	1.25" (31.8 mm)	4.875" (123.8 mm)
LLM6	6 mm	1.438" (36.5 mm)	5.688" (144.5 mm)
LLM8	8 mm	1.688" (42.9 mm)	6.313" (160.4 mm)
LLM10	10 mm	1.938" (49.2 mm)	7.125" (181 mm)

