
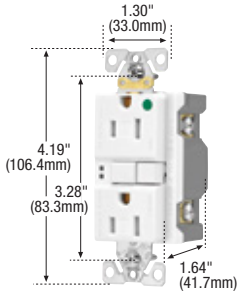



Hospital grade self-test GFCI receptacles

Product description


2-pole, 3-wire grounding
15A, 125V/AC; 20A, 125V/AC
NEMA 5-15R, 5-20R

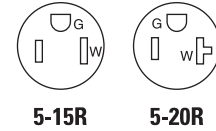


TRSGFH15

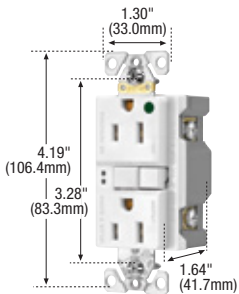

SGFH15

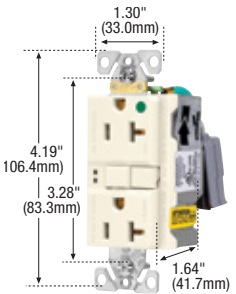

SGFH20_MOD

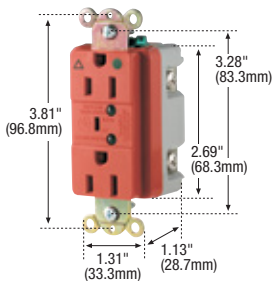

IG8200HG_S

Premium hospital grade receptacles




Rating	A	V/AC	NEMA	Description	Color suffix	Catalog no.			
15	125	5-15R	Hospital GFCI, back & side wire	B, GY, LA, RD, V, W	□ SGFH15__	•	•		
			Hospital GFCI, back & side wire	B, GY, LA, RD, V, W	□ SGFH15F__	•	•	•	•
			Tamper resistant hospital GFCI, back & side wire	B, BK, GY, LA, RD, V, W	□ TRSGFH15__	•	•		
			Tamper resistant hospital GFCI, back & side wire	B, GY, LA, RD, V, W	□ TRSGFH15F__	•	•	•	•
20	125	5-20R	Hospital GFCI, back & side wire	B, GY, LA, RD, V, W	□ SGFH20__	•	•		
			Hospital GFCI, back & side wire	B, GY, LA, RD, V, W	□ SGFH20F__	•	•	•	•
			Tamper resistant hospital GFCI, back & side wire	B, BK, GY, LA, RD, V, W	□ TRSGFH20__	•	•		
			Tamper resistant hospital GFCI, back & side wire	B, GY, LA, RD, V, W	□ TRSGFH20F__	•	•	•	•

Includes standard size unbreakable wallplate

Hospital grade surge protection receptacles with LED indicators & audible alarm

Product description

2-pole, 3-wire grounding
15A, 125V/AC
20A, 125V/AC
NEMA 5-15R, 5-20R

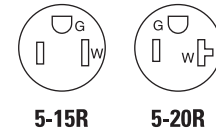

Surge protection receptacles w/audible alarm & LED indicators



Rating	A	V/AC	NEMA	Description	Color suffix	Catalog no.		
15	125	5-15R	Hospital grade duplex receptacle, back & side wire	BL, RD, V, W	□ 8200__S	•	•	
			IG hospital grade duplex receptacle, back & side wire	BL, RN, V, W	□ IG8200HG__S	•	•	
20	125	5-20R	Hospital grade duplex receptacle, back & side wire	BL, RD, V, W	□ 8300__S	•	•	
			IG hospital grade duplex receptacle, back & side wire	BL, RN, V, W	□ IG8300HG__S	•	•	

560 Joules, max. surge current - 18kA, MCOV - 150V/AC

Color ordering information:

For ordering devices, include Catalog no. followed by the Color suffix: B (Brown), BK (Black), BL (Blue), GY (Gray), LA (Light Almond), RD (Red), V (Ivory), W (White)



Specification information:

Hospital grade GFCI: H-9
Surge protection receptacles with audible alarm & LED: I-20

Compliances, specifications and availability are subject to change without notice.

➡ ArrowLink option available. Add "MOD" suffix to standard catalog number (example TRSGFH15W, TRSGFH15WMOD). For ordering information on ArrowLink & ArrowLink SPD connectors, see Page J-9

TR Tamper resistant

🔧 Build-to-spec customizable devices - Page J-10

🇺🇸 Indicates NAFTA compliant - Page Q-32

🌱 RoHS compliant - Page Q-32