




## 2-010 Round Insulated GU10

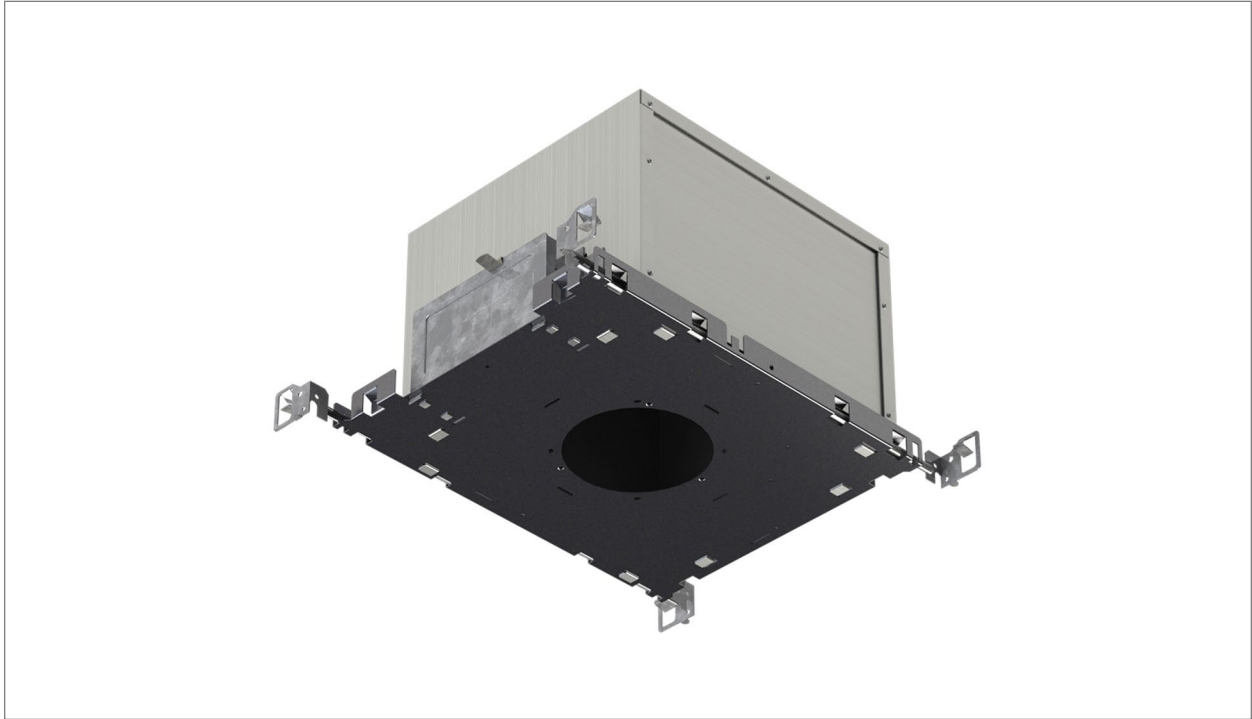

The 2-010 series housing is designed for insulated and airtight ceilings. Performing in accordance with ASTM E283-91, the airtight option also meets the requirements of "having no more than 2.0 CFM air movement from the conditioned space to the ceiling cavity" (Sec. 502.4 of 1991 WSEC—Washington State Electrical Code).

### FEATURES

- Designed for 50W GU10 halogen 120V lamp
- GU10-LED lamp rated for 15W (max.)
- 16" hanger bars standard
- 20 Ga. cold rolled steel baseplate
- 18 Ga. galvanized steel junction box
- 5 junction box knock outs
- Over lamping protection
- Approved for branch circuit wiring

 
 


 
 





 





 
 
 
 
 

 
 
 


### DETAILS

Aperture: 4"  
Shape: Round  
Ceiling: Insulated



2-010-GU10-Specs • Subject to change without notice • Rev 2017.01.11 • 1/4

## Compatible Trims

Trim	Trim Type	
	Trimmed	Trimless
2-110 Coral		—
2-112 Round Wall Wash		—
2-115 Aqua		
2-120 Aurora		
2-125 Deep Aurora		
2-160 Demi		—
2-167 Starlite		
2-170 Conus		
2-175 Corona		—
2-180 Pinhole		
2-182 Flare Wall Wash		
2-185 Picolo		
2-187 Lensed Picolo		
2-190 Keyhole		
2-195 Pivot		
2-197 Linover		

2-010-GU10-Specs • Subject to change without notice • Rev 2017.01.11 • 3/4

# 2-010

## Round Insulated GU10

---

Project

Type

Notes

Product Code

\_\_\_\_\_

1                      2                      3                      4                      5

### 1. Housing

**2-010** Round

### 2. Housing Type

**IC** Insulated

**IC-AT** Insulated Airtight

**IC-TL** Trimless Insulated

**IC-AT-TL** Trimless Airtight Insulated

### 3. Lamp

**GU10-HAL** Halogen

**GU10-LED** LED<sup>1</sup>

### 4. Voltage

**120**

### 5. Options

**BPHI** Black Painted Housing Interior

**WPHI** White Painted Housing Interior

Notes

<sup>1</sup> **GU10-LED** is compatible with GU10 LED lamp, rated for a maximum 15W, sold separately.

---

2-010-GU10-Specs • Subject to change without notice • Rev 2017.01.11 • 4/4

---