


2-020 Round Non-Insulated MR16

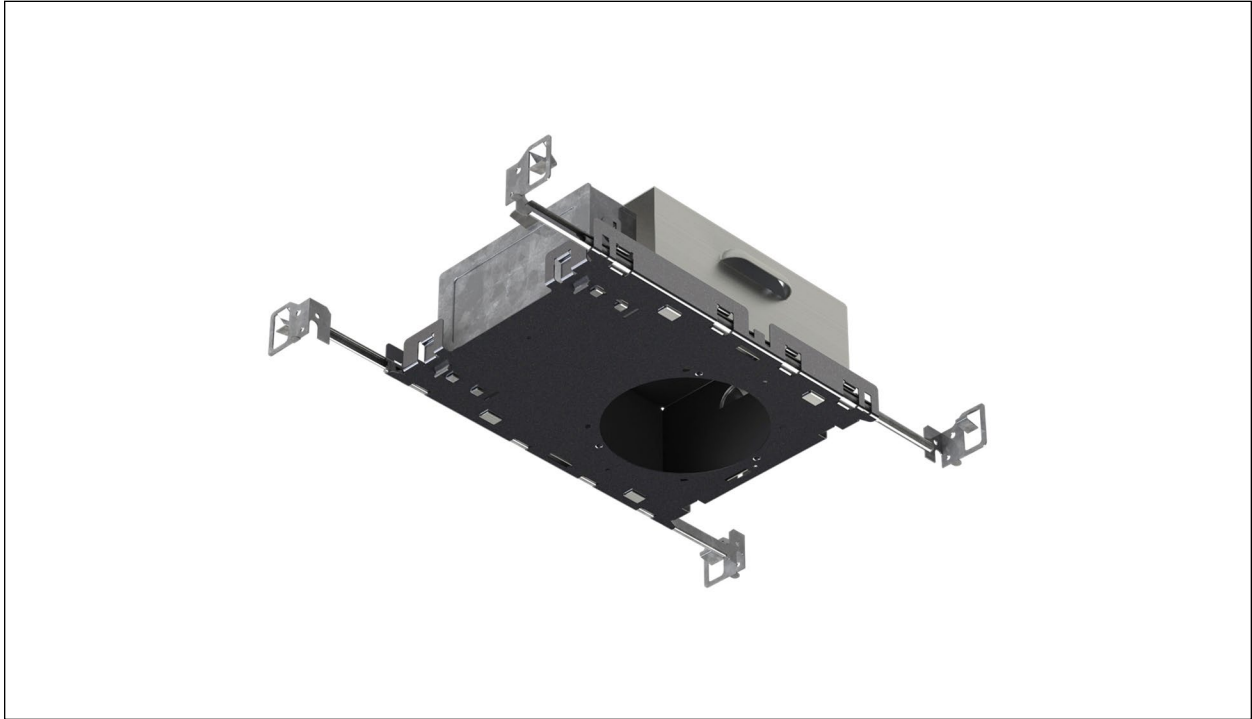

The 2-020 series housing is designed for non-insulated ceilings, allowing for installation of very shallow plenums, as low as 4". It's sleek footprint allows for compatibility with most ceiling applications.

FEATURES

- Rated for non-insulated ceilings
- Low voltage (12V) MR16 lamp (sold separately)
- Porcelain Bi Pin socket type GX5.3
- MR16 LED lamp is compatible with E15 electronic transformer option
- 16" hanger bars standard
- 20 Ga. cold rolled steel baseplate
- 18 Ga. galvanized steel junction box
- 5 junction box knock outs
- Approved for branch circuit wiring
- Transformer accessible through the ceiling

















 





 
DETAILS

Aperture: 4"
Shape: Round
Ceiling: Insulated



2-020-MR16-Specs • Subject to change without notice • Rev 2016.12.19 • 1/5

Compatible Trims

Trim	Trim Type	
	Trimmed	Trimless
2-110 Coral		—
2-112 Round Wall Wash		—
2-115 Aqua		
2-120 Aurora		
2-130 Sunburst		—
2-140 Eclipse		—
2-150 Siris		—
2-160 Demi		—
2-167 Starlite		
2-170 Conus		
2-175 Corona		—
2-180 Pinhole		
2-182 Flare Wall Wash		
2-185 Piccolo		
2-187 Lensed Piccolo		

2-020-MR16-Specs • Subject to change without notice • Rev 2016.12.19 • 3/5

2-020

Round Non-Insulated MR16

Project

Type

Notes

Product Code

1 2 3 4 5

1. Housing

2-020 Round

2. Housing Type

F Non-Insulated

F-TL Trimless Non-Insulated

3. Transformer

E Electronic

E15 15W Electronic ¹

M Magnetic

4. Voltage

120

277

347 ²

5. Options

BPHI Black Painted Housing Interior

WPHI White Painted Housing Interior

Notes

¹ **E15** transformer option is only compatible with Sora MR16 LED lamp.

² **347** voltage is only available with **M** magnetic transformer.

2-020-MR16-Specs • Subject to change without notice • Rev 2016.12.19 • 5/5
