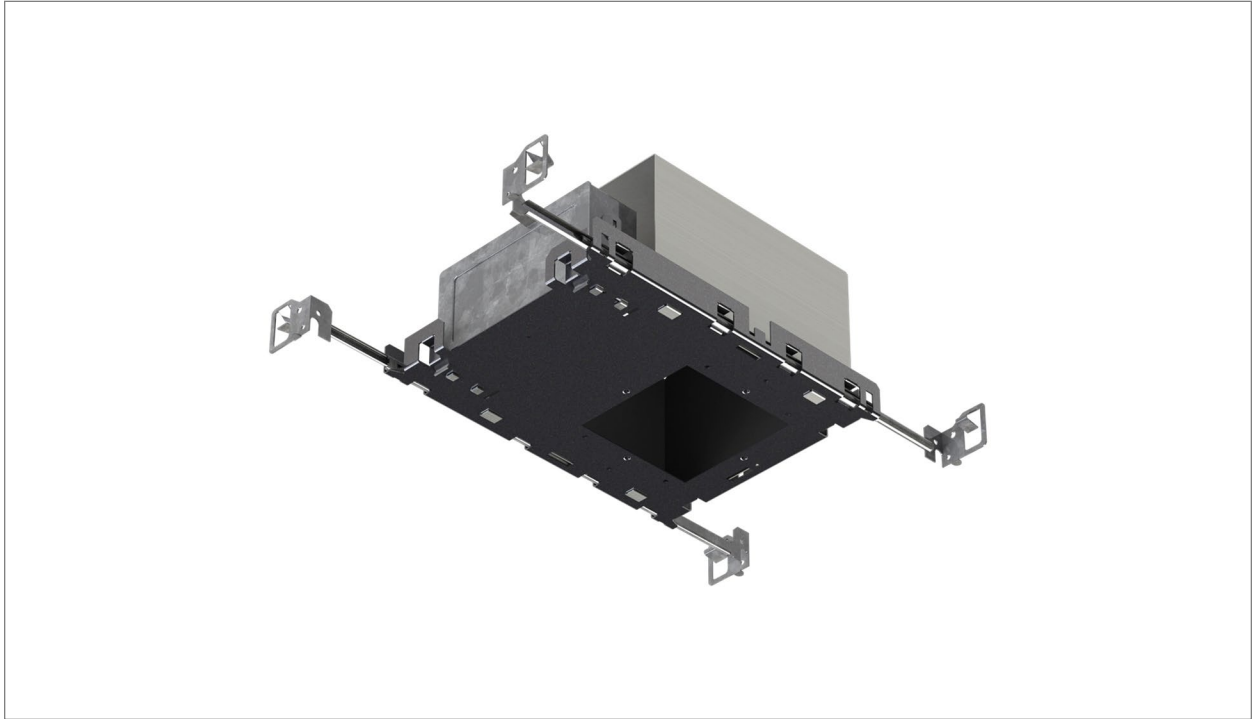


2-025

Square Non-Insulated MR16



The 2-025 series housing is designed for non-insulated ceilings, allowing for installation of very shallow plenums, as low as 4". It's sleek footprint allows for compatibility with most ceiling applications.

FEATURES

- Rated for non-insulated ceilings
- Low voltage (12V) MR16 lamp (sold separately)
- Porcelain Bi Pin socket type GX5.3
- MR16 LED lamp is compatible with E15 electronic transformer option
- 16" hanger bars standard
- 20 Ga. cold rolled steel baseplate
- 18 Ga. galvanized steel junction box
- 5 junction box knock outs
- Approved for branch circuit wiring
- Transformer accessible through the ceiling

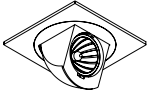
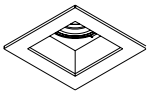
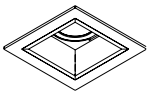

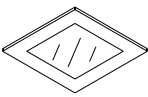
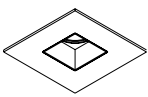

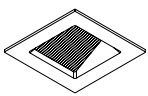
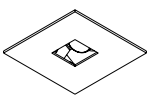



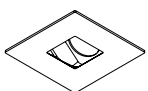

DETAILS

Aperture: 4"
Shape: Square
Ceiling: Non-Insulated



2-025-MR16-Specs • Subject to change without notice • Rev 2016.12.19 • 1/4

Compatible Trims

Trim	Trim Type	
	Trimmed	Trimless
2-250 Quadra Split		—
2-500 Quadra		—
2-520 Miro		
2-550 Nemo		—
2-580 Forte		
2-582 Quadra Wall Wash		—
2-585 Quadra Pinhole		
2-587 Forte Wall Wash		
2-597 Quadra Linover		

2-025

Square Non-Insulated MR16

Project

Type

Notes

Product Code

1 2 3 4 5

1. Housing

2-025 Square

2. Housing Type

F-Q Non-Insulated

F-Q-TL Trimless Non-Insulated

3. Transformer

E Electronic

E15 15W Electronic ¹

M Magnetic

MPT Magnetic Potted ²

4. Voltage

120

277

347 ³

5. Options

BPHI Black Painted Housing Interior

WPHI White Painted Housing Interior

Notes

¹ **E15** transformer option is only compatible with Sora MR16 LED lamp.

² **MPT** transformer option is available in 120V and increases housing height to 4.5".

³ **347** voltage is only available with **M** magnetic transformer.

2-025-MR16-Specs • Subject to change without notice • Rev 2016.12.19 • 4/4
