




2-025

Square Non-Insulated GU10

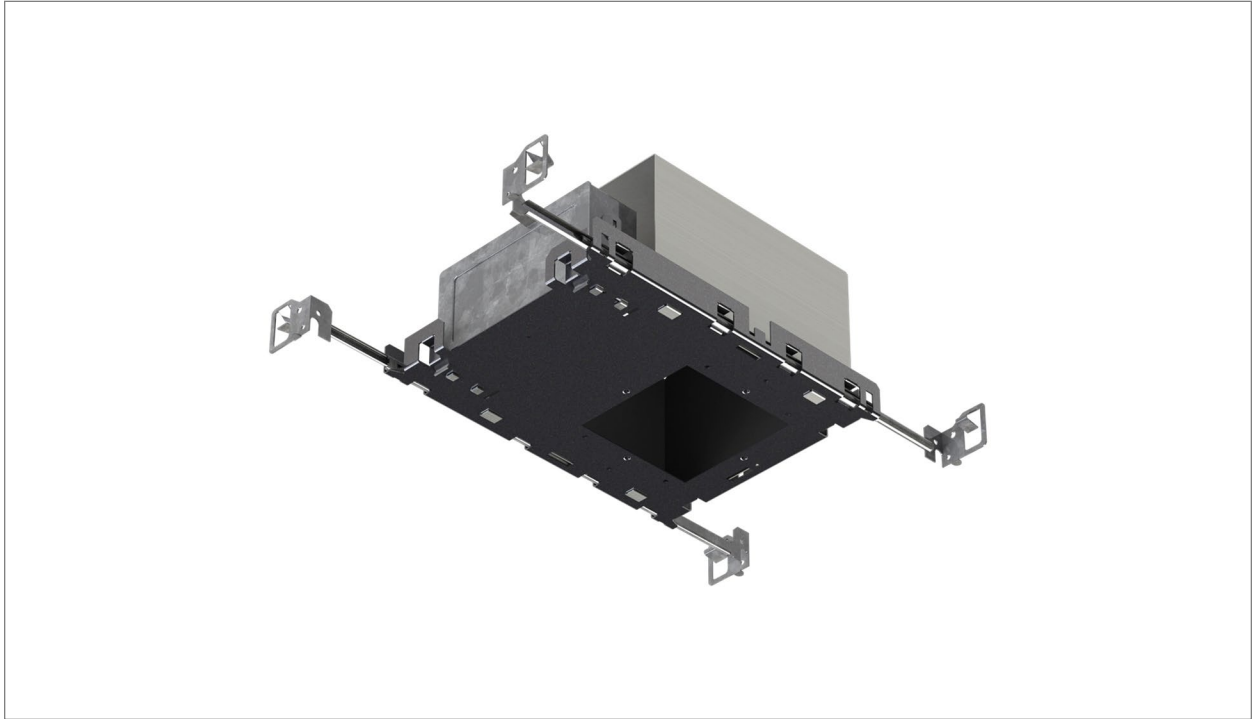

The 2-025 series housing is designed for non-insulated ceilings, allowing for installation of very shallow plenums, as low as 5". It's sleek footprint allows for compatibility with most ceiling applications.

FEATURES

- Designed for 50W GU10 halogen 120V lamp
- GU10-LED lamp rated for 15W (max.)
- 16" hanger bars standard
- 20 Ga. cold rolled steel baseplate
- 18 Ga. galvanized steel junction box
- 5 junction box knock outs
- Over lamping protection
- Approved for branch circuit wiring


 

 
 

 
 



 

DETAILS

Aperture: 4"
Shape: Square
Ceiling: Non-Insulated



2-025-GU10-Specs • Subject to change without notice • Rev 2016.12.19 • 1/4

Compatible Trims

Trim	Trim Type	
	Trimmed	Trimless
2-500 Quadra		—
2-520 Miro		
2-550 Nemo		—
2-580 Forte		
2-582 Quadra Wall Wash		—
2-585 Quadra Pinhole		
2-587 Forte Wall Wash		
2-597 Quadra Linover		

2-025

Square Non-Insulated GU10

Project

Type

Notes

Product Code

1 2 3 4 5

1. Housing

2-025 Square

2. Housing Type

F-Q Non-Insulated

F-Q-TL Trimless Non-Insulated

3. Lamp

GU10-HAL Halogen

GU10-LED LED¹

4. Voltage

120

5. Options

BPHI Black Painted Housing Interior

WPHI White Painted Housing Interior

Notes

¹ **GU10-LED** is compatible with GU10 LED lamp, rated for a maximum 15W, sold separately.

2-025-GU10-Specs • Subject to change without notice • Rev 2016.12.19 • 4/4
