

2-120-T Aurora MR16



With a myriad of reflector, trim, and color temperature combinations, Aurora blends discretely with any décor. The 2 1/2" regressed lamp delivers high lumens without glare, while 35° aiming increases flexibility in locating luminaires.

FEATURES

- Utilizes MR16
- 35° aiming
- Die-cast aluminum fixture
- Powder coated and plated trim ring finishes
- Trim clips designed for 5/8" ceiling thickness
- Accepts up to 2 optional media
- Clear glass lens included
- Trimless version available (see separate specifications)

DETAILS

Trim Class: 4"
Category: Recessed Downlight
Shape: Round
Adjustability: Aiming




2-120-T-Aurora-MR16-Specs • Subject to change without notice • Rev 2016.12.19 • 1/4


Compatible Housings

NON-INSULATED

2-020
Round Non-Insulated
L 10 1/2" [267mm]
W 7 3/4" [197mm]
H 3 1/2" [90mm]

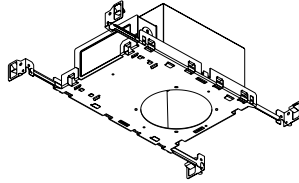


2-060
Round Non-Insulated
L 13 3/4" [349mm]
W 10 7/8" [276mm]
H 3 1/2" [90mm]

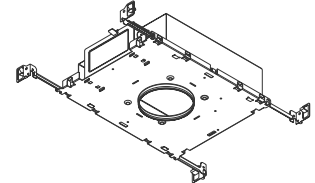


INSULATED

2-010
Round Insulated
L 13 3/4" [350mm]
W 10 7/8" [277mm]
H 7" [178mm]

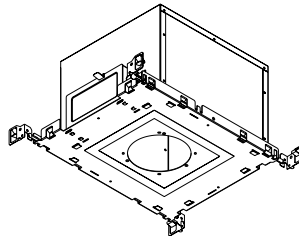


2-012
Round Insulated
L 22 1/2" [572mm]
W 8 1/2" [216mm]
H 5 7/8" [150mm]

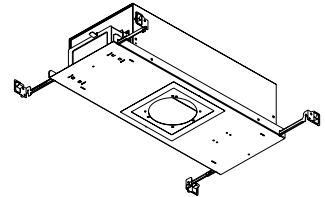


REMODEL

2-030
Round Remodel
L 14" [356mm]
W 4 1/2" [114mm]
H 5 1/8" [130mm]

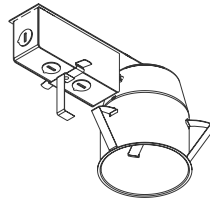


SPECIALIZED

2-060
Round Chicago Plenum
L 13 3/4" [350mm]
W 10 7/8" [277mm]
H 4 1/2" [115mm]

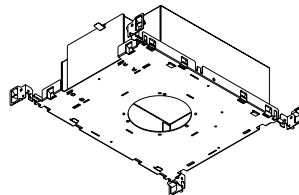

2-100
Round Concrete Housing
L 18" [457mm]
W 12" [305mm]
H 6" [152mm]

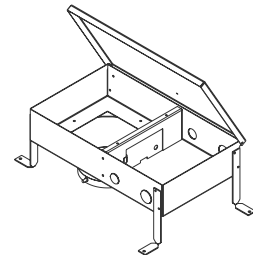

2-120-T Aurora MR16

Project

Type

Notes

Product Code

1 2 3 4

1. Trim

2-120-T Aurora

2. Lamp

MR16 Halogen

3. Flange Finish

- 01** White
- 02** Chrome Plated
- 04** Black
- 05** Matte Silver
- 06** Bronze
- 09** Gold Plated
- 11** Matte Nickel
- CC** Custom Color¹

4. Reflector Finish

- BLO** Black Open
- BA** Black Specular
- BLS** Black Stepped Baffle
- CHA** Champagne Specular
- CHAS** Champagne Satin
- COPA** Copper Specular
- COPAS** Copper Satin
- GA** Gold Specular
- GAS** Gold Satin
- MOCH** Mocha Brushed
- NICS** Nickel Satin
- SA** Silver Specular
- SAS** Silver Satin
- WHO** White Open
- WHS** White Stepped Baffle

Notes

¹ **CC** custom color requires consultation with Lightheaded sales personnel.

2-120-T-Aurora-MR16-Specs • Subject to change without notice • Rev 2016.12.19 • 4/4