



Compatible Housings

NON-INSULATED

2-025
Square Non-Insulated
L 10 1/2" [267mm]
W 7 3/4" [197mm]
H 3 1/2" [90mm]

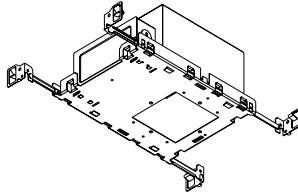


2-065
Square Non-Insulated
L 13 3/4" [349mm]
W 10 7/8" [276mm]
H 3 1/2" [90mm]

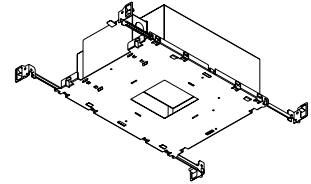


INSULATED

2-015
Square Insulated
L 13 3/4" [350mm]
W 10 7/8" [277mm]
H 7" [178mm]

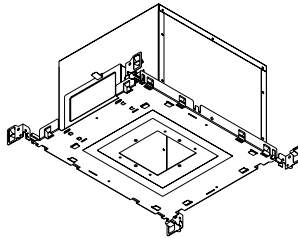


2-017
Square Insulated
L 22 1/2" [572mm]
W 8 1/2" [216mm]
H 5 7/8" [150mm]

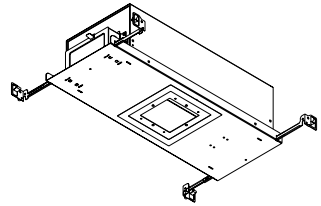


REMODEL

2-035
Square Remodel
L 14" [356mm]
W 4 1/2" [114mm]
H 5 1/8" [130mm]

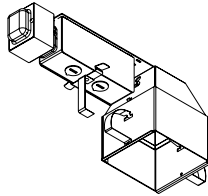


SPECIALIZED

2-065
Square Chicago Plenum
L 13 3/4" [350mm]
W 10 7/8" [277mm]
H 4 1/2" [115mm]

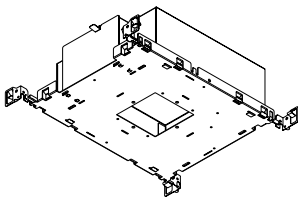

2-105
Square Concrete Housing
L 18" [457mm]
W 12" [305mm]
H 6" [152mm]

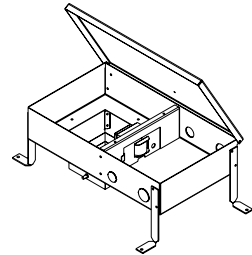

2-500-T Quadra MR16

Project

Type

Notes

Product Code

1 2 3 4 5

1. Trim

2-500-T Quadra

2. Lamp

MR16 Halogen

3. Flange Finish

01 White

02 Chrome Plated

04 Black

05 Matte Silver

06 Bronze

11 Matte Nickel

CC Custom Color¹

4. Optional Media (2 Maximum)

CL Clear

EL Elongating

FRO Frosted

HC Honeycomb

PER Perimeter Frosted

SL Solite Softening

SPDL Spread

5. Options

WP White Painted Interior

Notes

¹ **CC** custom color requires consultation with Lightheaded sales personnel.

² **WP** white painted interior. Trim interior painted black standard.

2-500-T-Quadra-MR16-Specs • Subject to change without notice • Rev 2017.08.03 • 4/4

2-500-T Quadra MR16



A clear modern aesthetic shines through in the Quadra family of square-aperture recessed downlights. Quadra was integrally engineered to ensure ultra-low glare from the deeply regressed light source.

FEATURES

- Utilizes MR16
- 360° rotation
- 30° aiming
- Powder coated and plated trim ring finishes
- Trim clips designed for 5/8" ceiling thickness
- Accepts up to 2 optional media
- Clear glass lens included
- Relamp from below the ceiling

DETAILS

Trim Class: 4"
Category: Recessed Downlight
Shape: Square
Adjustability: Tilt With Rotation



2-500-T-Quadra-MR16-Specs • Subject to change without notice • Rev 2017.08.03 • 1/4