

LET-75VA Transformer



FEATURES


- Electronic transformer
- UL and C-UL recognized
- 3oz. (86g)
- 50°C maximum ambient temperature
- 90°C maximum case temperature
- 120V, 50/60Hz input @ 0.635A
- 11.75Vac, 40kHz output @ 6.35A
- 75W maximum load
- 10W minimum load without dimmer
- 20W minimum load with dimmer
- 0.95 power factor
- Waterproof potting
- Electronic internal resettable protection, patented auto heat regulation that also automatically acts as over load protection, auto reset thermal cut-off @ 125°C.




LET-75VA-Specs • Subject to change without notice • Rev 2016.12.16 • 1/3

Features


DIMENSIONS

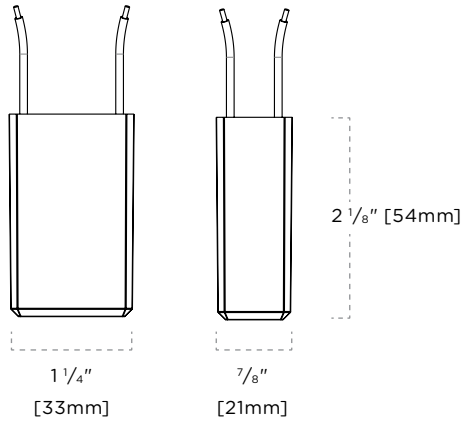

OUTPUT VOLTAGE VS. LOAD @ 120V

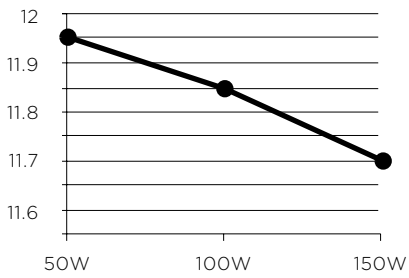

OUTPUT VOLTAGE VS. INPUT @ MAX LOAD

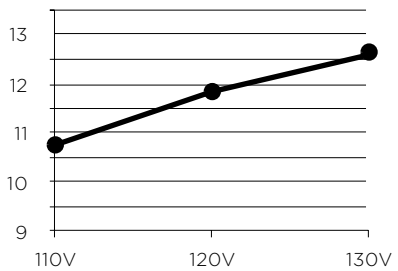

LET-75VA Transformer

Project

Type

Notes

Product Code

1

2

1. Transformer

LET-75VA

2. Voltage

120

LET-75VA-Specs • Subject to change without notice • Rev 2016.12.16 • 3/3
