



WHITE



BLACK



SATIN  
CHROME

## RZR-LED-420

### 4.00" LOW PROFILE GIMBAL LED RAZOR SERIES - 9W

#### Product codes

RZR-420-9W-3K-WH : WHITE - 3K

RZR-420-9W-3K-BLK : BLACK - 3K

RZR-420-9W-3K-SC : SATIN CHROME - 3K

RZR-420-9W-4K-WH : WHITE - 4K

RZR-420-9W-4K-BLK : BLACK - 4K


 
RZR-420-9W-4K-SC : SATIN CHROME - 4K

RZR-420-9W-5K-WH : WHITE - 5K

This low profile gimbal unit is IC and AIR TIGHT rated and with its low profile allows installation in almost any location. It is suitable for damp locations, such as a shower and outdoors in soffits. Included with the unit is a junction box with driver, pressure fit clips and Quick Connect wire connectors for quick and easy installation. The junction box has integrated screw holes to allow the box to be secured to studs or joists, if needed. The maximum number of the 9W fixtures that can be installed with a standard 150W LED dimmer is 16 units. The 3K & 4K models replace a 600 lumen 50W halogen style bulb. This product is CSA certified in Canada and the US conforms to UL standard 1598 and CSA standard C22.2 NO. 250.0, and includes the following:

The wiring compartment accommodates up to (6) 14 gauge insulated conductors to satisfy luminaire junction box volume requirements.

A complete listing of compatible dimmers may be found in our "Product Knowledge" section of our site. Although this product is AIR-TIGHT rated, some municipalities will require the use of a vapor barrier. Verify local building codes prior to installation.

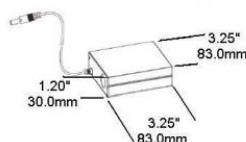

#### Don'ts techniques

Cutting hole	4.50" (114.3 mm)
--------------	------------------

Beam Angle	107° 1/2
------------	----------

Adjustment angle	20° 1/2
------------------	---------

Color Temperature	3K / 4K
-------------------	---------

CRI	>80
-----	-----

Dimmable	Y
----------	---

Mounting Plate	MP/AMP/MPHB 450
----------------	-----------------

LED Life	50 000hrs
----------	-----------