




WHITE



BLACK



SATIN
CHROME

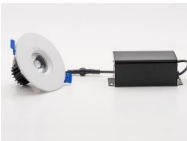

OB-LED-300

3" HIGH PERFORMANCE ORBIT SERIES - 10W

Product codes

OB300-0510-27K-WH : WHITE - 27K

OB300-0510-3K-WH : WHITE - 3K

OB300-0510-3K-BK : BLACK - 3K

OB300-0510-3K-SC : SATIN CHROME - 3K

OB300-0510-3K-BRZ : BRONZE - 3K

OB300-0510-4K-WH : WHITE - 4K

OB300-0510-4K-BK : BLACK - 4K

OB300-0510-4K-SC : SATIN CHROME - 4K

OB300-0510-4K-BRZ : BRONZE - 4K

OB300-0510-5K-WH : WHITE - 5K

OB300-0510-3K-WH-CRI90 : WHITE - 3K (CRI90)

OB300-0510-4K-WH-CRI90 : WHITE - 4K (CRI90)

High performance LED recessed downlight with a pressure-fit spring clips application for an easy install. Integrated COB technology offers low-energy, long lasting performance with outstanding light outputs of 850 LUMENS. Available in a CRI 80 or CRI 90 version.

Suitable for residential applications, this recessed LED light source offers an anti-glare lighting. A 36 degree focused beam angle with a 360 degree rotation will answer many lighting applications.

The body is constructed of die cast aluminum, with junction box manufactured in aluminum extrusion. For easy and quick installation, the unit comes with pressure-fit spring clips and quick connect wire connectors. Dimmable driver included. It is IC rated and suitable for dry, damp & wet locations.

An optional 120-277V, 0-10V dimmable driver available

Données techniques

Cutting hole	3.25" (82.6 mm)
Beam Angle	36° ± 1/2
Adjustment angle	27° ± 1/2
Head Rotation	360° ± 1/2
Color Temperature	3000k / 4000k
Mounting Plate	MP300/AMP300/MPHB-300
CRI	>80 or 90

