

**3, 4 & 6 Lamp
T8 OR T5HO**

The SHE and TSHE Fluorescent High Bay luminaire features 95% reflective aluminum reflectors and a solid enclosure design for an efficient alternative in industrial lighting applications.

CONSTRUCTION/FINISH


- Enclosed housing design
- Suitable for chain mounting only. Can not be surface mounted
- Housing is multi-stage phosphate treated for maximum corrosion resistance and finish coat is high reflectance baked white enamel
- 1.5" deep individual cavity reflectors are made from high reflectance, specular aluminum Miro 4
- Top access plate standard
- "V" Hook included
- Suitable for row-mounting
- Optional wireguard or lens available

ELECTRICAL

- cUL listed for damp locations and 40° C ambient
- Energy saving electronic ballasts are standard
- Complete with 6 ft cord (no plug)

Sample Catalogue Number: TSHE332-UNV-1/42EBH-WG-SHE-4LP

CATALOG NUMBER

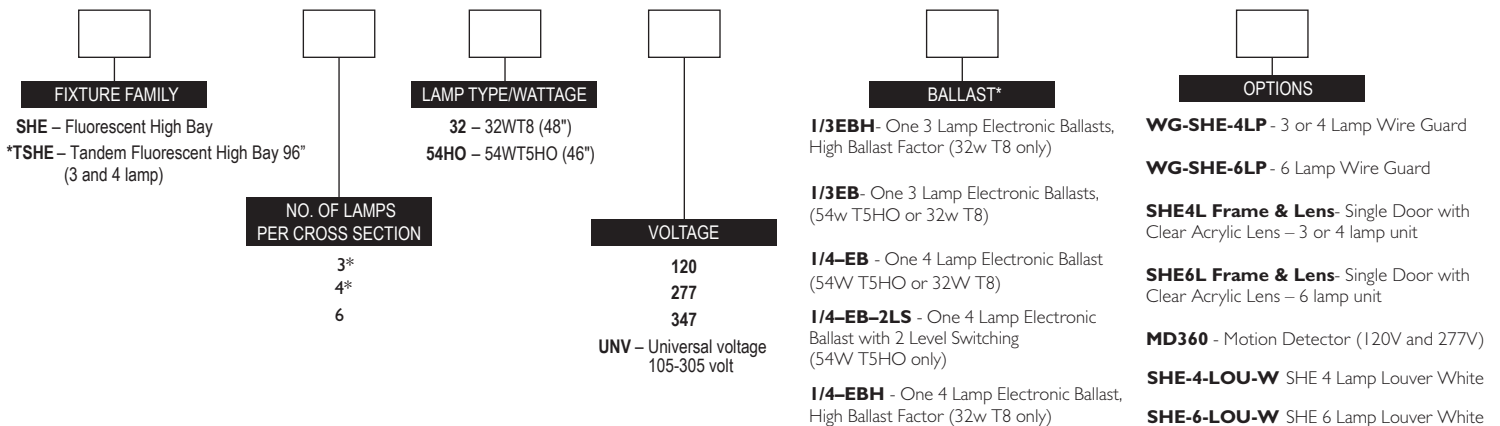

ENERGY DATA


LAMP WATTS	BALLAST TYPE	INPUT WATTS	Size	Family	Lamps Cross Section	Lamp
32	1/3 EBH	110	4	SHE	3,4,6	32, 54HO
	1/4-EBH	146	8*	TSHE	3,4	32, 54HO
	1/42-EBH	220				
	1/4 EB	112				
	2/4-EBH	292				
	2/4-EB	224				
	1/42-EB	171				
	1/3-EB	85				
54	1/4 EB	240				
	2/4 EB	480				
	1/42 EB	358				
	1/3-EB	182				

General Notes:
All options are field installed.


Job name: _____

Type: _____



DIMENSIONS 6 LAMPS

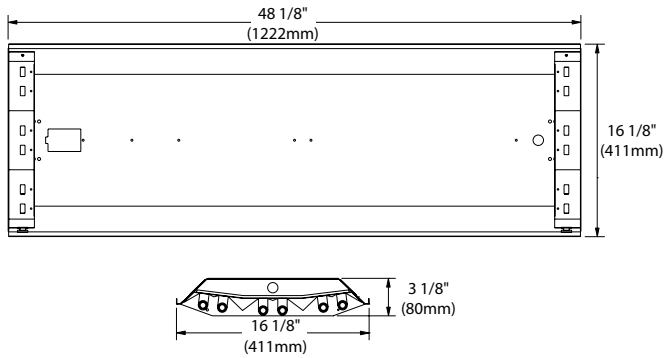

DIMENSIONS 3 or 4 LAMPS C 0609.3

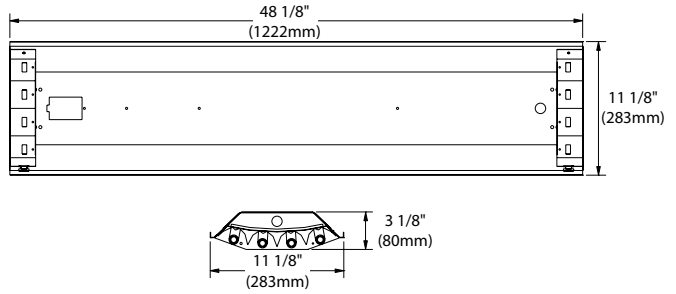

DIMENSIONS 6 and 8 LAMPS

 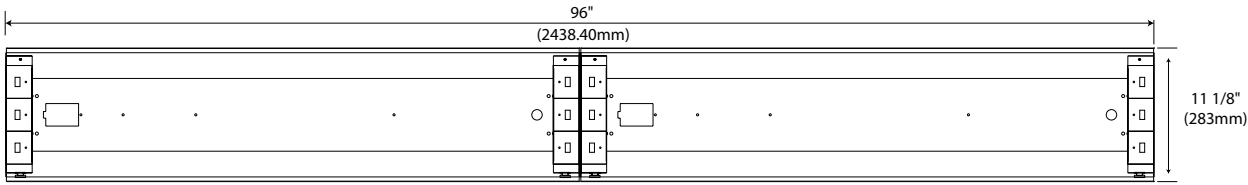


ACCESSORIES


MD360 – Motion Detector UNV, (120-277V), 347v
 (field installed, ordered separately)



MD360

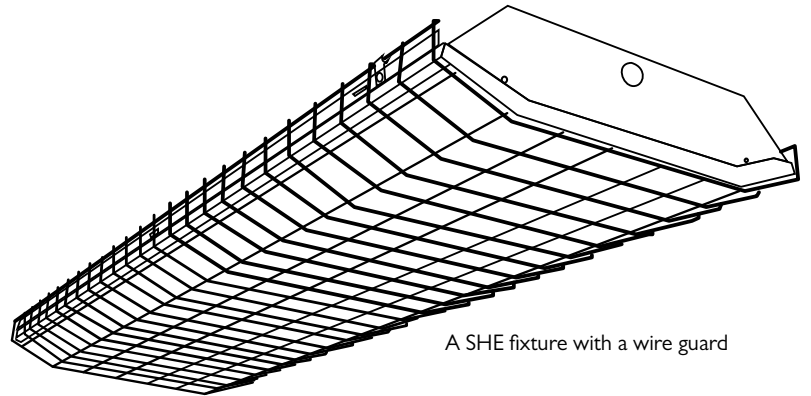

A SHE fixture with a wire guard

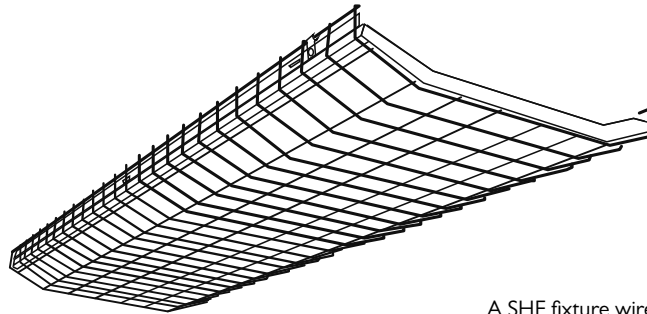

A SHE fixture wire guard