

12VDC Surface / Recess Mount LED Slim Puck

Pucks have come a long way since we first introduced them to our customers over 10 years ago. Our 120V LED Slim Puck incorporates superior quality matched with the latest LED technology.

At a slim 1/4" depth, Slim Puck employs a unique trim that is captured to the recess or surface mounting, magnetically. At 2.2W, Slim Puck boasts up to 180 lumens in either 3000K or 4000K.



SLIM PUCK FEATURES

- 12VDC operation
- 3000k or 4000K
- Dimmable (ELV or MLV)*
- Surface or Recess Mount
- Magnetic Cover Plates
- 48" leads
- Max. pucks 20 per lead
- ETL
- 5 Year Warranty


*ELV low voltage (electric)
MLV low voltage (magnetic)



At only 1/4" slim, the LED Slim Puck provides an unobtrusive, sleek profile.



Black Slim Puck

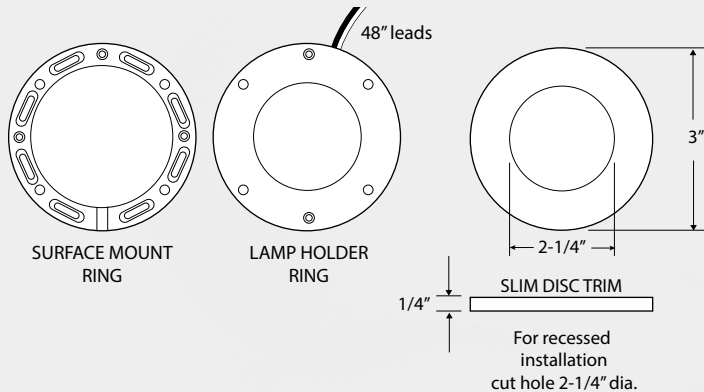

ORDERING INFORMATION

| Catalog No. | Dimensions | Wattage | Lumens | Color Temp.* | CRI | Finish |
|-------------|----------------------|---------|--------|--------------|-----|----------------|
| SP-2-30-W | 3" dia. x 1/4" depth | 2.2W | 170 | 3000K | 80+ | White |
| SP-2-30-BNK | 3" dia. x 1/4" depth | 2.2W | 170 | 3000K | 80+ | Brushed Nickel |
| SP-2-30-B | 3" dia. x 1/4" depth | 2.2W | 170 | 3000K | 80+ | Black |
| SP-2-30-BZ | 3" dia. x 1/4" depth | 2.2W | 170 | 3000K | 80+ | Bronze |
| SP-2-40-W | 3" dia. x 1/4" depth | 2.2W | 180 | 4000K | 80+ | White |
| SP-2-40-BNK | 3" dia. x 1/4" depth | 2.2W | 180 | 4000K | 80+ | Brushed Nickel |
| SP-2-40-B | 3" dia. x 1/4" depth | 2.2W | 180 | 4000K | 80+ | Black |
| SP-2-40-BZ | 3" dia. x 1/4" depth | 2.2W | 180 | 4000K | 80+ | Bronze |

* Kelvin temperature (color) ± 200K