

# 12VDC Surface / Recess Mount LED Slim Puck

Pucks have come a long way since we first introduced them to our customers over 10 years ago. Our 120V LED Slim Puck incorporates superior quality matched with the latest LED technology.

At a slim 1/4" depth, Slim Puck employs a unique trim that is captured to the recess or surface mounting, magnetically. At 2.2W, Slim Puck boasts up to 180 lumens in either 3000K or 4000K.



## SLIM PUCK FEATURES

- 12VDC operation
- 3000k or 4000K
- Dimmable (ELV or MLV)\*
- Surface or Recess Mount
- Magnetic Cover Plates
- 48" leads
- Max. pucks 20 per lead
- ETL
- 5 Year Warranty


\*ELV low voltage (electric)  
MLV low voltage (magnetic)



At only 1/4" slim, the LED Slim Puck provides an unobtrusive, sleek profile.



Black Slim Puck

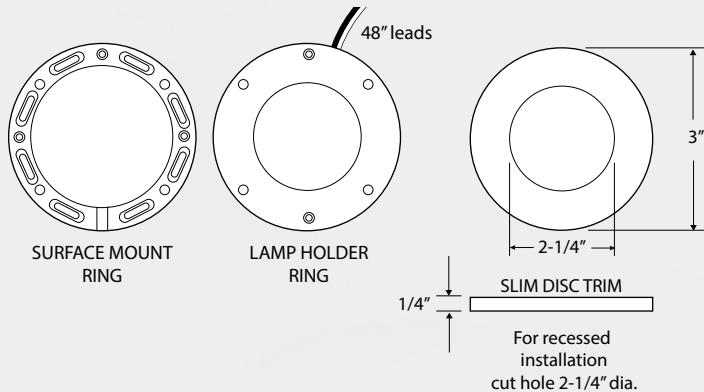

## ORDERING INFORMATION

Catalog No.	Dimensions	Wattage	Lumens	Color Temp.*	CRI	Finish
SP-2-30-W	3" dia. x 1/4" depth	2.2W	170	3000K	80+	White
SP-2-30-BNK	3" dia. x 1/4" depth	2.2W	170	3000K	80+	Brushed Nickel
SP-2-30-B	3" dia. x 1/4" depth	2.2W	170	3000K	80+	Black
SP-2-30-BZ	3" dia. x 1/4" depth	2.2W	170	3000K	80+	Bronze
SP-2-40-W	3" dia. x 1/4" depth	2.2W	180	4000K	80+	White
SP-2-40-BNK	3" dia. x 1/4" depth	2.2W	180	4000K	80+	Brushed Nickel
SP-2-40-B	3" dia. x 1/4" depth	2.2W	180	4000K	80+	Black
SP-2-40-BZ	3" dia. x 1/4" depth	2.2W	180	4000K	80+	Bronze

\* Kelvin temperature (color) ± 200K