

# LED InstantFit Lamps

## 11T5HE/34-850/IF15/G/DIM 10/1

Philips LED T8 InstantFit Lamps are an ideal energy saving choice for existing linear fluorescent fixtures.

### Product data

<b>General Information</b>		<b>Voltage (Nom)</b>		50-80 V
Cap-Base	G5 [ G5]	<b>Temperature</b>		
Nominal Lifetime (Nom)	50000 h	T-Ambient (Max)	45 °C	
Switching Cycle	50000X	T-Ambient (Min)	-20 °C	
B50L70	50000 h	T-Storage (Max)	65 °C	
<b>Light Technical</b>		T-Storage (Min)	-40 °C	
Color Code	850 [ CCT of 5000K]	T-Case Maximum (Nom)	70 °C	
Beam Angle (Nom)	200 °	<b>Controls and Dimming</b>		
Initial lumen (Nom)	1500 lm	Dimmable	Yes	
Luminous Flux (Rated) (Nom)	1500 lm	<b>Mechanical and Housing</b>		
Rated Beam Angle	200 °	Product Length	900 mm	
Correlated Color Temperature (Nom)	5000 K	<b>Approval and Application</b>		
Color Consistency	<5	Energy Saving Product	Yes	
Color Rendering Index (Nom)	82	Approbation Marks	UL certificate RoHS compliance	
LLMF At End Of Nominal Lifetime (Nom)	70 %	<b>Product Data</b>		
<b>Operating and Electrical</b>		Order product name	11T5HE/34-850/IF15/G/DIM 10/1	
Input Frequency	40000-110000 Hz	EAN/UPC - Product	046677476489	
Power (Rated) (Nom)	11 W	Order code	476481	
Lamp Current (Max)	400 mA	Numerator - Quantity Per Pack	1	
Lamp Current (Min)	60 mA	Numerator - Packs per outer box	10	
Starting Time (Nom)	0.5 s			
Warm Up Time to 60% Light (Nom)	0.5 s			
Power Factor (Nom)	0.9			


LED InstantFit Lamps

Material Nr. (12NC)	929001823804
Net Weight (Piece)	0.110 kg
Model Number	9290018238

Warnings and Safety

- Perform a visual inspection to ensure lamp holders (or sockets) are not damaged or loose. If the lamp holders (or sockets) are damaged, corroded, charred, blackened or loose, contact a qualified electrician for proper replacement.
- Please refer to the ballast compatibility guide located at [www.philips.com/instantfit](http://www.philips.com/instantfit).



Dimensional drawing

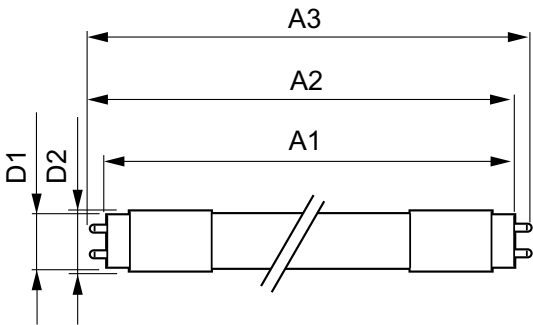


TLED 900mm HFV11.5-21W 1500lm 5000K ND

Product	D1	D2	A1	A2	A3
11T5HE/34-850/IF15/G/DIM 10/1	15.3 mm	18.4 mm	847.8 mm	854.9 mm	862 mm

Photometric data

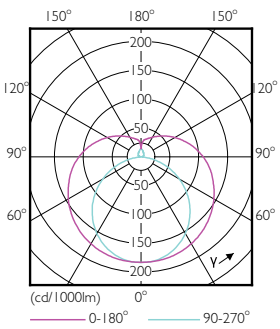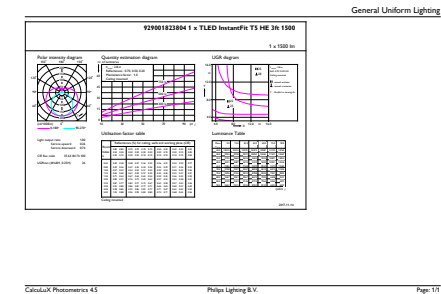



LEDtube 8W G5 830 200D DIM IF10

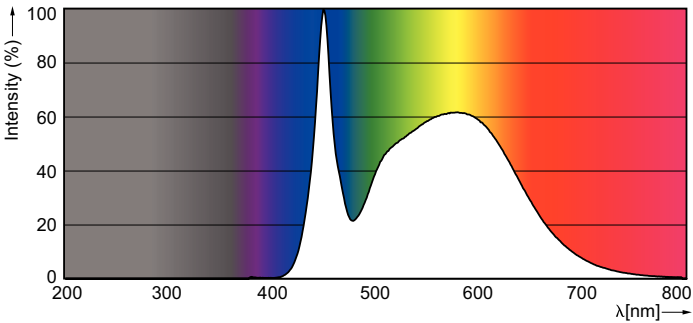


LEDtube 1200mm 12W G13/850

LED InstantFit Lamps


Lifetime

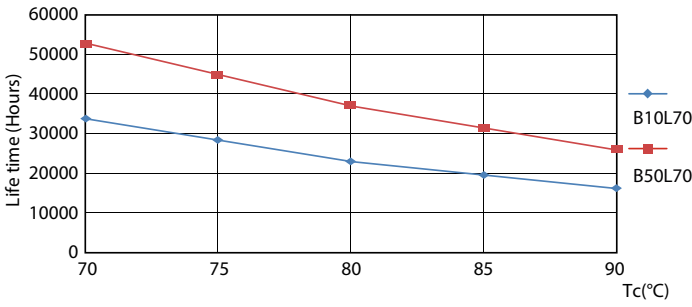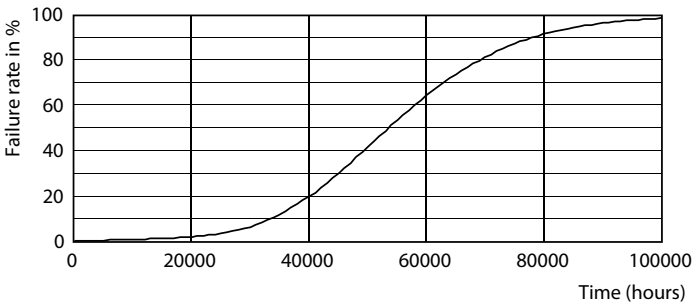


LEDtube 8-14W G5 830-850 200D DIM IF10-21

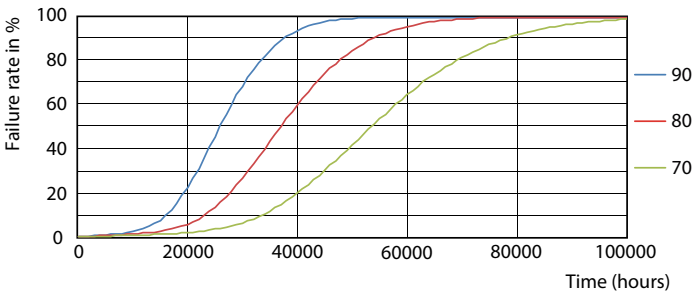

LEDtube 8-14W G5 830-850 200D DIM IF10-21

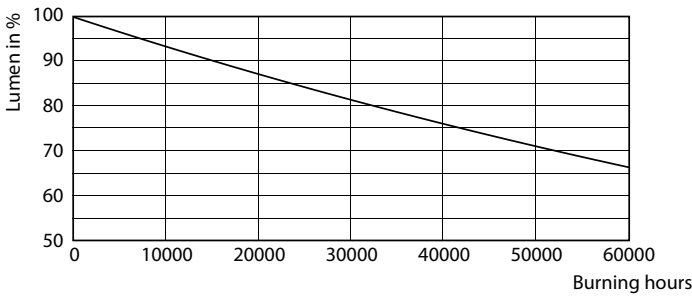

LEDtube 8-14W G5 830-850 200D DIM IF10-21

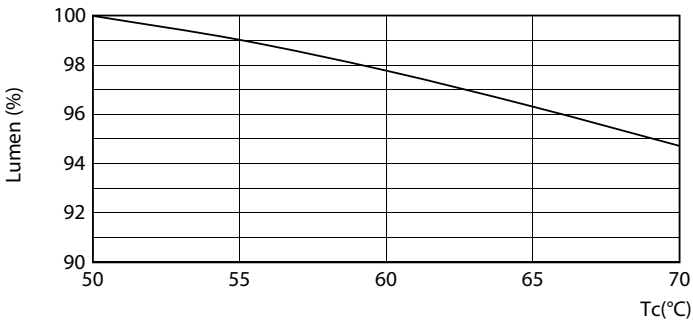

LEDtube 8-14W G5 830-850 200D DIM IF10-21

LEDtube 8-14W G5 830-850 200D DIM IF10-21