


Category 6

CMR/CMP

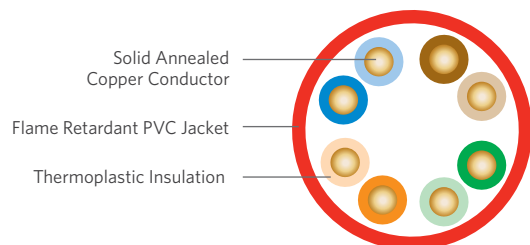

SPECIFICATIONS

Pair Count	4
Conductor	Solid annealed copper
AWG (mm)	23 (0.57)
Insulation	CMR: Polyolefin CMP: FEP
Insulation Colors	Pair 1: ColorTip Light Blue, Blue Pair 2: ColorTip Light Orange, Orange Pair 3: ColorTip Light Green, Green Pair 4: ColorTip Light Brown, Brown
Jacket	CMR: Flame retardant (FR) PVC CMP: FR, low smoke PVC
Characteristic Impedance Ohms	100 ± 15
Nominal Velocity of Propagation %	CMR: 70 CMP: 73
Performance Compliance	UL 444 CSA C22.2 No. 214-08 UL 1666 NFPA 262 ANSI/TIA-568-C.2 Article 800, NEC (NFPA 70)
NRTL Programs	UL Verified CAT 6 UL, c(UL) Listed CMR UL, c(UL) Listed CMP
Sustainability	UL Certified EPD HPD Multi-Attribute Certification USGBC® Member RoHS-compliant/RoHS 2-compliant REACH-compliant

PRODUCT DESCRIPTION



FIRST MANUFACTURER IN THE INDUSTRY
to offer products that contribute toward LEED!

Superior Essex Series 77 product line provides exceptional value for jobs that require standards compliant Category 6 cable at a cost-effective price.

APPLICATIONS

- 10BASE-T through 1000BASE-T Ethernet
- Power over Ethernet (PoE) – IEEE 802.3af
- PoE+ – IEEE 802.3at Type 1 and 2
- ATM and token ring

FEATURES

- UL Certified Environmental Product Declaration (EPD)
- Health Product Declaration™ (HPD™)
- Multi-Attribute Certification by GreenCircle Certified, LLC
- Meets ANSI/TIA-568-C.2 specification
- BrakeBox® payout control system
- CableID® alpha numeric code printed every 2 feet
- QuickCount® marking system in feet and meters
- ColorTip® circuit identification system
- Color coded box labels

BENEFITS

- Contributes toward 1 LEED point under the Material and Resources credit (MRC)
- Contributes toward 1 LEED point under the MRC
- Offers an overview of the sustainability of a product, its packaging and manufacturing
- Provides cost effective solution
- Adjustable tension control on reel prevents over spin and entangling of cable
- Allows both ends of a cable run to be easily identifiable without the need to separately label or tone the cable
- Provides remaining length of cable on reel
- Easily identifiable conductor mates even in low-light environments
- Easily identifies jacket colors

PART NUMBERS AND PHYSICAL CHARACTERISTICS

Listing	Part Number ¹	Nominal Diameter in (mm)	Approx. Weight lbs/kft (kg/km)	Package
CMR	77-xxx-yA	0.21 (5.3)	22 (33)	use key
CMP	77-xxx-yB	0.20 (5.1)	23 (34)	use key

PACKAGING

	150 ft Coil	200 ft Coil	250 ft Coil	300 ft Coil	1,000 ft POP Box	1,000 ft BrakeBox	1,000 ft Plywood Reel	2,500 ft Plywood Reel
¹ Replace "xxx" with:	225	229	230	231	240	246	272	273
Packages per Pallet	120	120	144	120	36	27	16	12

JACKET COLORS

¹Replace "y" with: Blue = 2 Gray = 3 White = 4 Green = 5 Yellow = 6 Purple = 7 Red = 9 Pink = C Orange = D Black = E

ELECTRICAL SPECIFICATIONS

Frequency MHz	Insertion Loss @ 20°C Maximum dB/100 m		NEXT Minimum dB/100 m		ACR Minimum dB/100 m		PSNEXT Minimum dB/100 m	
	TIA-568-C.2	Superior Essex	TIA-568-C.2	Superior Essex	TIA-568-C.2	Superior Essex	TIA-568-C.2	Superior Essex
	Specified	Typical	Specified	Typical	Calculated	Typical	Specified	Typical
1	2.0	1.7	74.3	82.9	72.3	82.2	72.3	81.9
4	3.8	3.4	65.3	77.6	61.5	74.2	63.3	75.0
8	5.3	4.8	60.8	74.4	55.4	68.9	58.8	71.9
10	6.0	5.4	59.3	70.1	53.3	64.7	57.3	68.3
16	7.6	6.9	56.2	69.6	48.6	62.5	54.2	67.1
20	8.5	7.8	54.8	68.7	46.3	60.7	52.8	65.7
25	9.5	8.8	53.3	66.1	43.8	58.7	51.3	64.7
31.25	10.7	9.8	51.9	67.8	41.2	56.2	49.9	63.4
62.5	15.4	14.2	47.4	64.0	32.0	47.8	45.4	59.1
100	19.8	18.2	44.3	58.0	24.5	38.7	42.3	55.0
155	25.2	23.0	41.4	54.5	16.3	31.6	39.4	52.1
200	29.0	26.6	39.8	53.8	10.8	26.5	37.8	50.6
250	32.8	30.1	38.3	51.0	5.5	21.1	36.3	48.7
300		33.4		53.8		19.4		49.1
350		36.5		50.1		14.3		47.5
400		39.5		49.1		8.0		44.5
450		42.3		44.6		3.3		43.4
500		45.1		42.9				41.7
550		47.7		41.6				39.1

Frequency MHz	PSACR Minimum dB/100 m		Return Loss Minimum dB/100 m		ELFEXT Minimum dB/100 m		PSELFEXT Minimum dB/100 m	
	TIA-568-C.2	Superior Essex	TIA-568-C.2	Superior Essex	TIA-568-C.2	Superior Essex	TIA-568-C.2	Superior Essex
	Calculated	Typical	Specified	Typical	Specified	Typical	Specified	Typical
1	70.3	80.2	20.0	26.0	67.8	78.7	64.8	76.6
4	59.5	71.6	23.0	31.1	55.8	65.9	52.8	64.2
8	53.4	67.1	24.5	34.5	49.7	60.1	46.7	58.4
10	51.3	62.9	25.0	36.3	47.8	58.1	44.8	56.4
16	46.6	60.2	25.0	37.7	43.7	54.0	40.7	52.2
20	44.3	58.1	25.0	36.0	41.8	52.1	38.8	50.3
25	41.8	56.1	24.3	38.6	39.8	50.2	36.8	48.4
31.25	39.2	53.6	23.6	38.3	37.9	48.1	34.9	46.4
62.5	30.0	45.0	21.5	32.8	31.9	41.4	28.9	40.3
100	22.5	37.0	20.1	30.7	27.8	36.8	24.8	35.2
155	14.3	29.1	18.8	28.8	24.0	33.3	21.0	31.9
200	8.8	24.0	18.0	27.6	21.8	32.6	18.8	31.8
250	3.5	18.8	17.3	28.5	19.8	32.5	16.8	31.3
300		15.8		28.6		30.8		28.9
350		11.6		29.0		26.8		25.4
400		5.0		24.9		24.7		23.5
450		1.2		23.9		23.2		21.9
500				25.0		22.5		21.5
550				24.2		22.4		22.0

SUSTAINABILITY LEADERSHIP



UL and the related logo are registered trademarks of UL LLC. Health Product Declaration, HPD and the related logo are trademarks of Health Product Declaration Collaborative. GreenCircle Certified logo is a registered trademark of GreenCircle Certified, LLC. USGBC and the related logo are registered trademarks of U.S. Green Building Council.