

Technical Information Bulletin

LED Puck Light



Date: _____ Name of distributor: _____
 In hands date of project: _____ Client #: _____
 Project name/Number: _____ Name of end user: _____

ORDERING INFORMATION

Order code: 67175
 Description: UCP/KIT3/12V/2.2W/40K/FR/BLK/STD
 UPC: 69549671751
 Case quantity: 30

PHYSICAL DATA

Type: LED Puck Light - kit of 3 units
 Size (in): 3"
 Shape: Round
 Finish: Black
 Lens Finish: Frosted
 Mounting: Surface and Recessed
 Wire Length (ft.): 4
 Wire gauge (AWG): 24
 Daisy Chain installation: Up to 10 pucks can be installed in daisy chain




PERFORMANCE DATA

Watts (W) per unit: 2.2
 Volts (VDC): 12
 Colour temp. (K)¹: 4 000
 Lumen output (lm) per unit: 150
 Lumen per Watts (lm/W) per unit: 68
 CRI: 90
 Life L70 (h)²: 50 000
 Beam angle (°): 120
 Operating temp. range: -20°C to 40°C (-4°F to 104°F)

¹ Typical colour temperature range: +/- 5 %
² Life hours are derived from IESNA LM80-08 testing report and projected per IESNA TM-21-11 extrapolations



TECHNICAL DRAWINGS AND DIMENSIONS

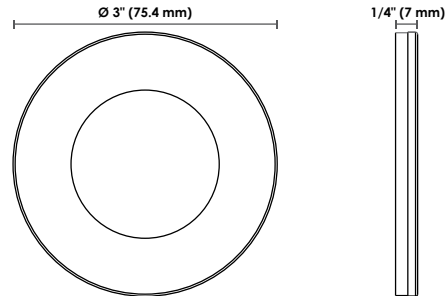

COMPATIBLE ACCESSORIES

| Order code | Description | Type |
|------------|---------------------------|------------------------------------|
| 67180 | UCP/TRIM/BACKPLATE/WH/STD | White trim and back plate |
| 67182 | UCP/TRIM/BACKPLATE/BN/STD | Brushed nickel trim and back plate |
| 67183 | UCP/ACC/HUB6/STD | Hub for 6 LED Puck Lights |
| 67185 | UCP/ACC/DIMMER/STD | Dimmer Switch |
| 67186 | UCP/ACC/MOTIONSENSOR/STD | Motion Sensor |

COMPATIBLE DRIVERS

| Order code | Description |
|------------|----------------------------------|
| 67184* | LED/DRIVER/12W/12V/PLUG/ND/STD |
| 62265 | LED/TAPE/36W/12V/WW+CW/PS/ND/STD |
| 65743 | LED/DRIVER/10W/12V/HW/ND/STD |
| 65744 | LED/DRIVER/20W/12V/HW/ND/STD |
| 65740 | LED/DRIVER/50W/12V/HW/D/STD |
| 65745 | LED/DRIVER/60W/12V/HW/ND/VS/STD |
| 65746 | LED/DRIVER/60W/12V/HW/ND/STD |
| 67071 | DRIVER-DIMMER/12V/60W/WH/STD |

*(Included in the kits of 3 units)

DESCRIPTION AND OTHER OPTIONS

| UCP | / | KIT3 | / | 12V | / | 2.2W | / | 40K | / | FR | / | BLK | / | STD |
|------------------------|-----|----------|-------|----------|-------|-----------|--------------------|---------|-------------|---------|-------------|---------|----------------|----------|
| Family | Kit | | Volts | | Watts | | Colour Temperature | | Lens Finish | | Trim Colour | | Brand | |
| UCP Undercabinet Pucks | 3 | Kit of 3 | 12V | 12 Volts | 2.2W | 2.2 Watts | 30K | 3 000 K | 40K | 4 000 K | FR | Frosted | WH | White |
| | | | | | | | | | | | | BLK | Black | STD |
| | | | | | | | | | | | | BN | Brushed nickel | STANDARD |

| Qty | Description | Price |
|-----|-------------|-------|
| | | |

I accept the specifications of the luminaire configuration mentioned above.

Name: _____

Company: _____

Signature: _____

Date: _____

Data is based upon tests performed in a controlled environment and representative of relative performance. Actual performance can vary depending on operating conditions. Specifications are subject to change without notice. March 27, 2019