

Commercial grade switches

Designed for the most demanding commercial applications

Arrow Hart's commercial grade switches are designed to provide superior quality, reliability and performance in a variety of commercial environments

Commercial grade AC switch features & benefits

Automatic grounding eliminates need for bonding jumper in metal enclosures

Welded construction provides superior assembly security under heavy use

Smooth face for ease of cleaning

Built-in wire stripper to speed up installation

Tri-combo head terminal and mounting screws, plus easy-access grounding terminal

Stippled line and ground contacts ensure solid contact; ground screw clamp provides secure wiring

Tapered back-wire openings handle multiple sizes and types, up to #10 AWG solid or stranded wire

Oversized termination screws for simplified wire installation

Horsepower rated for motor loads

Horsepower rated for motor loads per UL20				
Amps	120V/AC	240V/AC	277V/AC	Max.
15A	1/2 HP	2HP	2HP	12A
20A	1HP	2HP	2HP	16A

A complete line of switches available for any commercial application:



Combination switches



CuVerro® antimicrobial surfaces



Commercial grade CSB series



Commercial grade CS series


Compliances, specifications and availability are subject to change without notice.

www.eaton.com
www.eaton.com/arrowhart

Commercial grade AC decorator switches

Product description

Single-pole, double-pole, 3-way, 4-way
 15A, 120/277V/AC;
 20A, 120/277V/AC

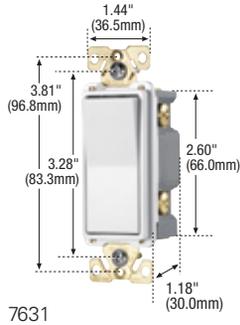

AC decorator switches, back & side wire



Rating A	V/AC	Description	Color suffix	Catalog no.	
20	120/277	Single-pole, lighted decorator	A, LA, V, W	□ 7631__	• • •
		3-Way, lighted decorator	LA, V, W	□ 7633__	• •
		4-Way, lighted decorator	LA, V, W	□ 7634__	• •

AC decorator switches, back & side wire



Rating A	V/AC	Description	Color suffix	Catalog no.	
15	347	Single-pole, decorator	V, W	□ 7601-347__	• • •
		3-Way, decorator	V, W	□ 7603-347__	• •
		4-Way, decorator	V, W	□ 7604-347__	• •
20	347	Single-pole, decorator	V, W	□ 7621-347__	• • •
		Double-pole, decorator	V, W	□ 7622-347__	• •
		3-Way, decorator	V, W	□ 7623-347__	• •
		4-Way, decorator	V, W	□ 7624-347__	• •


AC decorator switches, back & side wire



Rating A	V/AC	Description	Color	Catalog no.	
15	120/277	Single-pole, two position, momentary contact, decorator	W	□ 7521W	•

Color ordering information:

 For ordering devices, include Catalog no. followed by the Color suffix: A (Almond), LA (Light Almond), V (Ivory), W (White)



Specification information: 120/277V/AC commercial ArrowLink modular: E-43, 120/277V/AC commercial decorator: E-40
Compliances, specifications and availability are subject to change without notice.

➤ ArrowLink option available. Add "M" suffix to standard catalog number (example AH8300W, AH8300WM). For ordering information on ArrowLink & ArrowLink SPD connectors, see Page E-4

Build-to-spec customizable devices - Page E-6
 RoHS compliant - Page Q-32