


Service masts

Service entrance masts and accessories

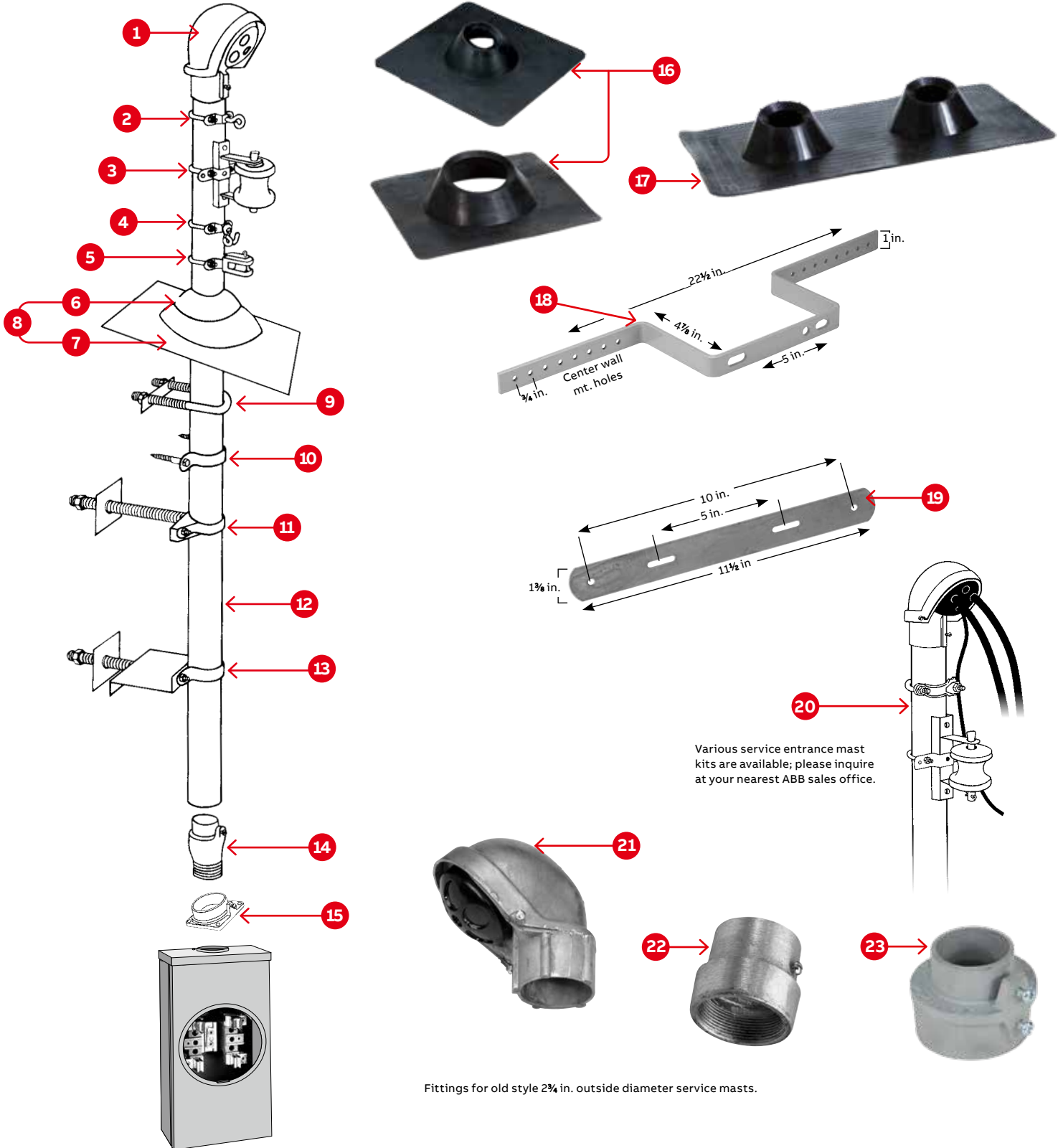

Service masts

Service entrance masts and accessories

Reference no.	Cat. no.	lb/kg 100 pcs	Std. pkg.	Description
1	MM104	105/47.1	20	1¼ in. Entrance cap 100 A
	MM105	130/59	10	1½ in. Entrance cap 150–200 A
	MM202	200/90	10	2 in. Entrance cap 200 A
2	MM380	50/22.7	50	Guy attachment comes with oval eye
	MM380A	50/22.7	50	Guy attachment without oval eye, complete with bracket
3	MM101	125/56	20	Light-duty spool rack 100 A
	MM5101	164/74	20	Light-duty spool rack (Alberta only) 100 A
	MM201	300/136	10	Heavy-duty spool rack 200 A
	MM801	360/163	10	Heavy-duty spool rack 400 A, fits 4 in. rigid conduit
4	MM390	50/22.7	50	Drop wire hook bracket
5	MM300	100/45.4	20	Service mast wire holder
6	MM500	14/6.3	50	Neoprene collar only
	MM501	36/16.3	20	Steel collar only
7	MM502	150/68	10	Roof base flange only
8	MM503	180/81	10	Roof flange, comes with steel collar
	MM505N	140/63	10	Roof flange, comes with neoprene collar
	MM5505N	140/63	10	Roof flange, comes with neoprene collar 1¼ in.
9	MM250	125/56	20	½ in. dia. "U" bolt mast clamp
10	MM251	40/18.1	50	Pipe strap, comes with two ¾ in. x 4 in. lag screws
	MM255	40/18.1	50	Pipe strap, comes with two ¾ in. x 5 in. lag screws
	MM252	30/13.6	50	Pipe strap only, no lag screws
11	MM400	225/102	20	Support clamp, comes with ¾ in. x 10 in. fully threaded bolt and 4 in. x 4 in. square washer
	MM401	110/50	20	Clamp only, no bolt and washer
	MM445	215/97	20	Support clamp, comes with ¾ in. x 4½ in. fully threaded bolt and 4 in. x 4 in. square washer
	MM5400	215/97	20	Support clamp, comes with ½ in. x 10 in. bolt
12	MM8	2,800/1272	50	8 ft. x 2½ in. outside diameter mast
	MM9CM	3,300/1500	50	9 ft. x 2½ in. outside diameter mast
	MM10	3,500/1590	50	10 ft. x 2½ in. outside diameter mast
	MM12	4,200/1909	50	12 ft. x 2½ in. outside diameter mast
13	MM600	235/106	20	Meter spacer, complete with pipe strap; ¾ in. x 4½ in. carriage bolt and 4 in. x 4 in. square washer
	MM601	190/86	20	Same as above except no pipe strap
	MM602	150/68	20	Spacer only (less strap, bolt and washer) (suggested for brick applications with MM201 less pipe strap)
	MM602LD	119/54	20	Light-duty spacer only (less strap, bolt and washer)
	MM603	200/90	20	Spacer with pipe strap (less bolt and washer)
14	MM100	36/16.3	25	1 in. Female reducer
	MM140	44/20	25	1¼ in. Female reducer
	MM140M	44/20	25	1¼ in. Male reducer
	MM150	44/20	25	1½ in. Female reducer
	MM150M	44/20	25	1½ in. Male reducer
	MM200	44/20	25	2 in. Female reducer
	MM200M	44/20	25	2 in. Male reducer
15	MH200	40/18	1	2 in. Mast adaptor
	MH40	103/46.82	10	4 in. Mast coupler
16	MM506N	52/23.6	10	Simple all-neoprene roof flange, 200 A, for 2½ in. masts
	MM806N	100/45	10	Simple all-neoprene roof flange, 400 A, for 4 in. masts
17	MM507DN	93/42.3	10	Double all-neoprene roof flange; for 2½ in. masts
18	MM604	150/68	10	Meter socket bracket (Dimensions see page D66)
19	MM605	50/22.7	25	Meter socket mounting bracket (Dimensions see page D66)
20	MM700	85/38.6	50	Service mast ground clamp, wire range: 8–1/0 AWG
21	MM202P	200/90	10	2 in. Entrance cap for old style 2¾ in. service masts
	CIEFA-4	590/268	1	4 in. entrance head
22	MM200P	44/20	20	2 in. Female reducer for old style 2¾ in. service masts
23	MC250	45/21	30	2½ in. one-piece coupler (check the installation standards in your region before using the product)