


Safety grip hospital grade plugs & connectors features & benefits



Safety grip hospital grade devices exceed federal spec. and hospital grade testing for use in demanding healthcare environments

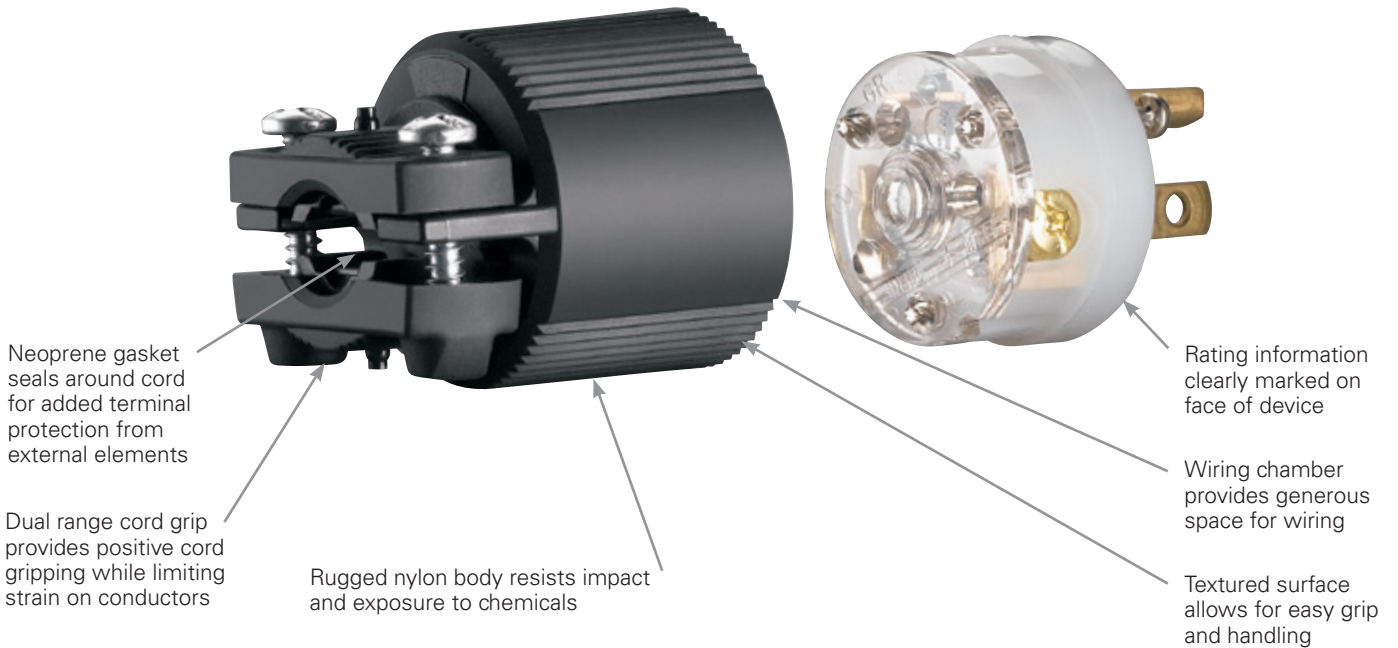

Clear terminal cover allows for easy inspection of conductors and terminations



Retained quick drive assembly screws speed installation



Four position angled plug option is ideal for applications requiring power cord to lay close to walls and floors



Tapered, individual wire pockets guide stranded wire into contact area for ease of installation




Multiple-head drive screws provide versatility for ease of use

Compliances, specifications and availability are subject to change without notice.

www.eaton.com
www.eaton.com/arrowhart

Quick grip hospital and industrial grade plugs & connectors features & benefits

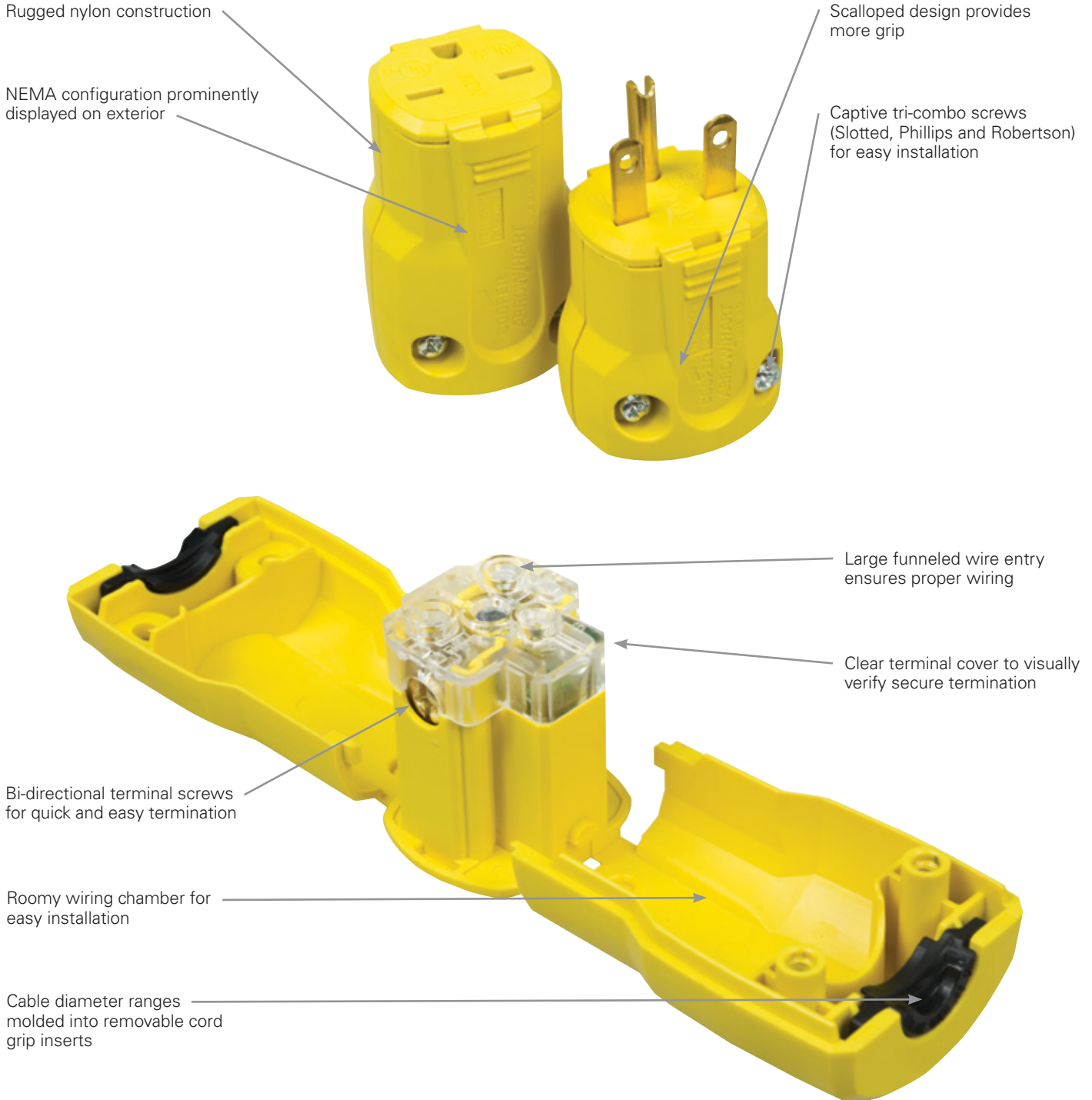

Compliances, specifications and availability are subject to change without notice.

Commercial grade straight blade plugs & connectors

Product description


2-pole, 3-wire grounding
20A, 125V/AC
NEMA 5-20




5-20P




5-20R

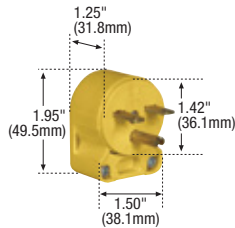

4866AN

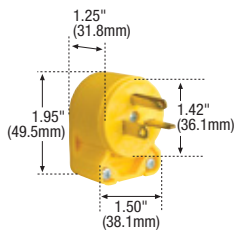

4509AN

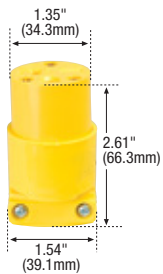

4229

Commercial grade plugs & connectors



Rating A	V/AC	NEMA	Description	Cord diameter	Color	Plug catalog no.	Connector catalog no.	USA	RoHS
20	125	5-20	Vinyl straight body	0.25-0.66" (6.3-16.6mm)	Y	□ 4409*	□ 4228*	•	•
			Vinyl angled body	0.25-0.66" (6.3-16.6mm)	Y	□ 4409AN	—	•	•

* UL and CSA Listed Only

Commercial grade straight blade plugs & connectors

Product description

2-pole, 2-wire grounding
15A, 250V/AC
NEMA 6-15



6-15P



6-15R

Commercial grade plugs & connectors



Rating A	V/AC	NEMA	Description	Cord diameter	Color	Plug catalog no.	Connector catalog no.	USA	RoHS
15	250	6-15	Vinyl straight body	0.25-0.66" (6.3-16.6mm)	Y	—	□ 4227*	•	•
			Vinyl angled body	0.25-0.66" (6.3-16.6mm)	Y	□ 4866AN	—	•	•

* UL and CSA Listed Only

Commercial grade straight blade plugs & connectors

Product description

2-pole, 2-wire grounding
20A, 250V/AC
NEMA 6-20



6-20P



6-20R

Commercial grade plugs & connectors



Rating A	V/AC	Vinyl NEMA	Description	Cord diameter	Color	Plug catalog no.	Connector catalog no.	USA	RoHS
20	250	6-20	Vinyl straight body	0.25-0.66" (6.3-16.6mm)	Y	□ 4509*	□ 4229 [†]	•	•
			Vinyl angled body	0.25-0.66" (6.3-16.6mm)	Y	□ 4509AN	—	•	•

[†] Not NOM cert, * UL Listed Only

Color information:

Y (Yellow)



(Yellow)

Commercial grade dimensional information: B-17

Specification information:
Commercial grade plugs & connectors: B-26

Compliances, specifications and availability are subject to change without notice.

Indicates NAFTA compliant - Page Q-32

RoHS compliant - Page Q-32