
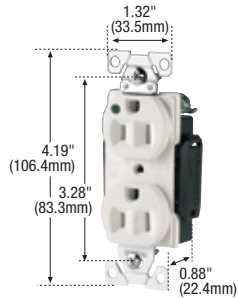



### Hospital grade straight blade receptacles

#### Product description


2-pole, 3-wire grounding  
 15A, 125V/AC; 20A, 125V/AC  
 NEMA 5-15R, 5-20R

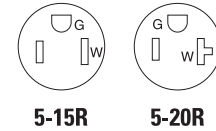


AH8200

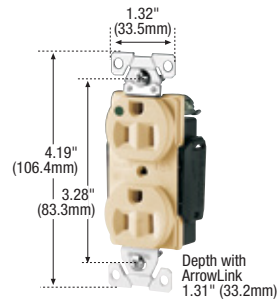

AH8200\_M

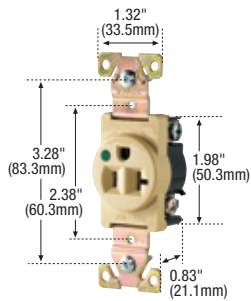

8310

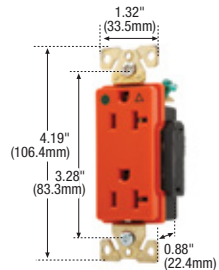

IG8362

#### Premium hospital grade receptacles



 
Rating	A	V/AC	NEMA	Description	Color suffix	Catalog no.				
15	125	5-15R	Premium duplex receptacle, back & side wire		B, BK, GY, RD, V, W	□ AH8200__	▶	◻	USA	✓
			Premium illuminated duplex receptacle, back & side wire		V, W	□ AH8200LT__	▶	◻	USA	✓
			Premium single receptacle, back & side wire		B, GY, V, W	□ 8210__	▶	◻	USA	✓
20	125	5-20R	Premium duplex receptacle, back & side wire		B, BK, GY, LA, RD, V, W	□ AH8300__	▶	◻	USA	✓
			Premium illuminated duplex receptacle, back & side wire		RD, V	□ AH8300LT__	▶	◻	USA	✓
			Premium single receptacle, back & side wire		B, RD, V, W	□ 8310__	▶	◻	USA	✓

#### Premium decorator hospital grade receptacles



Rating	A	V/AC	NEMA	Description	Color suffix	Catalog no.				
15	125	5-15R	Premium decorator duplex receptacle, back & side wire		GY, RD, V, W	□ 8262__	▶	◻	USA	✓
			Premium decorator illuminated duplex receptacle, back & side wire		V, W	□ 8262LT__	▶	◻	USA	✓
20	125	5-20R	Premium decorator duplex receptacle, back & side wire		B, BK, GY, RD, V, W	□ 8362__	▶	◻	USA	✓
			Premium decorator illuminated duplex receptacle, back & side wire		RD, V, W	□ 8362LT__	▶	◻	USA	✓

#### Isolated ground premium hospital grade receptacles



Rating	A	V/AC	NEMA	Description	Color suffix	Catalog no.				
15	125	5-15R	Premium IG duplex receptacle, back & side wire		GY, RD, RN, V, W	□ IG8200__	▶	◻	USA	✓
			Premium IG single receptacle, back & side wire		RN	□ IG8210*	▶	◻	USA	✓
			Premium IG decorator duplex receptacle, back & side wire		GY, RN, V, W	□ IG8262__	▶	◻	USA	✓
20	125	5-20R	Premium IG duplex receptacle, back & side wire		GY, RD, RN, V, W	□ IG8300__	▶	◻	USA	✓
			Premium IG single receptacle, back & side wire		RN	□ IG8310*	▶	◻	USA	✓
			Premium IG decorator duplex receptacle, back & side wire		GY, RN, V, W	□ IG8362__	▶	◻	USA	✓

\*Not Fed Spec

#### Color ordering information:

For ordering devices, include Catalog no. followed by the Color suffix: B (Brown), BK (Black), GY (Gray), LA (Light Almond), RD (Red), RN (Orange), V (Ivory), W (White)



**Specification information:** Premium HG receptacles: A-26, Isolated ground premium HG receptacles: A-27, ArrowLink premium HG Receptacles: A-36

**Compliances, specifications and availability are subject to change without notice.**

▶ ArrowLink option available. Add "M" suffix to standard catalog number (example AH8300W, AH8300WM). For ordering information on ArrowLink & ArrowLink SPD connectors, see Page A-5

◻ Build-to-spec customizable devices - Page A-6

USA Indicates NAFTA compliant - Page Q-32


✓ RoHS compliant - Page Q-32

# Hospital grade straight blade receptacles

## Performance, longevity, reliability

In today's healthcare environment the power to save lives begins with the electrical system. Downtime is not an option and the right receptacle can make the difference in critical situations

### Premium hospital grade AH8200, AH8300 series features & benefits

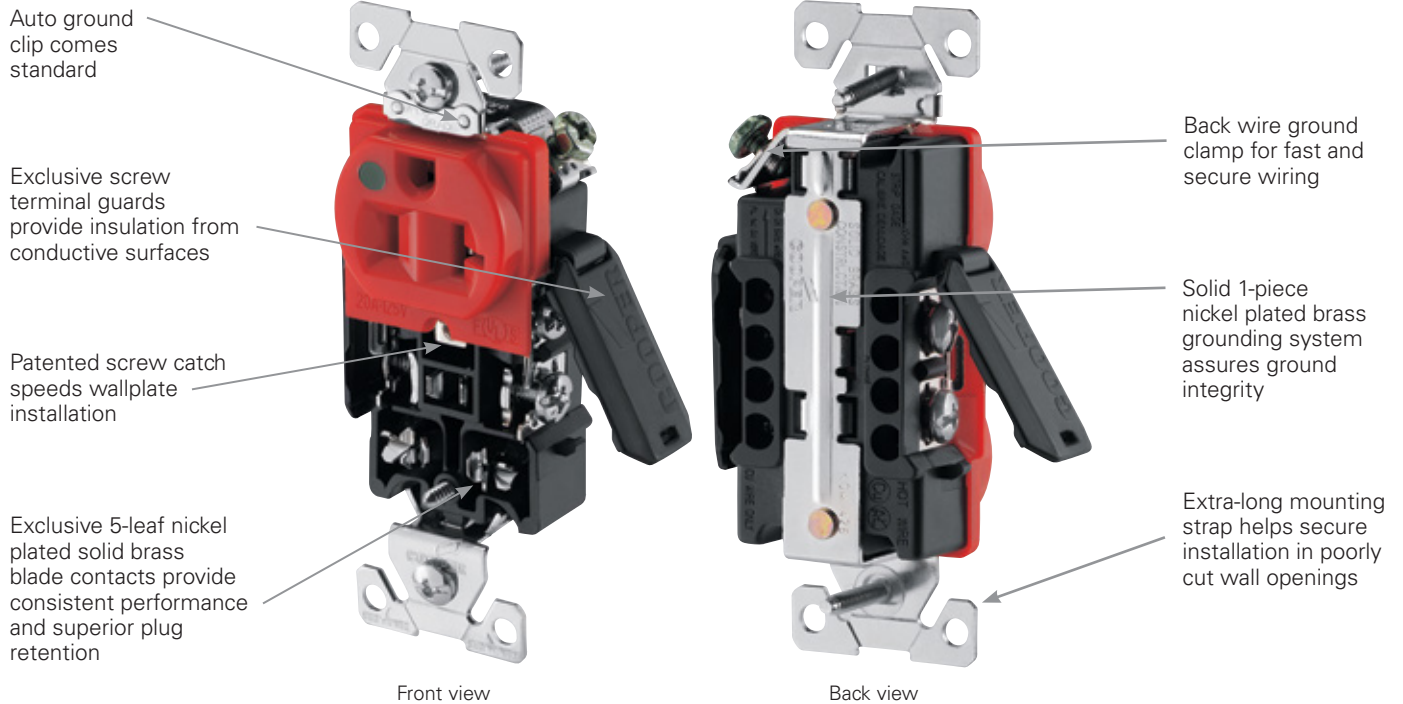

#### Additional features & benefits

- Available in 15A & 20A duplex & single configurations, including lighted, tamper resistant and ArrowLink modular styles
- Glass-filled nylon base provides superior strength and heat resistance
- Convenient built-in #10 and #12 AWG wire strippers
- High impact- and chemical-resistant nylon face holds structural integrity
- Tri-head combination brass terminal screws are backed out and ready to wire

Compliances, specifications and availability are subject to change without notice.



[www.eaton.com](http://www.eaton.com)  
[www.eaton.com/arrowhart](http://www.eaton.com/arrowhart)

## Straight blade receptacles


### Hospital grade straight blade receptacles

#### Product description


2-pole, 3-wire grounding  
15A, 125V/AC; 20A, 125V/AC  
NEMA 5-15R, 5-20R

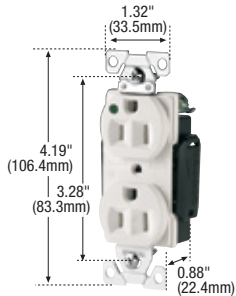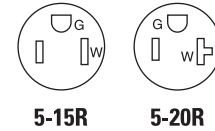


AH8200

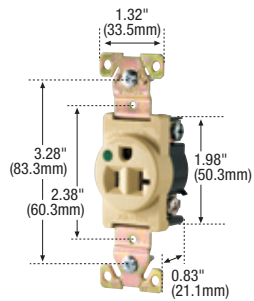

8310

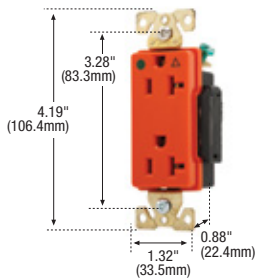

IG8362

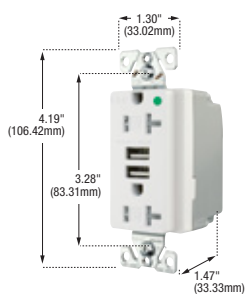

TR8355

#### Premium hospital grade receptacles



Rating	A	V/AC	NEMA	Description	Color suffix	Catalog no.				
15	125	5-15R	Duplex receptacle, back & side wire		B, BK, GY, RD, V, W	□ AH8200__	•	•	•	•
			Illuminated duplex receptacle, back & side wire		V, W	□ AH8200LT__	•	•		
			Single receptacle, back & side wire		B, GY, V, W	□ 8210__	•	•	•	•
20	125	5-20R	Duplex receptacle, back & side wire		B, BK, GY, LA, RD, V, W	□ AH8300__	•	•	•	•
			Illuminated duplex receptacle, back & side wire		RD, V	□ AH8300LT__	•	•		
			Single receptacle, back & side wire		B, RD, V, W	□ 8310__	•	•	•	•

#### Premium decorator hospital grade receptacles



Rating	A	V/AC	NEMA	Description	Color suffix	Catalog no.				
15	125	5-15R	Duplex receptacle, back & side wire		GY, RD, V, W	□ 8262__	•	•	•	•
			Illuminated duplex receptacle, back & side wire		V, W	□ 8262LT__	•			
20	125	5-20R	Duplex receptacle, back & side wire		B, BK, GY, RD, V, W	□ 8362__	•	•	•	•
			Illuminated duplex receptacle, back & side wire		RD, V, W	□ 8362LT__	•			

#### Isolated ground premium hospital grade receptacles



Rating	A	V/AC	NEMA	Description	Color suffix	Catalog no.				
15	125	5-15R	IG duplex receptacle, back & side wire		GY, RD, RN, V, W	□ IG8200__	•	•	•	•
			IG single receptacle, back & side wire		RN	□ IG8210*	•	•	•	•
			IG decorator duplex receptacle, back & side wire		GY, RN, V, W	□ IG8262__	•	•	•	•
20	125	5-20R	IG duplex receptacle, back & side wire		GY, RD, RN, V, W	□ IG8300__	•	•	•	•
			IG single receptacle, back & side wire		RN	□ IG8310*	•	•	•	•
			IG decorator duplex receptacle, back & side wire		GY, RN, V, W	□ IG8362__	•	•	•	•

\*Not Fed. Spec.

 
#### USB charger with hospital grade tamper resistant receptacle



Receptacle Rating	A	V/AC	USB Rating	Amp	V/DC	Description	Color suffix	Catalog no.
15	125	3.1	5	USB charger with hospital grade tamper resistant duplex receptacle		GY, LA, RD, V, W	□ TR8255__	
				USB charger with hospital grade tamper resistant duplex receptacle		GY, LA, RD, V, W	□ TR8355__	

#### Color ordering information:

For ordering devices, include Catalog no. followed by the Color suffix: B (Brown), BK (Black), GY (Gray), LA (Light Almond), RD (Red), RN (Orange), V (Ivory), W (White)



#### Specification information:

Premium HG receptacles: A-26  
ArrowLink premium HG Receptacles: A-30 & A-31  
Isolated ground premium HG receptacles: A-27

Compliances, specifications and availability are subject to change without notice.

➡ ArrowLink option available. Add "M" suffix to standard catalog number (example AH8300W, AH8300WM). For ordering information on ArrowLink & ArrowLink SPD connectors, see Page J-9

🏠 Build-to-spec customizable devices - Page J-10

🇺🇸 Indicates NAFTA compliant - Page Q-32

🌱 RoHS compliant - Page Q-32

🛡️ Tamper resistant