


Sockets for RPY Relays


ZPY11A

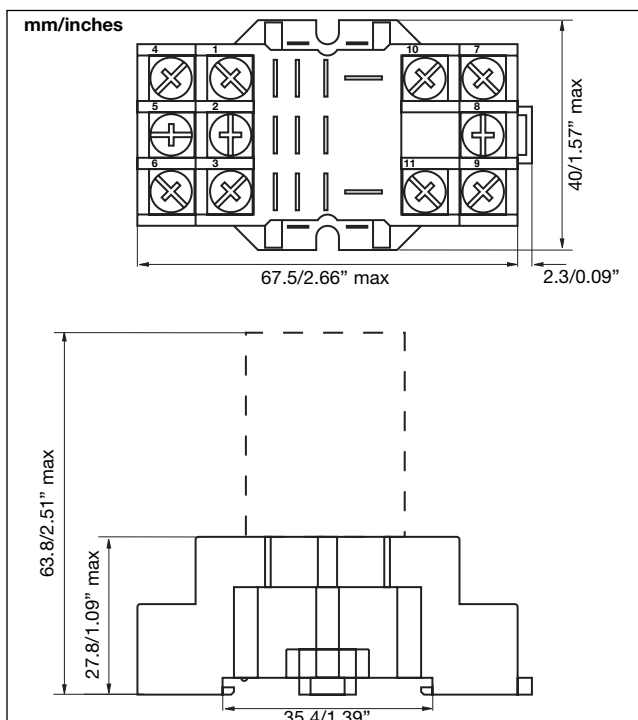


General data

Rated Voltage	400VAC
Rated Current	10A
Insulation Voltage	>2kV
Socket material	PA66 + GF (V0)
Socket colour	RAL 7035 / Pantone 1C
Contact material	Nickel Plated - Cu Zn 33
Screw type	Screw cage
Screw type	M3 with combi head (slotted, Philips Gr.1, Pozi)
Max. screw torque	1.0N/m
Max wire section	0.5-2.5mm ² (20AWG 14AWG)
Operating temperature	-25° to +85°C (-13° to +185°F)
UL rating	10A 300VAC
UL temperature	0° to +60°C (+32° to +140°F)

Drilling pattern

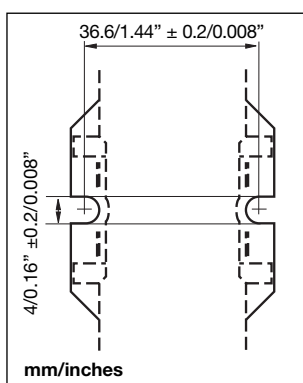

Wiring diagram

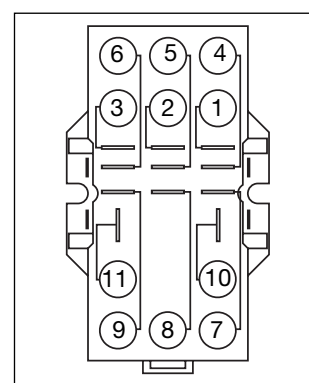

Approvals



Box content: 10 sockets
 Box size: (W 81 x D 140 x H 72) mm Weight: 660g
 (W 3.19 x D 5.51 x H 2.83) inches Weight: 23.28oz

Optional Accessories (to be ordered separately if required)

Hold-down spring steel SZPY 35M (see on page 83)