

StrongHold™ Electrical PVC Vinyl Tape Full Line Offering

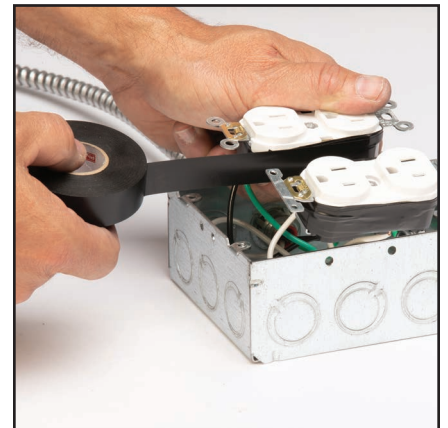
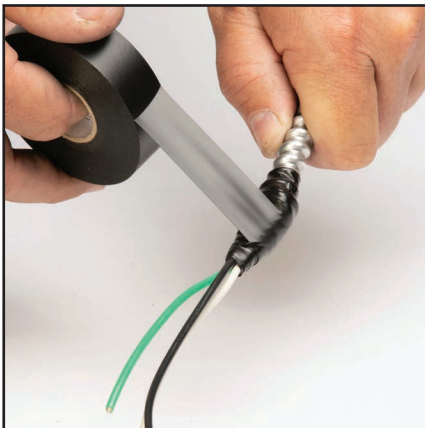
With over 25 varieties of tape designed for insulating, bundling and identifying in various indoor/outdoor environments, we are confident that we have all your application needs covered. StrongHold™ Offerings are committed to providing the contractor with Reliable, Convenient, Economical products to support their installations.

Suitable for primary insulation and splicing up to 600V and can be used as protective jacketing. Our offering protects against an array of abrasive and corrosive materials offering quality adhesion properties as well as resistance to UV rays and cold weather.





| Tape Grade | Temperature Rating | Breaking Strength | Adhesion to Backing | Elongation |
|---|---|-------------------|---------------------|------------|
| Heavy Duty ST88 | Hot: 221°F (105°C) Cold: 0°F (-18°C) | 38 N/cm TYP | 2.2 N/cm TYP | 300% TYP |
| Professional Grade ST43 & ST35 | Hot: 221°F (105°C) Cold: 0°F (-18°C) | 30 N/cm TYP | 2.2 N/cm TYP | 260% TYP |
| General Purpose ST14, ST15 & ST17 | Hot: 176°F (80°C) Cold: 14°F (-10°C) | 25 N/cm TYP | 1.6~1.8 N/cm TYP | 200% TYP |

NOTE: N/cm refers to Newton per centimeter. TYP refers to typical value.



StrongHold™ Electrical PVC Vinyl Tape Full Line Offering





StrongHold™ Heavy Duty Tape Offering

| Vinyl Electrical Tapes | Product Description/Applications | Thickness | Low and Max Temperatures | Roll Size |
|--|---|--|--------------------------------|--|
| ST88   | Heavy Duty grade that offers easy application for high level performance over a range of temperatures with protection against UV rays, abrasion, water, oil and other corrosive chemicals. Suitable for primary insulation for splicing up to 600V and can be used as protective jacketing. | 8.5 mil 8.5 mil 8.5 mil 8.5 mil | 0°F to 211°F -18°C to 105°C | 0.75" x 0.0085" x 66' 1.0" x 0.0085" x 108' 1.5" x 0.0085" x 66' 2.0" x 0.0085" x 66' |

Heavy Duty Electrical PVC Vinyl Tape Offering

| StrongHold™ Part Numbers | UPC Code | Case Quantity | Color | Thickness | Dimension |
|--------------------------|--------------|---------------|-------|-----------|-----------------------|
| ST88-075-66BK | 613056580367 | 100 | Black | 8.5 mil | 0.75" x 0.0085" x 66' |
| ST88-100-66BK | 613056732414 | 80 | Black | 8.5 mil | 1.0" x 0.0085" x 66' |
| ST88-150-66BK | 613056732421 | 100 | Black | 8.5 mil | 1.5" x 0.0085" x 66' |
| ST88-200-66BK | 613056732438 | 40 | Black | 8.5 mil | 2.0" x 0.0085" x 66' |

StrongHold™ Professional Grade Tape Offering







| Vinyl Electrical Tapes | Product Description/Applications | Thickness | Color | Roll Size |
|--|--|-----------|--|----------------------|
| ST43   | Pressure sensitive vinyl electrical tape that offers high abrasion resistance with easy application over a range of temperatures. Flame retardant as well as cold resistant, suitable for primary insulation for splicing up to 600V and can be used as protective jacketing. | 7 mil | Black | 0.75" x 0.007" x 66' |
| ST35   | Available in nine colors for color coding, excellent elasticity and insulating properties. Professional grade designed to handle range of temperatures with protection against abrasion, water, oil and other corrosive chemical. Suitable for primary insulation for splicing up to 600V and can be used as protective jacketing. | 7 mil | White Red Blue Yellow Brown Orange Green Gray Violet | 0.75" x 0.007" x 66' |

Professional Grade Electrical PVC Vinyl Tape Offering

| StrongHold™ Part Numbers | UPC Code | Case Quantity | Color | Thickness | Dimension |
|--------------------------|--------------|---------------|--------|-----------|----------------------|
| ST35-075-66BU | 613056580343 | 20 | Blue | 7 mil | 0.75" x 0.007" x 66' |
| ST35-075-66BR | 613056715868 | 20 | Brown | 7 mil | 0.75" x 0.007" x 66' |
| ST35-075-66GY | 613056732353 | 20 | Gray | 7 mil | 0.75" x 0.007" x 66' |
| ST35-075-66GR | 613056732360 | 20 | Green | 7 mil | 0.75" x 0.007" x 66' |
| ST35-075-66OR | 613056732377 | 20 | Orange | 7 mil | 0.75" x 0.007" x 66' |
| ST35-075-66RD | 613056580366 | 20 | Red | 7 mil | 0.75" x 0.007" x 66' |
| ST35-075-66VI | 613056732384 | 20 | Violet | 7 mil | 0.75" x 0.007" x 66' |
| ST35-075-66WH | 613056580350 | 20 | White | 7 mil | 0.75" x 0.007" x 66' |
| ST35-075-66YL | 613056732391 | 20 | Yellow | 7 mil | 0.75" x 0.007" x 66' |
| ST43-075-66BK | 613056755505 | 100 | Black | 7 mil | 0.75" x 0.007" x 66' |

StrongHold™ Electrical PVC Vinyl Tape Full Line Offering

StrongHold™ General Purpose Tape Offering

| Vinyl Electrical Tapes | Product Description/Applications | Thickness | Color | Roll Size |
|---|---|-----------|--|----------------------|
| ST14   | Excellent conformability properties and ease of tearing due to high elongation. Non-corrosive and pressure-sensitive adhesive which eliminates the need for catalysts during application. Flame retardant as well as cold and cold resistant. Suitable as a primary insulation when used for splicing up to 600V. | 7 mil | Black | 0.75" x 0.007" x 60' |
| ST17   | Excellent conformability properties and ease of tearing due to high elongation. Non-corrosive and pressure-sensitive adhesive which eliminates the need for catalysts during application. Flame retardant as well as cold and cold resistant. Suitable as a primary insulation when used for splicing up to 600V. | 7 mil | White Red Blue Yellow Brown Orange Green Gray Violet | 0.75" x 0.007" x 66' |
| ST15   | Non-corrosive and pressure-sensitive adhesive which eliminates the need for heat, moisture or other catalysts to affect the application. High elongation, nonflammable and able to be used in various weather conditions. Suitable as a primary insulation when used for splicing up to 600V. | 5 mil | Yellow/Green | 0.75" x 0.005" x 66' |

General Purpose Electrical PVC Vinyl Tape Offering



| StrongHold™ Part Numbers | UPC Code | Color | Thickness | Dimension |
|--------------------------|--------------|---------------------------|-----------|----------------------|
| ST17-075-66BU | 613056732568 | Blue | 7 mil | 0.75" x 0.007" x 66' |
| ST17-075-66BR | 613056732575 | Brown | 7 mil | 0.75" x 0.007" x 66' |
| ST17-075-66GY | 613056732582 | Gray | 7 mil | 0.75" x 0.007" x 66' |
| ST17-075-66GR | 613056732599 | Green | 7 mil | 0.75" x 0.007" x 66' |
| ST17-075-66OR | 613056732605 | Orange | 7 mil | 0.75" x 0.007" x 66' |
| ST17-075-66RD | 613056732612 | Red | 7 mil | 0.75" x 0.007" x 66' |
| ST17-075-66YL | 613056732629 | Yellow | 7 mil | 0.75" x 0.007" x 66' |
| ST17-075-66VI | 613056732636 | Violet | 7 mil | 0.75" x 0.007" x 66' |
| ST17-075-66WH | 613056732643 | White | 7 mil | 0.75" x 0.007" x 66' |
| ST14-075-60BK | 613056732650 | Black | 7 mil | 0.75" x 0.007" x 60' |
| ST15-075-66GYL | 613056732674 | Yellow with Green Stripes | 5 mil | 0.75" x 0.005" x 66' |
| ST14-075-60BKX | 613056732667 | Black | 7 mil | 0.75" x 0.007" x 60' |