



 
M18 FUEL
16 Gauge Angled Finish Nailer Kit

2742-21CT (2742-20 Tool-Only)

Specifications:

Nail Diameter	16 Gauge
Nail Size	1-1/4" – 2-1/2"
Nail Collation Angle	20°
Magazine Size	110 Nails
Max Fire Rate	3 Nails per Second
Magazine Loading	Bottom Load
Length / Weight	11.9" / 7.2 lbs

Includes: (1) M18™ REDLITHIUM™ CP2.0 Battery Pack, Multi-Voltage Charger, Contractor Bag



M18 FUEL
Deep Cut Band Saw Kit

2729-22HD, 2729-22, 2729-21 (2729-20 Tool-Only)

Specifications:

SFPM	0 – 380
Cut Capacity	5" x 5"
Shoe	Tool-Free
LED Light	Yes
Hang Hook	Yes
Weight	15.9 lbs

Includes: 2729-22HD (2) M18™ REDLITHIUM™ HD9.0 Battery Packs, Rapid Charger; 2729-22 (2) M18™ REDLITHIUM™ XC5.0 Battery Packs, Multi-Voltage Charger; 2729-21 (1) M18™ REDLITHIUM™ XC5.0 Battery Pack, Multi-Voltage Charger;

All Kits Include: Blade, Carrying Case

Related Accessories:

- 48-39-0501 10 TPI Standard Deep Cut Portable Band Saw Blades (3-Pack);
- 48-39-0511 14 TPI Standard Deep Cut Portable Band Saw Blades (3-Pack);
- 48-39-0521 18 TPI Standard Deep Cut Portable Band Saw Blades (3-Pack);
- 48-39-0531 24 TPI Standard Deep Cut Portable Band Saw Blades (3-Pack);
- 48-39-0551 10/14 TPI Standard Deep Cut Portable Band Saw Blades (3-Pack);
- 48-39-0561 14/18 TPI Standard Deep Cut Portable Band Saw Blades (3-Pack);
- 48-39-0601 8/10 TPI Extreme Metal Deep Cut Portable Band Saw Blades (3-Pack);
- 48-39-0611 12/14 TPI Extreme Metal Deep Cut Portable Band Saw Blades (3-Pack)



M18™ Band Saw Kit

2629-22 (2629-20 Tool-Only)

Specifications:

SFPM	480
Cut Capacity	3-1/4" x 3-1/4"
Shoe	Tool-Free
LED Light	Yes
Weight	10.2 lbs

Includes: (2) M18™ REDLITHIUM™ XC3.0 Battery Packs, Blade, Multi-Voltage Charger, Carrying Case

Related Accessories:

- 48-39-0509 10 TPI Compact Portable Band Saw Blades (3-Pack);
- 48-39-0519 14 TPI Compact Portable Band Saw Blades (3-Pack);
- 48-39-0529 18 TPI Compact Portable Band Saw Blades (3-Pack);
- 48-39-0539 24 TPI Compact Portable Band Saw Blades (3-Pack);
- 48-39-0609 8/10 TPI Extreme Metal Compact Portable Band Saw Blades (3-Pack);
- 48-39-0619 12/14 TPI Extreme Metal Compact Portable Band Saw Blades (3-Pack)




M18 FUEL
18 Gauge Brad Nailer Kit

2740-21CT (2740-20 Tool-Only)

Specifications:

Nail Diameter	18 Gauge
Nail Size	5/8" – 2-1/8"
Nail Collation Angle	0°
Magazine Size	110 Nails
Max Fire Rate	3 Nails per Second
Magazine Loading	Side Load
Length / Weight	11.4" / 6.1 lbs

 Includes: (1) M18™ REDLITHIUM™ CP2.0 Battery Pack, Multi-Voltage Charger, Contractor Bag






M18 FUEL
16 Gauge Straight Finish Nailer Kit

2741-21CT (2741-20 Tool-Only)

Specifications:

Nail Diameter	16 Gauge
Nail Size	3/4" – 2-1/2"
Nail Collation Angle	0°
Magazine Size	110 Nails
Max Fire Rate	3 Nails per Second
Magazine Loading	Bottom Load
Length / Weight	11.9" / 7.2 lbs

  Includes: (1) M18™ REDLITHIUM™ CP2.0 Battery Pack, Multi-Voltage Charger, Contractor Bag

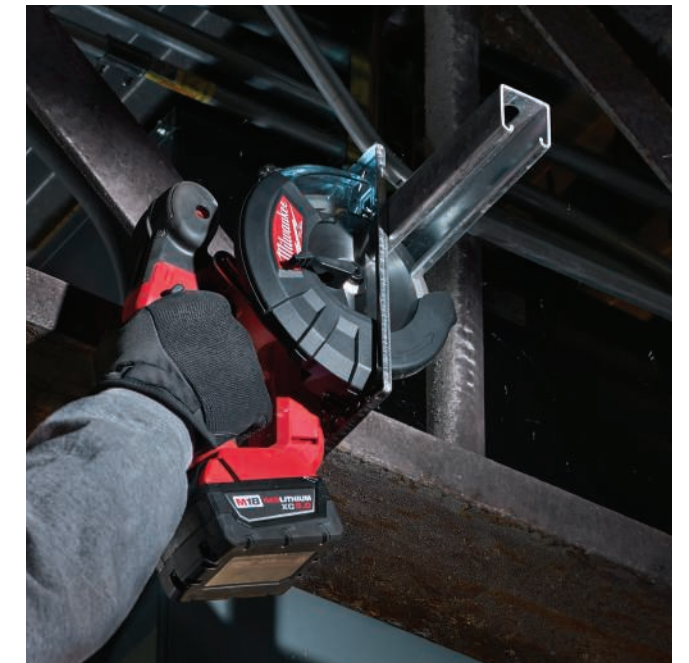

M18 FUEL
Metal Cutting Circular Saw Kit

2782-22 (2782-20 Tool-Only)

Specifications:

RPM	3,900
Blade Size	5-3/8" – 5-7/8"
Arbor Size	20 mm
Hang Hook	Yes
Length / Weight	4.7" / 6.5 lbs

Includes: (2) M18™ REDLITHIUM™ XC5.0 Battery Packs, 30T Blade, Multi-Voltage Charger, Contractor Bag

