

# OWP-FC-116-LED

LED Slimline Full Cut-Off Wall Pack Series


up to 40 Wattage / up to 5000 Lumens

Catalog Number:

Project Name:

Note:

Type:

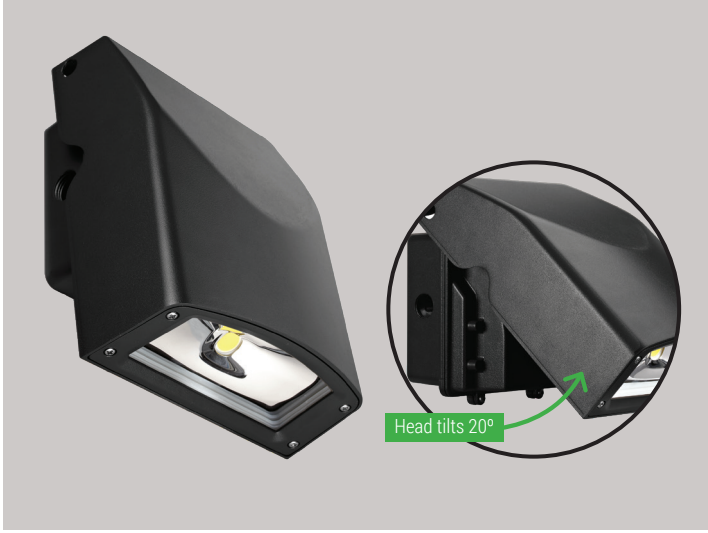


## APPLICATIONS:

The Slim LED wall pack provides outdoor illumination utilizing a low-profile and provides versatility with an adjustable head tilt. Shallow distribution allows for varying mounting heights. Forward throw distribution provides a larger coverage area while keeping with the slim aesthetics. Ideal for low rise offices, apartments, hospitality, retail, and education.


## FEATURES:

- Sealed die-casting profile for outdoor applications
- Head tilts max 20° vertically to extend coverage area
- Replacing 50-100W HID
- Lumen output from 3500-5000lm with efficacy of 100lm/ W
- Built-in UL class 2 driver, optional for photocell
- UL listed

## DIMENSION:

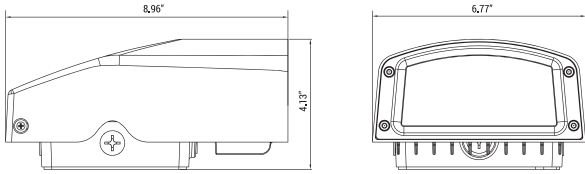

## PHOTOMETRICS:

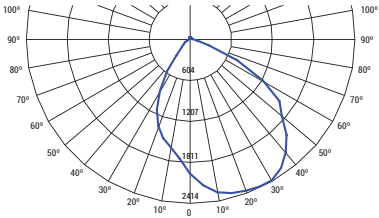

B	U	G
2	1	0

## SPECIFICATIONS:

LUMENS	3500 / 5000 lumens
WATTAGE	27W / 40W
CCT	40K, 50K
CRI	70
LIGHT EFFICIENCY	100 lumens/watt
VOLTAGE	120-277 VAC
POWER FREQUENCY	50/60 Hz
FINISH	Bronze
APPLICABLE ENVIRONMENT	Dry/Damp/Wet location
WORKING TEMPERATURE	-40°C to 45°C



Ordering Guide > Example: OWP-FC-116-LED-5000L-MVOLT-40K-BZ

OWP-FC-116-LED					
<b>SERIES</b>	<b>PERFORMANCE</b>	<b>VOLTAGE</b>	<b>CCT</b>	<b>FINISH</b>	<b>ACCESSORIES</b>
OWP-FC-116-LED	3500L - 3500 lumens 5000L - 5000 lumens	MVOLT - 120/277V	30K - 3000K 35K - 3500K 40K - 4000K 50K - 5000K	BZ - Bronze	WPPHC - Photocell