

Metal Drilling

Drill Bit Sets / Gauges

Pro Set Cases



314018



318015



316015



4935643




3018009

METAL DRILLING

Description	Type	Contents	Point	Finish	Item #
15-Piece Set	Black Oxide HSS Fractional Straight Shank Jobber Length	1/16" - 3/8"	135°	Black Oxide	314015
18-Piece Set	Black Oxide HSS Fractional Jobber Length	1/16" - 1/2" with 3/8" Reduced Shank	135°	Black Oxide	314018
20-Piece Set	Drill/Drive Set with Black Oxide HSS Drills and Screwdriver Bits	1/16" (2), 3/32", 1/8" (2), 5/32", 3/16", 1/4" Drills and 12 Screwdriver and Nutdriver Bits	135°	Black Oxide	357020
15-Piece Set	Cobalt HSS Fractional Straight Shank Jobber Length	1/16" - 3/8"	135°	Cobalt	316015
15-Piece Set	TURBOMAX® HSS Fractional Straight Shank Jobber	Length 1/16"-3/8"	TURBOMAX	Black & Gold Oxide	318015
18-Piece Set	TURBOMAX HSS Fractional Jobber	Length 1/16"-1/2" with 3/8" Reduced Shank	TURBOMAX	Black & Gold Oxide	3018024SM
12-Piece Set	Black Oxide HSS 1/4" Hex Shank Jobber Length	1/16", 5/64", 3/32", 7/64", 1/8" (2), 9/64", 5/32", 3/16", 7/32", 1/4" Drills and Lock-N-Load® Quick-Change	135°	Black Oxide	4935643
15-Piece Set	Titanium Coated HSS Fractional Straight Shank Jobber	1/16"-3/8"	135°	TiN	4935607
15-Piece Set	Titanium Turbomax	1/16" - 3/8"	TURBOMAX	TiN	3018009
18-Piece Set	Titanium Turbomax	1/16" - 1/2"	TURBOMAX	TiN	3018010
9-Piece Set	Titanium Turbomax & Unibit	1/16" - 3/8" Unibit #1 & #4	TURBOMAX	TiN	3018008

Drill Bit Gauge & Stand

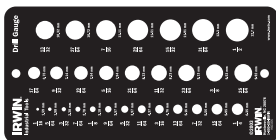

12092

Description	Carded Item #	Bulk Item #
Fractional Drill Gauge	12092	—
Drill Stand 1/16" - 1/2"	60172	—