



# LED Ceiling Luminaire

Discover our LED ceiling luminaire line equipped with high quality integrated LEDs: they are an energy efficient solution with a life rating of 50 000 hours. This line offers a pleasant, dimmable light making a great solution for any general lighting needs. Thanks to our variety of decorative options you can enjoy direct or indirect lighting fitting seamlessly into any commercial and residential installations.

# LED Traditional

02



6", 8"



11", 14"




16", 18", 20", 22"

Order code	Description	Watts (W)	Volts (VAC)	Colour temp. (K)	Lumen output (lm)	CRI	Life L70 (hrs)	Size (in.)	Shape	Finish	Case qty (master)
<b>6", 8"</b>											
66716	LED/CL6/10W/30K/FM/RND/STD	10	120	3 000	785	80	50 000	6	Round	White	24
66717	LED/CL6/10W/40K/FM/RND/STD	10	120	4 000	822	80	50 000	6	Round	White	24
66718	LED/CL8/12W/30K/FM/RND/STD	12	120	3 000	1012	80	50 000	8	Round	White	12
66719	LED/CL8/12W/40K/FM/RND/STD	12	120	4 000	1049	80	50 000	8	Round	White	12
<b>11", 14"</b>											
65598	LED/CL11/15W/27K/FM/RND/STD	15	120	2 700	1 120	80	50 000	11	Round	White	4
66711	CL11/S2/15W/30K/RND/WH/STD	15	120	3 000	1 150	80	50 000	11	Round	White	4
66712	CL11/S2/15W/40K/RND/WH/STD	15	120	4 000	1 164	80	50 000	11	Round	White	4
63300	LED/CL11/15W/30K/FM/SQR/STD	15	120	3 000	1 020	80	50 000	11	Square	White	4
63301	LED/CL11/15W/40K/FM/SQR/STD	15	120	4 000	1 123	80	50 000	11	Square	White	4
66713	LED/CL14/25W/27K/FM/RND/STD	25	120	2 700	1 718	80	50 000	14	Round	White	4
66714	CL14/S2/25W/30K/RND/WH/STD	25	120	3 000	1 783	80	50 000	14	Round	White	4
66715	CL14/S2/25W/40K/RND/WH/STD	25	120	4 000	1 851	80	50 000	14	Round	White	4
63304	LED/CL14/25W/30K/FM/SQR/STD	25	120	3 000	1 723	80	50 000	14	Square	White	4
63305	LED/CL14/25W/40K/FM/SQR/STD	25	120	4 000	1 844	80	50 000	14	Square	White	4
<b>16", 18", 20", 22"</b>											
65665	LED/CL16/26W/30K/FM/RND/STD	26	120	3 000	2 034	80	50 000	16	Round	White	4
65666	LED/CL16/26W/40K/FM/RND/STD	26	120	4 000	2 170	80	50 000	16	Round	White	4
65667	LED/CL18/32W/30K/FM/RND/STD	32	120	3 000	2 644	80	50 000	18	Round	White	4
65668	LED/CL18/32W/40K/FM/RND/STD	32	120	4 000	2 898	80	50 000	18	Round	White	4
65661	LED/CL20/37W/30K/FM/RND/STD	37	120	3 000	3 098	80	50 000	20	Round	White	2
65662	LED/CL20/37W/40K/FM/RND/STD	37	120	4 000	3 144	80	50 000	20	Round	White	2
65663	LED/CL22/40W/30K/FM/RND/STD	40	120	3 000	3 424	80	50 000	22	Round	White	2
65664	LED/CL22/40W/40K/FM/RND/STD	40	120	4 000	3 534	80	50 000	22	Round	White	2

## Replacement Lenses

Order code	Description	Replacement for
64867	LED/CL6/LENS/RND/STD	66716, 66717
64868	LED/CL8/LENS/RND/STD	66718, 66719
64869	LED/CL11/LENS/RND/STD	66711, 66712, 65598
64877	LED/CL11/LENS/SQR/STD	63300, 63301
64878	LED/CL14/LENS/RND/STD	66714, 66715, 66713
64879	LED/CL14/LENS/SQR/STD	63304, 63305

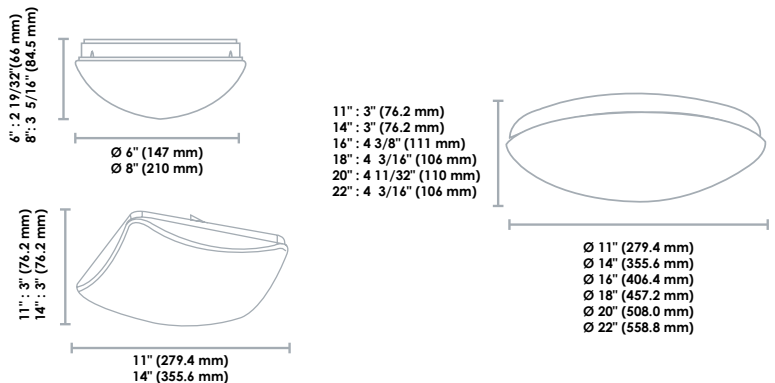

Lumen values are derived from photometric testing. For a complete list of compatible dimmers and ENERGY STAR qualified products, please visit [www.standardpro.com](http://www.standardpro.com)

# Shade

Our shades create a warm and elegant atmosphere. They complement our 11" and 14" LED traditional ceiling luminaires and are offered in assorted materials and textures which allows you to create a specific ambient style.

- Drum profile
- Materials and textures available: silk type, cork, wood, and linen type



02

Order code	Description	Shape	Material	Finish	Case qty (master)
------------	-------------	-------	----------	--------	-------------------

### Compatible for 11" traditional ceiling luminaires

65681	LED/CL11/SHADE/RND/WHITE/STD	Round	Linen type	White	6
65682	LED/CL11/SHADE/RND/BEIGE/STD	Round	Linen type	Beige	6
65683	LED/CL11/SHADE/RND/BLACK/STD	Round	Linen type	Black	6
65684	LED/CL11/SHADE/RND/DGRAY/STD	Round	Linen type	Grey	6
65685	LED/CL11/SHADE/RND/WOOD/STD	Round	Wood	Wood	6
65686	LED/CL11/SHADE/RND/CORK/STD	Round	Cork	Cork	6
65687	LED/CL11/SHADE/RND/WFROST/STD	Round	Silk type	White frosted	6
66044	LED/CL11/SHADE/RND/BRNW/STD	Round	Wood	Barn wood	6

### Compatible for 14" traditional ceiling luminaires

65688	LED/CL14/SHADE/RND/WHITE/STD	Round	Linen type	White	6
65689	LED/CL14/SHADE/RND/BEIGE/STD	Round	Linen type	Beige	6
65690	LED/CL14/SHADE/RND/BLACK/STD	Round	Linen type	Black	6
65691	LED/CL14/SHADE/RND/DGRAY/STD	Round	Linen type	Grey	6
65692	LED/CL14/SHADE/RND/WOOD/STD	Round	Wood	Wood	6
65693	LED/CL14/SHADE/RND/CORK/STD	Round	Cork	Cork	6
65694	LED/CL14/SHADE/RND/WFROST/STD	Round	Silk type	White Frosted	6
66045	LED/CL14/SHADE/RND/BRNW/STD	Round	Wood	Barn wood	6

