



2-110-T Coral MR16



Coral's stepped glass lens drops below the ceiling plane to balance horizontal and vertical illumination beautifully, flattering the appearance of both the space and its occupants. The Coral trim includes a silicone gasket and a sealed glass diffuser.

FEATURES

- Utilizes MR16
- Wet location listed
- Die-cast aluminum fixture
- Powder coated and plated trim ring finishes
- Trim clips designed for 5/8" ceiling thickness
- Accepts 1 optional media

DETAILS


Trim Class: 4"
Category: Recessed Downlight
Shape: Round
Adjustability: Fixed




2-110-T-Coral-MR16-Specs • Subject to change without notice • Rev 2016.12.16 • 1/4

Features & Lighting

DIMENSIONS

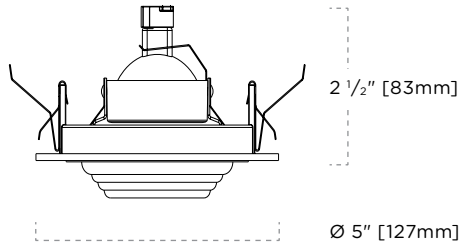

CEILING CUTOUT

 

FLANGE FINISHES

- White
- Chrome Plated
- Matte Silver
- Bronze
- Matte Nickel

GLASS


- Frosted
- Clear

2-110-T-Coral-MR16-Specs • Subject to change without notice • Rev 2016.12.16 • 2/4


Compatible Housings

NON-INSULATED

2-020
Round Non-Insulated
L 10 1/2" [267mm]
W 7 3/4" [197mm]
H 3 1/2" [90mm]

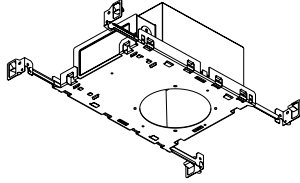


2-060
Round Non-Insulated
L 13 3/4" [349mm]
W 10 7/8" [276mm]
H 3 1/2" [90mm]

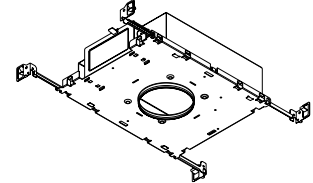


INSULATED

2-010
Round Insulated
L 13 3/4" [350mm]
W 10 7/8" [277mm]
H 7" [178mm]

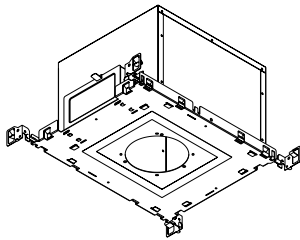


2-012
Round Insulated
L 22 1/2" [572mm]
W 8 1/2" [216mm]
H 5 7/8" [150mm]

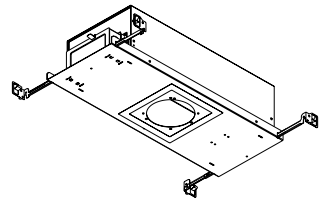


REMODEL

2-030
Round Remodel
L 14 1/2" [356mm]
W 4 1/2" [114mm]
H 5 1/8" [130mm]

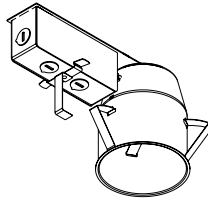

SPECIALIZED

2-060
Round Chicago Plenum
L 13 3/4" [350mm]
W 10 7/8" [277mm]
H 4 1/2" [115mm]

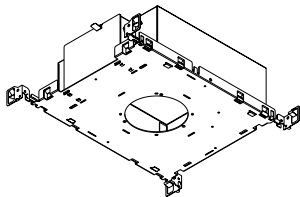

2-100
Round Concrete Housing
L 18" [457mm]
W 12" [305mm]
H 6" [152mm]

