

2-550-T Nemo MR16



The small Nemo trim, with its sealed and flush glass face, brings nuanced architectural lighting to wet locations: baths, covered walkways, entryways, and outdoor living spaces.

FEATURES

- Utilizes MR16
- Wet location listed
- 360° rotation
- 30° aiming
- Die-cast aluminum fixture
- Flush glass lens design
- Powder coated and plated trim ring finishes
- Trim clips designed for 5/8" ceiling thickness
- Accepts up to 2 optional media

DETAILS

Trim Class: 4"

Category: Recessed Downlight

Shape: Square

Adjustability: Aiming With Rotation



2-550-T-Nemo-MR16-Specs • Subject to change without notice • Rev 2016.12.19 • 1/4

Compatible Housings

NON-INSULATED


2-025

Square Non-Insulated

L 10 1/2" [267mm]

W 7 3/4" [197mm]

H 3 1/2" [90mm]

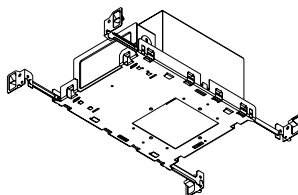


2-065

Square Non-Insulated

L 13 3/4" [349mm]

W 10 7/8" [276mm]

H 3 1/2" [90mm]

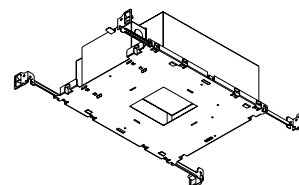

INSULATED


2-015

Square Insulated

L 13 3/4" [350mm]

W 10 7/8" [277mm]

H 7" [178mm]

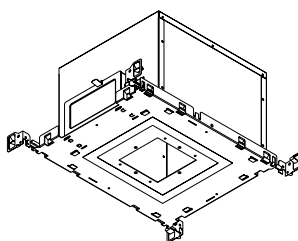


2-017

Square Insulated

L 22 1/2" [572mm]

W 8 1/2" [216mm]

H 5 7/8" [150mm]

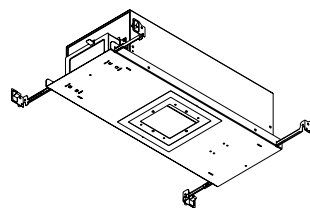

REMODEL


2-035

Square Remodel

L 14" [356mm]

W 4 1/2" [114mm]

H 5 1/8" [130mm]

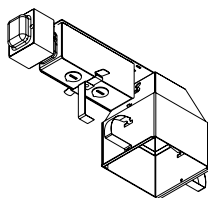

SPECIALIZED


2-065

Square Chicago Plenum

L 13 3/4" [350mm]

W 10 7/8" [277mm]

H 4 1/2" [115mm]

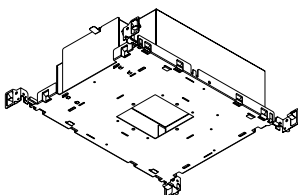


2-105

Square Concrete Housing

L 18" [457mm]

W 12" [305mm]

H 6" [152mm]

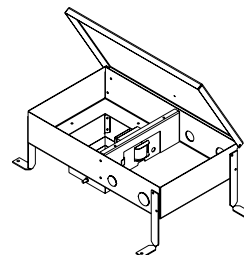

2-550-T Nemo MR16

Project

Type

Notes

Product Code

1 2 3 4 5

1. Trim

2-550-T Nemo

2. Lamp

MR16 Halogen

3. Flange Finish

01 White

02 Chrome Plated

04 Black

05 Matte Silver

06 Bronze

11 Matte Nickel

CC Custom Color ¹

4. Glass

C Clear Glass

F Frosted Glass

5. Options

WP White painted housing interior ²

Notes

¹ **CC** custom color requires consultation with Lightheaded sales personnel.

² **WP** white trim interior. Trim interior is painted black standard.

2-550-T-Nemo-MR16-Specs • Subject to change without notice • Rev 2016.12.19 • 4/4