








Red•Dot Weatherproof products

FS and FD metallic covers


Single-gang horizontal covers (cast aluminum)

	Cat. no.	Description	Std. ctn.
	CCD-FS	Grey – box mount (zinc)	50
	CFSH-G	One GFCI receptacle – box mount	25
	CWPDR	One duplex receptacle – device mount	25
	CWPDR-FS	One duplex receptacle – box mount	25

Single-gang vertical covers (cast aluminum)




	Cat. no.	Description	Std. ctn.
	CFSDR	One duplex receptacle – box mount	25
	CFSR-G	One GFCI receptacle – box mount	25
	CWPV-G	One GFCI receptacle – device mount	25

Single-gang horizontal covers (cast aluminum)


	Cat. no.	Description	Nominal size (in.)	Max. device face dia.	Std. ctn.
	CFSR-L	Single receptacle – box mount	1 ⁷ / ₁₆	1.600	25
	CFSR-S		1 ³ / ₈	1.395	25
	CFSR-X	1 ²⁷ / ₃₂	1.865	25	
	CFSR-XL	2 ¹ / ₈	2.145	25	
	CFSR-Y	1 ³ / ₄	1.750	25	

*Gasket and screws included.

Single-gang (cast aluminum)

	Cat. no.	Description	Std. ctn.
	CDR	One duplex receptacle – box mount	100
	CTS	One switch receptacle – box mount	100
	CFSB	Blank, box mount	100

Single-gang horizontal covers (cast aluminum)

	Cat. no.	Description	Nominal size (in.)	Max. device face dia.	Std. ctn.
	CRL	Single receptacle – box mount	1 ⁷ / ₁₆	1.600	100
	CRS		1 ³ / ₈	1.395	100

Covers are approved for dry locations only

Red-Dot Weatherproof products


FS and FD metallic covers

Single-gang vertical covers (cast aluminum)



Cat. no.	A	B	F	G	K	L
CFSDR	4 ⁹ / ₁₆	2 ¹³ / ₁₆	3 ¹ / ₄	1 ⁷ / ₈	-	-
CFSR-G	4 ⁹ / ₁₆	2 ¹³ / ₁₆	3 ¹ / ₄	1 ⁷ / ₈	2 ²¹ / ₃₂	1 ¹¹ / ₃₂
CWPV-G	4 ⁹ / ₁₆	2 ¹³ / ₁₆	3 ¹ / ₄	-	2 ²¹ / ₃₂	1 ¹¹ / ₃₂

Diagrams

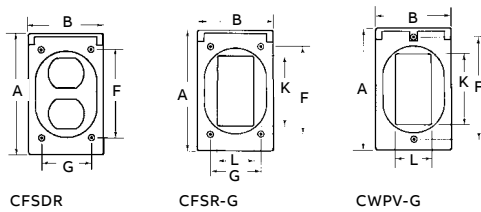


Single-gang vertical covers (cast aluminum)



Cat. no.	A	B	F	G
CFSR-L	4 ⁹ / ₁₆	2 ¹³ / ₁₆	3 ¹ / ₄	1 ⁷ / ₈
CFSR-S	4 ⁹ / ₁₆	2 ¹³ / ₁₆	3 ¹ / ₄	1 ⁷ / ₈
CFSR-X	4 ⁹ / ₁₆	2 ¹³ / ₁₆	3 ¹ / ₄	1 ⁷ / ₈
CFSR-XL	4 ⁹ / ₁₆	2 ¹³ / ₁₆	3 ¹ / ₄	1 ⁷ / ₈
CFSR-Y	4 ⁹ / ₁₆	2 ¹³ / ₁₆	3 ¹ / ₄	1 ⁷ / ₈

Diagram

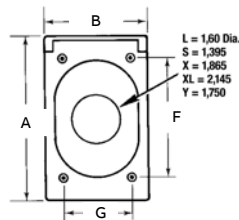

CFSR Series*


*Gasket and screws included.

Single-gang (cast aluminum)



Cat. no.	A	B	F	G
CDR	4 ⁹ / ₁₆	2 ¹³ / ₁₆	3 ¹ / ₄	1 ⁷ / ₈
CTS	4 ⁹ / ₁₆	2 ¹³ / ₁₆	3 ¹ / ₄	1 ⁷ / ₈

Diagrams

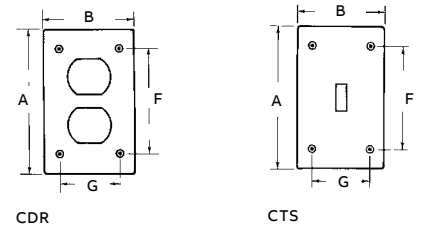


Single-gang (cast aluminum)



Cat. no.	A	B	F	G
CRL	4 ⁹ / ₁₆	2 ¹³ / ₁₆	3 ¹ / ₄	1 ⁷ / ₈
CRS	4 ⁹ / ₁₆	2 ¹³ / ₁₆	3 ¹ / ₄	1 ⁷ / ₈

Diagram

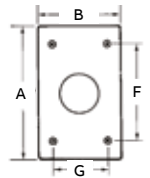

CRL




Covers are approved for dry locations only

Red•Dot Weatherproof products


FS and FD metallic covers

Two-gang				SP® UL	
	Cat. no.	Description	Std. ctn.		
	2CWPDPR	Two duplex receptacles – device mount	10		
	2CWPR-M	Single receptacle – hole – device mount	10		
	2CFSR-M	Single receptacle – hole – box mount	10		
	2CFST	Plunger-style cover	10		
	2CCB*	Grey – device mount (grey paint)	50		
	2CCB-AL	Blank cover – box mount (stamped aluminum)	50		
	2CFSB	Blank cover – box mount	50		

*cULus

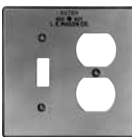Two-gang (cast aluminum)				SP® UL	
	Cat. no.	Description	Std. ctn.		
	2CDR	Two duplex receptacles – device mount	50		
	2CTS	Two switches – device mount	50		
	2CTDR	One switch and one duplex receptacle – device mount	50		

Covers are approved for dry locations only

Three-gang				SP® UL	
	Cat. no.	Description	Std. ctn.		
	3CCB*	Blank cover, three gang – device mount	25		
	3CCB-AL	Blank cover, three gang (stamped aluminum) – with gasket and screws – device mount	25		

Covers are approved for dry locations only

*cULus

Red-Dot Weatherproof products


FS and FD metallic covers

Two-gang (cast aluminum)



Cat. no.	A	B	F	G	K
2CWPDR	4 ⁹ / ₁₆	4 ⁵ / ₈	–	1 ¹³ / ₁₆	–
2CWPR-M	4 ⁹ / ₁₆	4 ⁵ / ₈	2 ³ / ₈	1 ¹³ / ₁₆	2 ³ / ₄
2CFSR-M	4 ⁹ / ₁₆	4 ⁵ / ₈	3 ³ / ₄	3 ³ / ₄	2 ³ / ₄
2CFST	4 ⁹ / ₁₆	4 ⁵ / ₈	3 ³ / ₄	3 ³ / ₄	–
2CCB	4 ⁹ / ₁₆	4 ⁵ / ₈	3 ⁹ / ₃₂	1 ¹³ / ₁₆	–
2CCB-AL	4 ⁹ / ₁₆	4 ⁵ / ₈	3 ⁹ / ₃₂	5 ⁵ / ₈	–
2CFSB	4 ⁹ / ₁₆	4 ⁵ / ₈	3 ³ / ₄	3 ³ / ₄	–

Diagrams

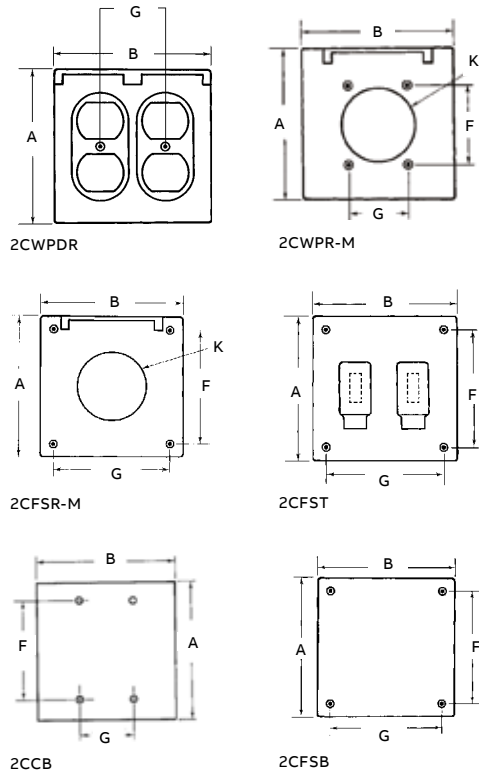


Two-gang (cast aluminum)



Cat. no.	A	B	F	G
2CDR	4 ⁹ / ₁₆	4 ⁵ / ₈	–	1 ¹³ / ₁₆
2CTS	4 ⁹ / ₁₆	4 ⁵ / ₈	2 ³ / ₈	1 ¹³ / ₁₆
2CTDR	4 ⁹ / ₁₆	4 ⁵ / ₈	2 ³ / ₈	–

Diagrams

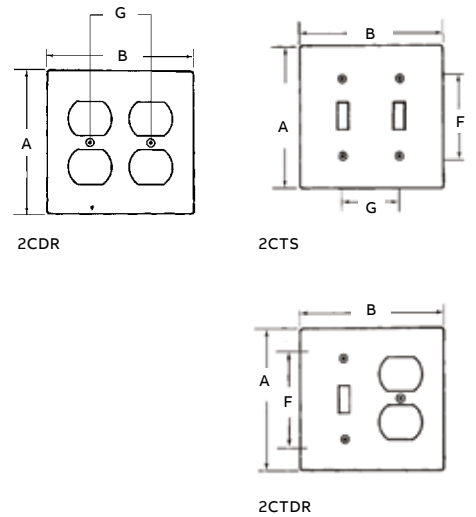


Covers are approved for dry locations only

Three-gang (stamped aluminum)



Cat. no.	A	B	F	G
3CCB	4 ¹ / ₂	6 ³ / ₈	3 ¹ / ₄	5 ⁵ / ₈
3CCB-AL	4 ¹ / ₂	6 ³ / ₈	3 ¹ / ₄	5 ⁵ / ₈

Diagram

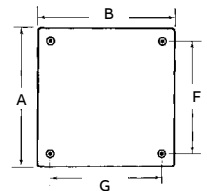

Covers are approved for dry locations only

Red•Dot Weatherproof products

Deck grommet and stainless steel box and cover



—
Nonmetallic deck grommet

Cat. no.	Finish
DKG-CA	Black

All supplied receptacles are tamper-resistant



- 37.3 cu. in. capacity
- 316 stainless steel construction
- NEMA 3R rated
- NEMA 4X rated while not in use when properly installed
- NSF certified
- cULus Listed

—
Stainless steel while-in-use box and cover system



Cat. no.	Description	Std. ctn.
SSE	Stainless steel while-in-use box and cover system	1