

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1301460031](#)
Status: **Active**
Overview: [Watertite Extreme Wet-Location Wiring Solutions](#)
Description: Watertite Extreme Plug, 2 Pole/3 Wire, NEMA 5-15, 125V, Cord Grip Body Size F2, Silicone Husk

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Datasheet \(PDF\)](#)

Agency Certification

CSA LR6837
 UL E10176

General

Product Family Wiring Devices
 Series [130146](#)
 IP Rating IP69K
 NEMA Configuration NEMA 5-15
 Overview [Watertite Extreme Wet-Location Wiring Solutions](#)
 Product Name Watertite Extreme
 Receptacle Type N/A
 Specialty N/A
 Type Plug
 UPC 78678871002

Physical

Cord Grip Body Size F2 1/2"
 Flange No
 Flip Lid No
 Gender Male
 Length N/A
 Locking Blade No
 Net Weight 113.851/g
 Poles 2-pole/3-wire

Electrical


Cord Type N/A
 Current - Maximum per Contact 15.0A
 GFCI No
 Lighted Connector No
 Voltage - Maximum 125V

Material Info

Engineering Number 14W47

Reference - Drawing Numbers

Sales Drawing 1301460031-000

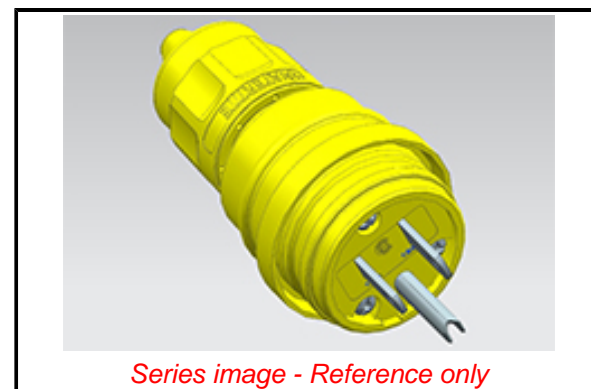

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 7(c)-I,6(c)

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

50 Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

[130146 Series](#)