

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1301460082](#)
Status: **Active**
Overview: [Watertite Extreme Wet-Location Wiring Solutions](#)
Description: [Watertite Extreme Plug with Locking Blade, 2 Pole/3 Wire, NEMA L5-15, 125V, Cord Grip Body Size F2, Silicone Husk](#)

Documents:

[Drawing \(PDF\)](#)

[Datasheet \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR6837
 UL E10176

General

Product Family [Wiring Devices](#)
 Series [130146](#)
 IP Rating [IP69K](#)
 NEMA Configuration [NEMA L5-15](#)
 Overview [Watertite Extreme Wet-Location Wiring Solutions](#)
 Product Name [Watertite Extreme](#)
 Receptacle Type [N/A](#)
 Specialty [N/A](#)
 Type [Plug](#)
 UPC [78678871202](#)

Physical

Cord Grip Body Size [F2 1/2"](#)
 Flange [No](#)
 Flip Lid [No](#)
 Gender [Male](#)
 Length [N/A](#)
 Locking Blade [Yes](#)
 Net Weight [126.552/g](#)
 Poles [2-pole/3-wire](#)

Electrical


Cord Type [N/A](#)
 Current - Maximum per Contact [15.0A](#)
 GFCI [No](#)
 Lighted Connector [No](#)
 Voltage - Maximum [125V](#)

Material Info

Engineering Number [24W47](#)

Reference - Drawing Numbers

Sales Drawing [1301460082-000](#)

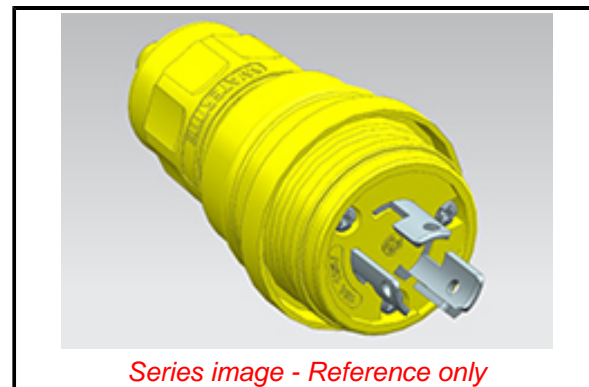

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[130146 Series](#)