

RAZOR

OVERVIEW

The Razor series' ultra-slim design is perfect for any small space and allows for flexible installation, particularly in confined areas or when facing constraints such as beams, ceiling joists or air ducts.

FEATURES

■ 3 COLOR TEMPERATURES AND SELECTABLE CCT

27 K, 3 K and 4 K, available in select styles (white finish only)
3-CCT: 3 K, 4 K and 5 K, available in all styles

■ 4 FINISHES

White, black, satin chrome and bronze

■ RATINGS AND CERTIFICATIONS

IC rated
Wet location rated
Airtight rated ASTM E283-04
ETL certified for USA and Canada
Fire rated FT4/FT6 wires (UL 2464)

- Largest assortment of shapes, sizes, finishes and color temperatures
- Widest range of compatible LED dimming options
- Designed for both forward phase and reverse phase dimmers at 120V
- Available with 0-10v dimming at 120-277V

■ WARRANTY AND LED LIFE

5 year warranty and a 50,000-hour LED life

■ EASY INSTALLATION

Each unit includes a junction box with driver, pressure-fit spring clips and Quick Connect wire connectors for fast and easy installation.

Heavy duty mounting clips are designed for sturdy installation and prevent springs from falling off during installation.

Large flange feature allows for compensation if hole cut-outs are done incorrectly.



RAZOR

ULTRA THIN RECESSED DOWNLIGHT **LED**

The Razor flat design with low profile allows the light unit to slip under a joist. Whether a home or commercial application, its superior brightness and low power usage offer an ideal lighting solution.

FINISH



WHITE



BLACK



BRONZE



SATIN CHROME

SIZE & MODELS



3"
420 lumens
RZR-CCT-300

4"
680 lumens
RZR-CCT-400

5"
780 lumens
RZR-CCT-500

6"
1000 lumens
RZR-CCT-600

8"
1450 lumens
RZR-CCT-800

COLOR TEMPERATURE

27 K, 3 K & 4 K
3-CCT: 3 K, 4 K & 5 K

* Available in a 120-277V option (0-10v dim)

** Single color temperature options available in select sizes, in white finish only



RAZOR·R

LED LOW PROFILE REGRESSED RECESSED DOWNLIGHT

FINISH



WHITE



BLACK



BRONZE



SATIN CHROME

SIZE & MODELS

4" 850 lumens RZR-CCT-411	6" 1170 lumens RZR-CCT-611
--	---

COLOR TEMPERATURE

27 K & 3 K, available in white finish only

3-CCT: 3 K, 4 K & 5 K

* Available in a **120-277V** option (0-10v dim)

The Razor-R series takes illumination to the next level, featuring a design and look that create a wash of light to flow throughout, with minimal hot spots on the ceiling. This improved Razor-R provides higher performance resulting in greater lumen output, while increasing the lumen per watt efficiency. Wet location rated.




IC/AIRTIGHT
RATED



The contemporary looking Razor-S series has all the benefits of the original Razor. The square design enables unlimited design applications, using cutting-edge installation techniques. All Razor-S units are wet rated and offer a round back feature, making hole cut-outs much easier and quicker than the standard square back versions.

This product has the added feature of being able to slip under a joist for installation.

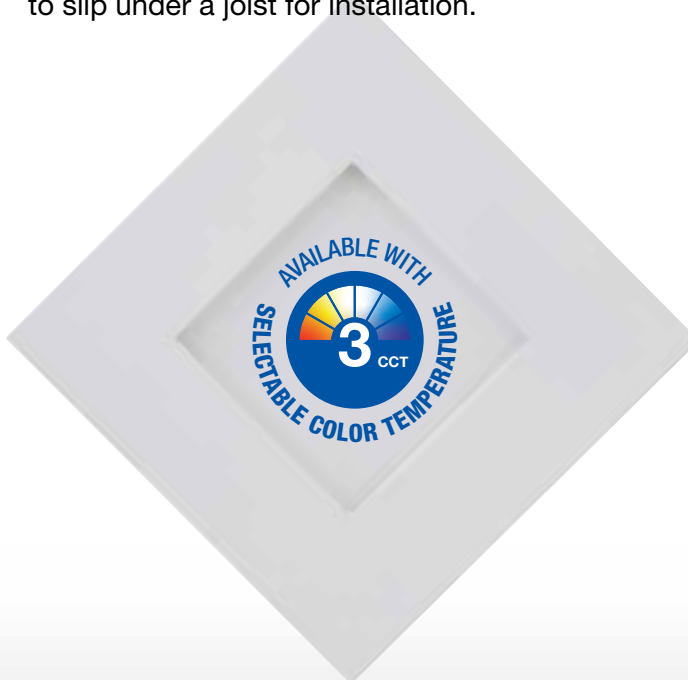

IC/AIRTIGHT
RATED



RAZOR·S

ULTRA THIN RECESSED SQUARE DOWNLIGHT **LED**

FINISH



WHITE



BLACK



BRONZE



SATIN CHROME

SIZE & MODELS

4" 680 lumens RZR-CCT-430	6" 1000 lumens RZR-CCT-630
--	---

COLOR TEMPERATURE

3-CCT: 3 K, 4 K & 5 K

* Available in a **120-277V** option (0-10v dim)

ROUND BACK



RAZOR-G

LED LOW PROFILE GIMBAL RECESSED DOWNLIGHT

FINISH



WHITE



BLACK



SATIN CHROME

SIZE & MODELS

4"
750 lumens
RZR-CCT-421

COLOR TEMPERATURE

3-CCT: 3K, 4K & 5K

* Available in a **120-277V**
option (0-10v dim)

The Razor-G series improves on the original concept by being able to direct the light output where needed. This unit is wet rated and is perfect for highlighting specific needs, such as a sloped ceiling application.



IC/AIRTIGHT
RATED



RAZOR COMPONENTS

VERSATILE PARTS FOR EASY INSTALLATION



JUNCTION BOX

"Quick Connect" wire connectors for a quick wire connection

Standard **120V** dimmable driver; optional **120-277V** drivers available as special order (0-10v dim)



TUNEABLE SWITCH ON 3-CCT MODELS

CCT switch located conveniently on the back side of light units and allows for color selection to be made at the final stage of installation

The Razor and Razor-S design has the added feature of being able to slip under a joist for installation



SPRING CLIPS & FLANGES

Heavy duty mounting clips are designed for sturdy installation and prevent springs from falling off during installation

Large flange feature allows for compensation if hole cut-outs are done incorrectly



MOUNTING PLATES WITH HANGER BARS

Recommended for new construction or suspended ceiling applications

