


SK Single Piece Strut Clamp for Conduit – SK125I



- One piece break apart strut clamp for EMT and Rigid conduit
- Includes thread impression and captured screw

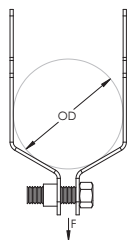

Part Number	SK125I
Material	Steel
Finish	Electrogalvanized
EMT Conduit Size	3/4"
Rigid Conduit/Pipe Size	3/4"
Outer Diameter (OD)	0.92" – 1.05"
Width (W)	1 1/4"
Static Load (F)	200 lb
Certifications	cULus
Standard Packaging Quantity	100 pc
UPC	78285625337
EAN-13	8711893018738

UL, UR, cUL, cUR, cULus and cURus are registered certification marks of UL LLC.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.erico.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

© 2020 nVent All rights reserved

nVent, nVent CADDY, nVent ERICO, nVent ERIFLEX and nVent LENTON are owned by nVent or its global affiliates.

All other trademarks are the property of their respective owners. nVent reserves the right to change specifications without prior notice.

