




# Luminaire Panel

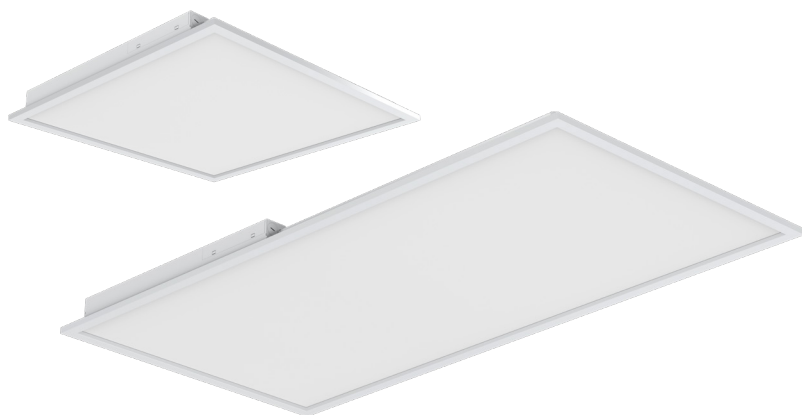

Project: \_\_\_\_\_

Location: \_\_\_\_\_

Cat.No: \_\_\_\_\_

Type: \_\_\_\_\_

Notes: \_\_\_\_\_

The Pila BP is a backlit LED flat panel that provides a uniformly lit lens for a clean aesthetic appeal, and even distribution of light to the space to minimize the number of light points needed. Shallow depth and light weight make the BP flat panel a versatile and easy to use product in applications such as schools, office, and retail.

## Product offering


| Catalog Code | Description   | UPC Code     | Case Qty. (pc/carton) | Pallet Qty. (pc/pallet) |
|--------------|---|--------------|-----------------------|-------------------------|
| BP2230L40KU  | 2x2 Panel, 30W, 3000 LUMENS, 4000K, 120-277V, 0-10V DIM | 190096130788 | 2                     | 28                      |
| BP2448L40KU  | 2x4 Panel, 48W, 4800 LUMENS, 4000K, 120-277V, 0-10V DIM | 190096130795 | 2                     | 14                      |
| BP2230L35KU  | 2x2 Panel, 30W, 3000 LUMENS, 3500K, 120-277V, 0-10V DIM | 190096130801 | 2                     | 28                      |
| BP2448L35KU  | 2x4 Panel, 48W, 4800 LUMENS, 3500K, 120-277V, 0-10V DIM | 190096130818 | 2                     | 14                      |

## Technical specifications

|                               |   |
|-------------------------------|---|
| <b>Nominal power</b>          | 2x2: 38W, 2x4: 48W  |
| <b>Nominal lumens</b>         | 2x2: 3000 lumens, 2x4: 4800 lumens  |
| <b>Input voltage</b>          | 120-277V, 50/60Hz   |
| <b>Dimming</b>                | 0-10V to 10%  |
| <b>CCT</b>                    | 3500, 4000K   |
| <b>CRI</b>                    | ≥80   |
| <b>Power Factor (system)</b>  | >0.9  |
| <b>System Efficacy</b>        | >100 lm/W   |
| <b>Material and finishing</b> | White painted finish, steel housing and driver box, extruded aluminum frame, acrylic diffuser |
| <b>Mounting</b>               | Recessed T-Bar NEMA G 15/16", NFG 9/16", T-bar clips provided (4)                             |
| <b>Weight</b>                 | 2x2: 5.3lb (2.4kg), 2x4: 10.1lb (4.6kg)   |
| <b>IP/IK rating</b>           | IP20 / IK03   |




|                                    |   |
|------------------------------------|---|
| <b>Operating temperature range</b> | 14°F to 95°F (-10°C to 35°C)                          |
| <b>Lifetime</b>                    | 50K hrs @ L70 B50 @Ta 25°C                            |
| <b>Compliance</b>                  | cETLus listed for use in damp locations, DLC standard |
| <b>Warranty</b>                    | 5-year limited warranty                               |



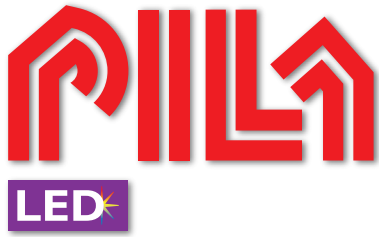

## Dimensions

2x2

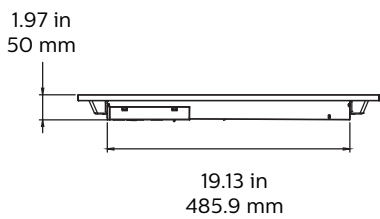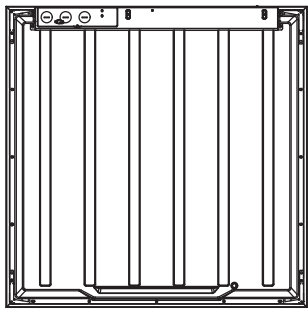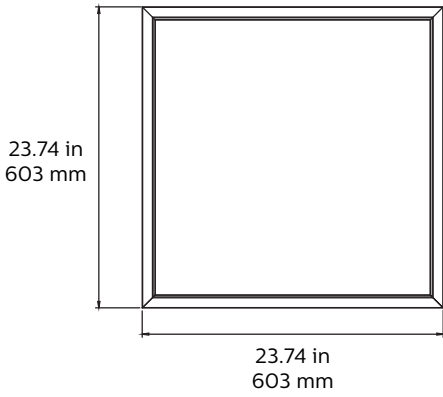

2x4

47.72 in  
1212 mm

